


PREVOS1 SAFETY QUICK COUPLINGS - CSI 08

Tapered male thread twin coupler

Profile : ISO 6150C



Part number	Male thread	Min. operating pressure (bar)	Flow rate at 6.00 bar (l/min) ($\Delta P = 0.60$ bar)	ID passage (mm)	Temperature min/max (°C)
CSI 088152	R3/8	2.00 / 12.00	2028.00	8 mm	-15.00 / 70.00
CSI 088153	R1/2	2.00 / 12.00	2028.00	8 mm	-15.00 / 70.00

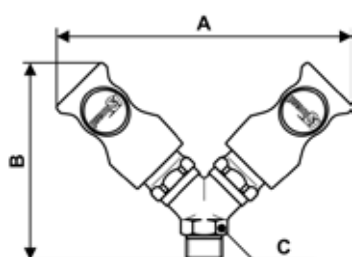

Part number	Dim. A (mm)	Dim. B (mm)	Dim. C (mm)
CSI 088152	135.00	90.00	20.00
CSI 088153	140.00	95.00	25.00