

RAMO 30 F, RJ45, round collar, frontring stainless steel, RJ 45 CAT 5



fields of application

- Measurement-control-regulation
- Electrical engineering
- Mechanical and system engineering
- Vehicle construction
- Chemical industry
- Industrial robots
- Home technology



description

Cable feed-through for front panels. Front side USB 3.0 or RJ45, rear side with corresponding sockets in the housing or 55 cm cable and socket.

technical data

➤ general

| | |
|---|--|
| Collar color | black |
| Front ring color | stainless steel |
| Collar shape | round |
| Operating temperature, min. | -25 °C |
| Operating temperature, max. | 70 °C |
| Storage temperature, min. | -40 °C |
| Storage temperature, max. | 90 °C |
| illuminated | No |
| Packaging | Box |
| Packaging unit | 2 pcs. |
| net weight | 31.3 g |
| Operating life | 750 cycles |
| Degree of protection, front side, according to DIN EN 60529 | IP65 with sealing cap |
| UL Enclosure Type Rating front side | type 4X indoor |
| Environment resistance | IEC 60068-2-14 IEC 60068-2-30 IEC 60068-2-78 |
| Impact resistance IK | 05 side 06 frontal |
| MOQ order | 2 pcs. |
| RoHS compliant | Yes |
| REACH compliant | Yes |

direct links

- RAFI eCatalog

> mounting diameters


| | |
|---------------------------|----------|
| Outside dimension, length | 34.5 mm |
| Outside dimension, width | 34.5 mm |
| Outside dimension, height | 45.43 mm |
| Mounting hole | 30.3 mm |
| Mounting depth | 40.26 mm |
| Installation height | 5.17 mm |
| Grid, min. | 35 mm |
| Collar dimension | 34.5 mm |

> mechanical data

| | |
|----------------------------|---------------|
| Fixing | Threaded ring |
| Threaded ring torque, max. | 1.2 Nm |
| Front side terminal | RJ 45 CAT 5 |
| Terminal on the rear | RJ 45 CAT 5 |

drawings

Dimensioned drawing

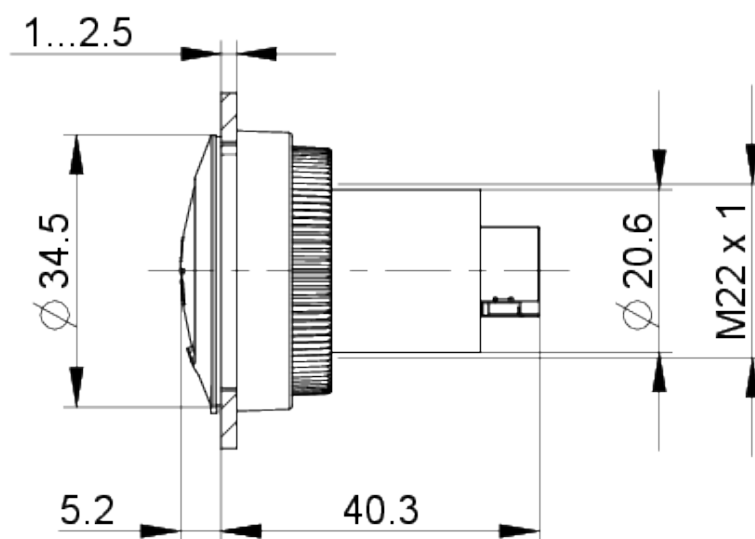

Mounting hole drawing

