


Features

- Lightweight construction for easy handling.
- Optimum flow is maintained by the smooth bore.
- Tough, flexible and extremely durable.
- Retains flexibility, even in cold weather applications.
- Outstanding resistance to the effects of weather.
- Excellent chemical and abrasion resistance.
- RoHS 3 compliant.
- Shock resistant rigid PVC reinforcement
- Flexible Phthalate free PVC

RS PRO Hose Pipes & Flex Tubes

RS Stock No.: 0336782

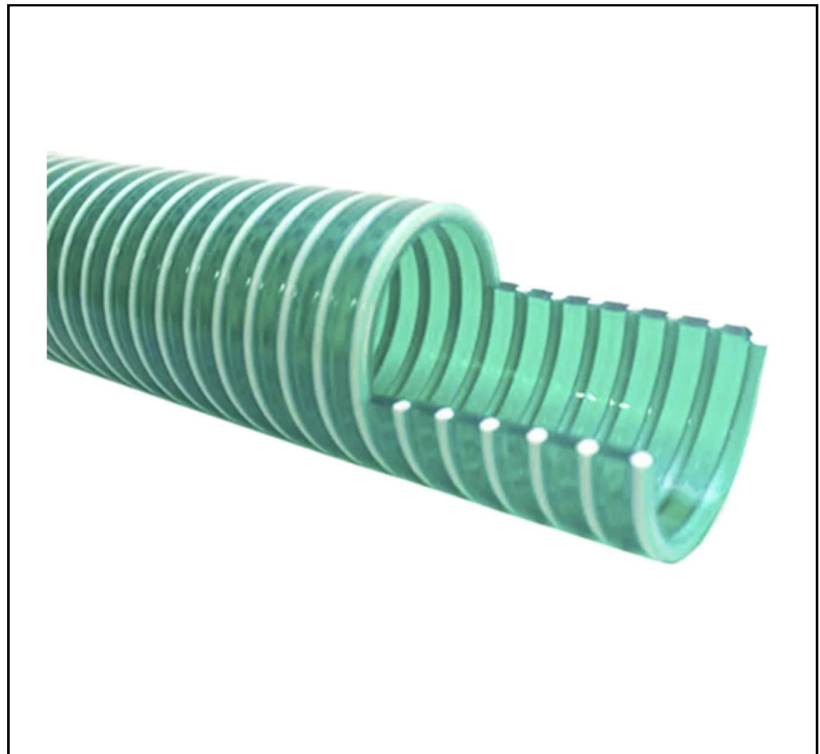

RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

A lightweight delivery hose reinforced with a rigid internal crush and kink resistant white PVC helix. It is tough, flexible and extremely durable. It has outstanding resistance to the effects of weather.

Key Features:

- Lightweight construction for easy handling.
- Optimum flow is maintained by the smooth bore.
- Tough, flexible and extremely durable.
- Retains flexibility, even in cold weather applications.
- Outstanding resistance to the effects of weather.
- Excellent chemical and abrasion resistance.
- RoHS 3 compliant.
- Shock resistant rigid PVC reinforcement
- Flexible Phthalate free PVC

Construction:

Manufactured with a white rigid crush resistant anti-shock PVC spiral helix encapsulated in a flexible translucent green PVC cover, with a smooth inside wall. Other colours available upon request.

Applications: • Light pressure transfer of liquids, slurries and powders • Agricultural • Horticultural • Marine • Construction

General Specifications

Hose Pipe / Flexible Tube	Flexible Tube
Colour	Green
Features	Flexible
Series	RS PRO DH
Inner Diameter	51.6mm
Outer Diameter	59.8mm
Material	PVC
Hose Pipe Action	Transfer, Vacuum
Maximum Working Pressure	5.3bar
Suitable Application	Industrial
Minimum Operating Temperature	-10°C
Maximum Operating Temperature	+55°C
Length	30m
Reinforced	Yes
Bend Radius	230mm
Standards Met	RoHS 3
Vacuum Metres H2O	7