


Data sheet

CTOT

ENGLISH

RS Stock No. 370-6262

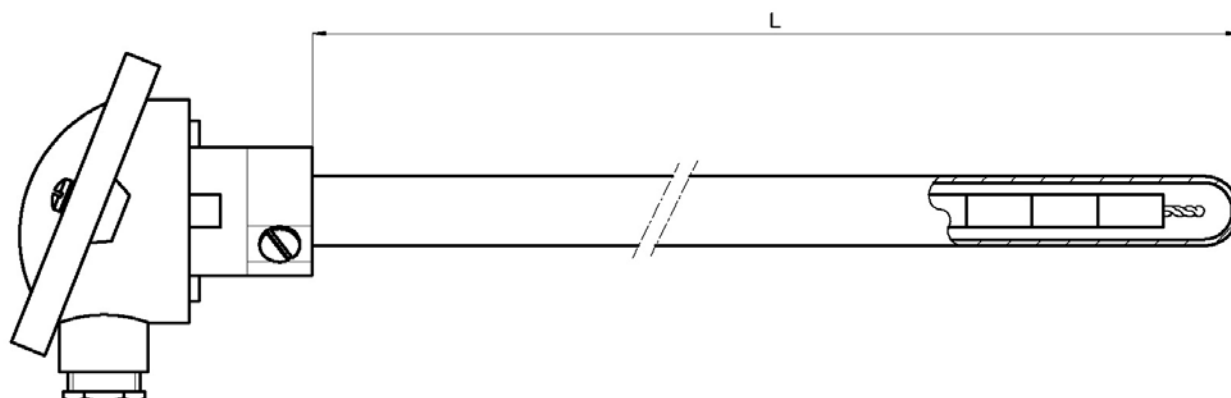

RANGE :				
<ul style="list-style-type: none"> 0 / 1050°C 				
USE :				
<ul style="list-style-type: none"> 				
KEY POINT :				
<ul style="list-style-type: none"> Oven thermal traitement and incineration 				
SPECIFICATIONS :				
<ul style="list-style-type: none"> Steel protector AR25/50Ø21.3 Link head DIN A 				
DIMENSIONS :				
<ul style="list-style-type: none"> Sonde length = 1000 mm Sonde diameter = Ø21.3 mm 				
METROLOGICAL DATA :				
<ul style="list-style-type: none"> As per IEC 584 Standard tolerance TC "K" class1: -40°C < t° < 375°C = ± 1.5°C 375°C < t° < 1000°C = ±0.004. [t] Time constant at 63% in water: 0.7 sec Output signal FEM(mV) as per curve of "K" type as per norme IEC 60584 				
Autre Dimensions :				
	Length	500	700	1000
Diameter				
	Ø21,3	370-6234	370-6256	370-6262