 


## Cast resin joint, Straight-through i, 4 x 25mm<sup>2</sup> to 4 x 95mm<sup>2</sup>, L=400mm, 1140 ml, Polyurethane resin (PUR) black

Art.-No. 435-12105 | i-4 / SF-PUR-BK | 



- Two-part, impact-proof, transparent moulding shells
- Compact, optimized dimensions
- Standard cable diameters indicated on the shells
- Safe-Filling system (SF)
- Immediately ready for use
- 
- 




More products in this product group:

[Straight-through cable joints without connectors >](#)

Application	RELICON straight-through joints are provided with an integrated connector block and made for low-voltage electrical networks. They are suitable for jointing on polymeric cables and wires made of PVC, XLPE, PE, EPR and utility cables. Application: Connections in industrial buildings, power supply in the ground, outdoors and underwater.
Colour	Black (BK)
Content	Cast resin PUR 771 Two-chamber pouch, transparent Moulding shells, transparent SF-system and nozzle Protective gloves, emery cloth, installation instructions HelaTape vinyl electrical tape Spacer for max. 5 core cable (i-1 to i-4)
Material	Polyurethane resin (PUR)
No. of Wires	5
PART DESCRIPTION	i-4 / SF-PUR-BK
Pack Content	1 Set
Package Content packed in	set
Product Family	RELICON i-Line SF with PUR 771
Product Group	Straight-through cable joints without connectors
Type	i-4 / SF
Variant	Cast resin



## Product Dimensions

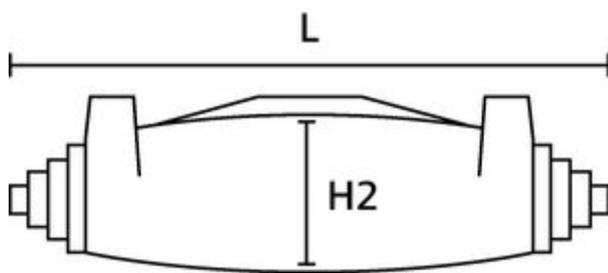

Conductor Size Range mm <sup>2</sup>	25-95 mm <sup>2</sup>
Height (H2)	69 mm
Length (L)	400 mm
Main Cable max	4 x 95 mm <sup>2</sup>
Main Cable min	4 x 25 mm <sup>2</sup>

ELV Compliant (Article 4 - 2)	YES
Halogen-free	No
Hazardous Goods	No
Operating Temperature	-25 °C to +130 °C
ROHS compliant	Yes
Shelf Life	36 months
Specifications	<b>RoHS</b> ✓
Voltage Range	0.6/1 kV

## Logistics and Packaging

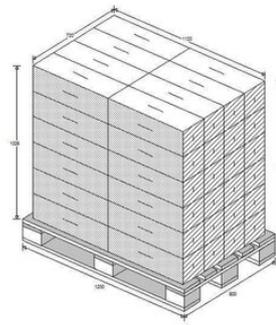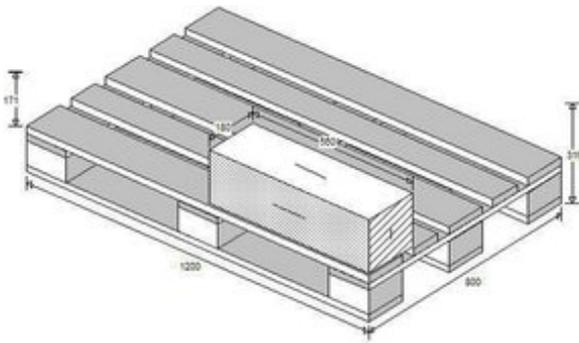

GTIN-13 / EAN	4031026627014
Packaging 3 - Height (m)	0.171 m
Packaging 3 - Length (m)	0.56 m
Packaging 3 - Qty	1
Packaging 3 - Type	box
Packaging 3 - Volume (m <sup>3</sup> )	0.0172 m <sup>3</sup>
Packaging 3 - Weight (kg)	2.6 kg
Packaging 3 - Width (m)	0.18 m
Packaging 4 - Height (m)	0.955 m
Packaging 4 - Length (m)	1.2 m
Packaging 4 - Qty	48
Packaging 4 - Type	pallet
Packaging 4 - Volume (m <sup>3</sup> )	0.917 m <sup>3</sup>
Packaging 4 - Weight (kg)	184.8 kg
Packaging 4 - Width (m)	0.8 m
Storage Temperature	+4 °C to +40 °C

## More Information

