

# ST 18/3-pole plug components

250 V, 16 A


# ST 18/3

## Terminal connection: single

Strain relief device:  
for PVC-sheathed flexible cord  
1 x round cable Ø 6.5–8.3 mm

Sheath strip length: 28 mm  
Insulation strip length: 7 mm

Part no. Box Qty


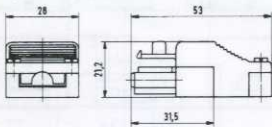


## Terminal connection: single

Strain relief device:  
for PVC-sheathed flexible cord  
1 x round cable Ø 6.5–8.3 mm  
2 x round cable Ø 5.5–7.2 mm  
1 x flat cable 4.6 x 8.1 mm

Sheath strip length: 28 mm  
Insulation strip length: 7 mm

Part no. Box Qty

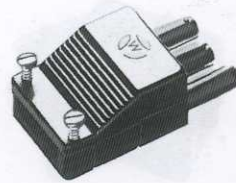
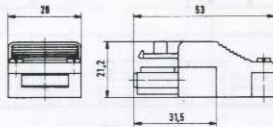


## Terminal connection: dual

Strain relief device:  
for PVC-sheathed flexible cord  
1 x round cable Ø 6.5–8.3 mm

Sheath strip length: 28 mm  
Insulation strip length: 7 mm

Part no. Box Qty

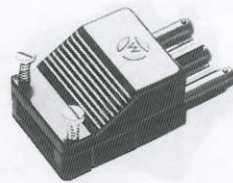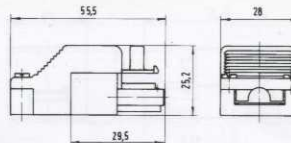


## Terminal connection: dual

Strain relief device:  
for PVC-sheathed flexible cord  
1 x round cable Ø 6.5–8.3 mm  
2 x round cable Ø 5.5–7.2 mm  
1 x flat cable 4.6 x 8.1 mm

Sheath strip length: 28 mm  
Insulation strip length: 7 mm

Part no. Box Qty

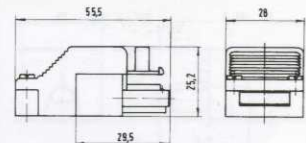

**Plug component** unassembled with strain relief device **without** locking device

**93.932.3353.0** 200  
**93.932.3350.0** 200  
93.932.3750.0 200

**Plug component** unassembled with strain relief device **with** locking device

**93.932.4353.0** 200  
**93.932.4350.0** 200  
93.932.4750.0 200

Part no. Box Qty



**Plug component**

**93.032.3353.0** 200  
**93.032.3350.0** 200  
**93.032.3750.0** 200

**Plug component** unassembled with strain relief device **without** locking device

**93.832.3353.0** 200  
**93.832.3350.0** 200  
93.832.3750.0 200

**Plug component** unassembled with strain relief device **with** locking device

**93.832.4353.0** 200  
**93.832.4350.0** 200  
93.832.4750.0 200

Part no. Box Qty



**Plug component**

**93.032.3353.0** 200  
**93.032.3350.0** 200  
**93.032.3750.0** 200

**Plug component** unassembled with strain relief device **without** locking device

**93.932.6353.0** 200  
**93.932.6350.0** 200

**Plug component** unassembled with strain relief device **with** locking device

**93.932.7353.0** 200  
**93.932.7350.0** 200

Part no. Box Qty



**Plug component**

**93.032.6353.0** 200  
**93.032.6350.0** 200

**Plug component** unassembled with strain relief device **without** locking device

**93.832.6353.0** 200  
**93.832.6350.0** 200

**Plug component** unassembled with strain relief device **with** locking device

**93.832.7353.0** 200  
**93.832.7350.0** 200

Part no. Box Qty



**Plug component**

**93.032.6353.0** 200  
**93.032.6350.0** 200



**Strain relief device without** locking device, base and top

**Z7.410.8153.0** 200  
**Z7.410.8150.0** 200

**Strain relief device with** locking device, base and top

**Z7.410.8353.0** 200  
**Z7.410.8350.0** 200




**Strain relief device without** locking device, base and top

**Z7.410.5153.0** 200  
**Z7.410.5150.0** 200

**Strain relief device with** locking device, base and top

**Z7.410.5353.0** 200  
**Z7.410.5350.0** 200

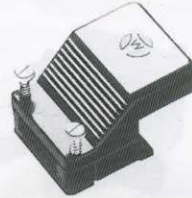

**Strain relief device without** locking device, base and top

**Z7.410.8253.0** 200  
**Z7.410.8250.0** 200

**Strain relief device with** locking device, base and top

**Z7.410.3453.0** 200  
**Z7.410.3450.0** 200



**Strain relief device without** locking device, base and top

**Z7.410.5253.0** 200  
**Z7.410.5250.0** 200

**Strain relief device with** locking device, base and top

**Z7.410.3353.0** 200  
**Z7.410.3350.0** 200

<sup>1)</sup> Plug component green, strain relief device black (Note: observe coding!)

<sup>1)</sup> Plug component green, strain relief device black (Note: observe coding!)

The order numbers printed in bold type can be supplied with short lead times. Goods are supplied unassembled.