




HST-DE RX7s 150W HO 2000K

Article number: 146176

BAI HPS HST-DE RX7s 150W 2000K 16500lm 23x132mm NAV-TS Clear High pressure sodium-vapour lamp

Gas discharge lamp with various applications.

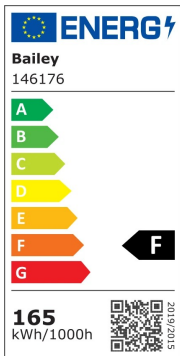

General ETIM properties

ETIM group	Lamps
ETIM class	High pressure sodium-vapour lamp
Name	HST-DE RX7s 150W HO 2000K
Brand	Bailey
Productseries	HID
Producttype	HST-DE

ETIM specifications

Socket	RX7s
Lamp power [W]	150
Lamp shape	Tube, single-ended
Colour temperature [K]	2000
Lamp designation	Other
Diameter [mm]	23
Total length [mm]	132
Lighting for plants	Yes
Colour rendering index CRI	20-39
Lamp efficacy [lm/W]	110
External ignitor required	Yes
External ballast required	Yes
Luminous flux [lm]	1650
Model	Clear
Replacement for mercury vapour lamp	No
Weighted energy consumption in 1000 hours [kWh]	165
Average nominal lifetime [h]	28000
Number of discharge tubes	1
Energy efficiency class according to EU regulation 2019/2015	F
Mercury-free	No

Complementary articles



146206

VS 100913 RX7s Lampholder
Cable 200mm 1pce