

**FAG****UKP218** **Plummer block housing unit**

Plummer block housing units UKP, cast iron housing, with long base, radial insert ball bearing with adapter sleeve, RSR seals

Technical information**Your current product variant**

Material	GG	Grey cast iron
Housing clearance	J7	Normal swivel torque

Main Dimensions & Performance Data


d	80 mm	Bore diameter
L	327 mm	Length total
H ₂	200 mm	Height
≈m	12.71 kg	Weight

Mounting dimensions

J	262 mm	Distance fixing bore
N	27 mm	Width (slot)
N ₁	33 mm	Length (slot)

Dimensions

H	101.6 mm	Distance shaft axis
A	88 mm	Width (base)
H ₁	33 mm	Height (base)
B ₁	86 mm	Locking collar total width
Q	M6	Connection thread for lubrication

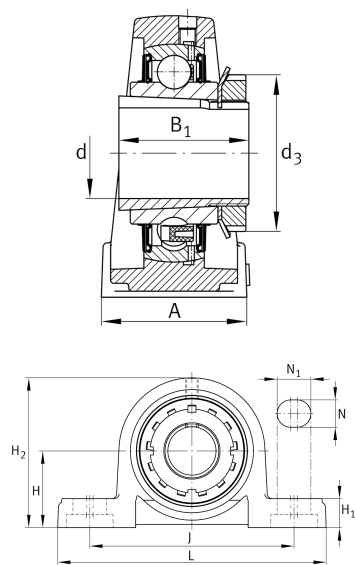



Additional information

P218	Housing
UK218	Bearing designation

Temperature range

T _{min}	-20 °C	Operating temperature min.
T _{max}	120 °C	Operating temperature max.