




Connectors > Connector Accessories > Heat Sinks

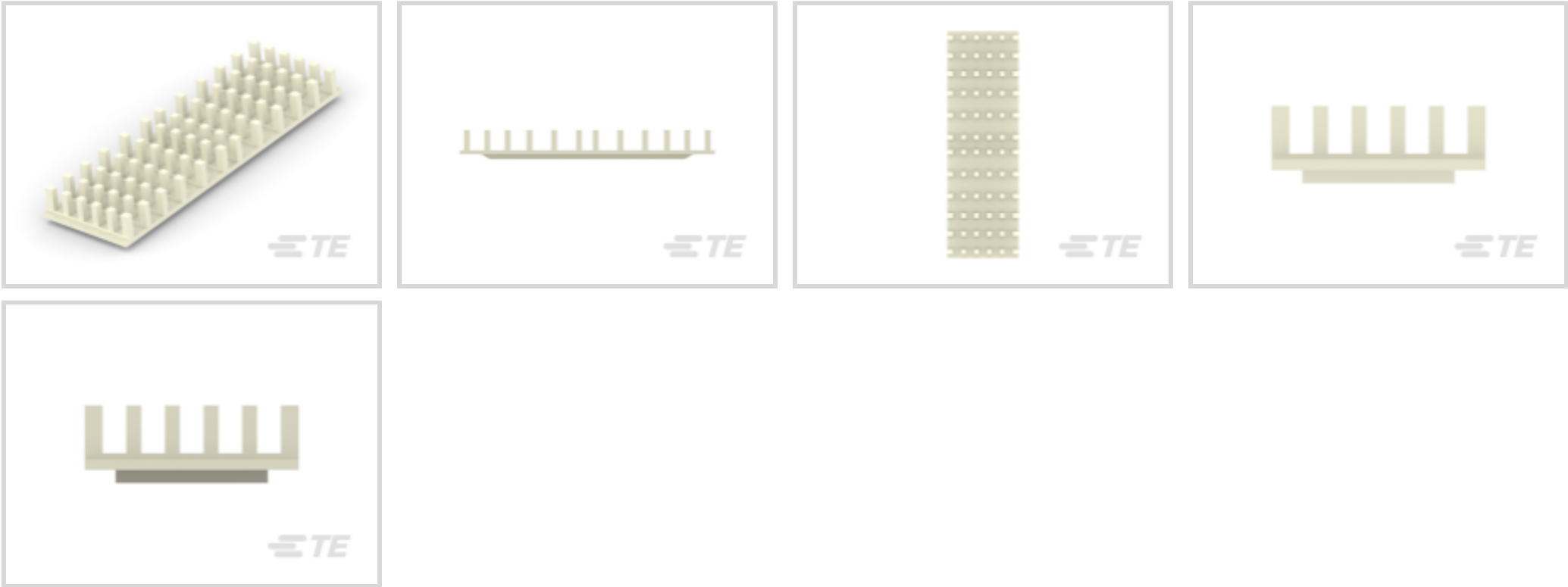

Device Type: **XFP**

Fin Style: **Pin Fin**

Number of Fins: **72**

Power Rating: **5 W, 10 W, 15 W**

Features

Product Type Features

|             |     |
|-------------|-----|
| Device Type | XFP |
|-------------|-----|

Configuration Features

|                |    |
|----------------|----|
| Number of Fins | 72 |
|----------------|----|

Electrical Characteristics

|              |                 |
|--------------|-----------------|
| Power Rating | 5 W, 10 W, 15 W |
|--------------|-----------------|

Body Features

|                                  |                                |
|----------------------------------|--------------------------------|
| Primary Product Material         | Aluminum, Cold-Forged Aluminum |
| Primary Product Plating Material | Nickel                         |
| Fin Style                        | Pin Fin                        |

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

|                                               |                                         |
|-----------------------------------------------|-----------------------------------------|
| EU RoHS Directive 2011/65/EU                  | Compliant                               |
| EU ELV Directive 2000/53/EC                   | Compliant                               |
| China RoHS 2 Directive MIIT Order No 32, 2016 | No Restricted Materials Above Threshold |
| EU REACH Regulation (EC) No. 1907/2006        |                                         |



Current ECHA Candidate List: JAN 2025  
(247)  
Candidate List Declared Against: JAN 2025  
(247)  
Does not contain REACH SVHC

|                           |                                                                                     |
|---------------------------|-------------------------------------------------------------------------------------|
| Halogen Content           | Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free |
| Solder Process Capability | Not applicable for solder process capability                                        |

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 1489948-2  
XFP HEAT SINK CLIP, PLATED




TE Part # CAT-X29-C1171XN  
XFP Cage Assemblies and Kits


Also in the Series | XFP



Connector Caps & Covers(1)

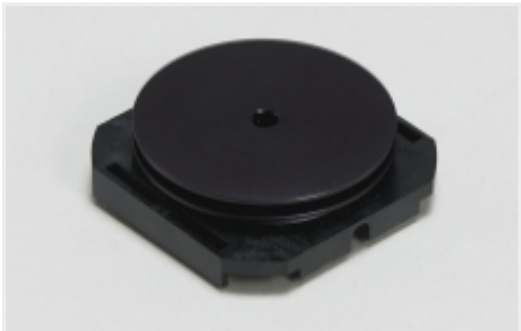

Heat Sinks(8)

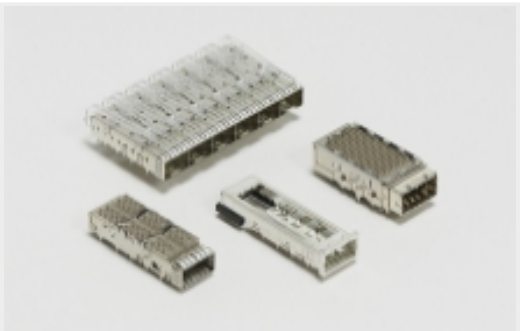

Pluggable IO Connectors & Cages(25)




XFP(25)


Customers Also Bought



TE Part #2007198-1  
SFP+ 1x1 Cage Assembly, Press-

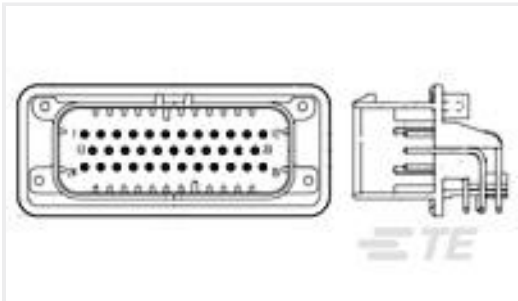


TE Part #776163-1  
35POS,PIN DIA 1.3,HDR ASSY,90DEG, COD 1

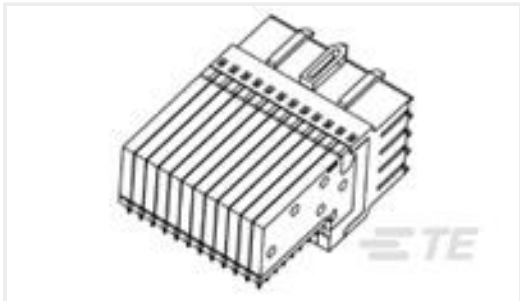

TE Part #1857657-1  
Female Connector




TE Part #2331350-1  
DET SW6.3X3.0X8.0 GW VERT. NO AG TB

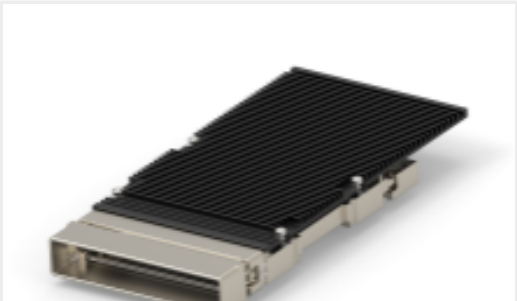


TE Part #2300837-1  
Hardware Kit, CFP, 5mm Heatsink




TE Part #1888247-1  
20 POS SMT CONN, SFP/SFP+, 30A

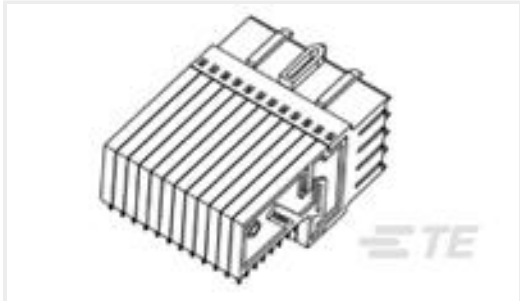

 TE Part #1982738-1  
Female Connector Telcordia



TE Part #2359292-1  
CAGE ASSEMBLY,SFP-DD 1X1, THERMAL BRIDGE

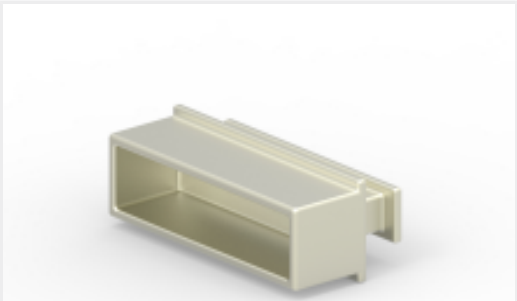

TE Part #2288221-1  
CFP2 EMI/DUST PLUG



TE Part #1393280-5  
V23086C1001A402

Documents

Product Drawings

XFP MSA SAN APPLICATION

English

CAD Files

Customer View Model

ENG\_CVM\_CVM\_1542618-2\_L.2d\_dxf.zip

English

3D PDF

3D

Customer View Model

ENG\_CVM\_CVM\_1542618-2\_L.3d\_igs.zip

English

Customer View Model

ENG\_CVM\_CVM\_1542618-2\_L.3d\_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages





1773408-1 Pluggable Input/Output Solutions catalog - XFP section

English

Product Specifications

Application Specification

English