
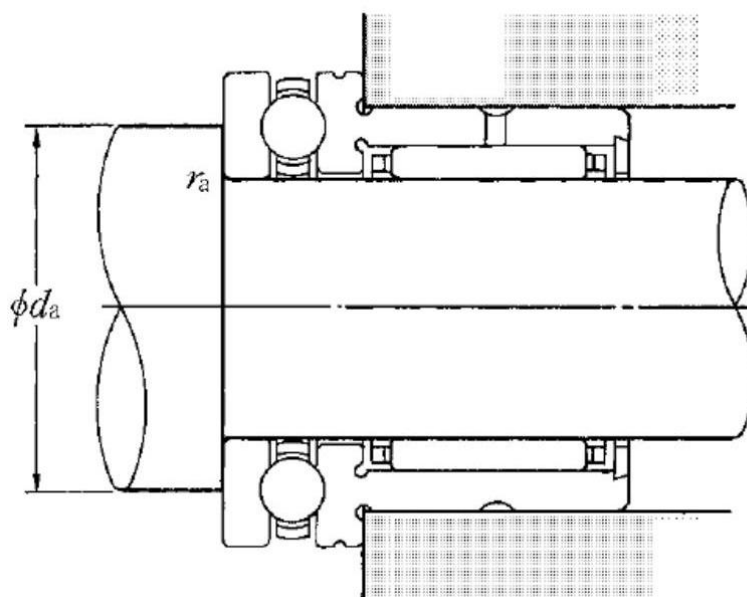


VISUAL (S)

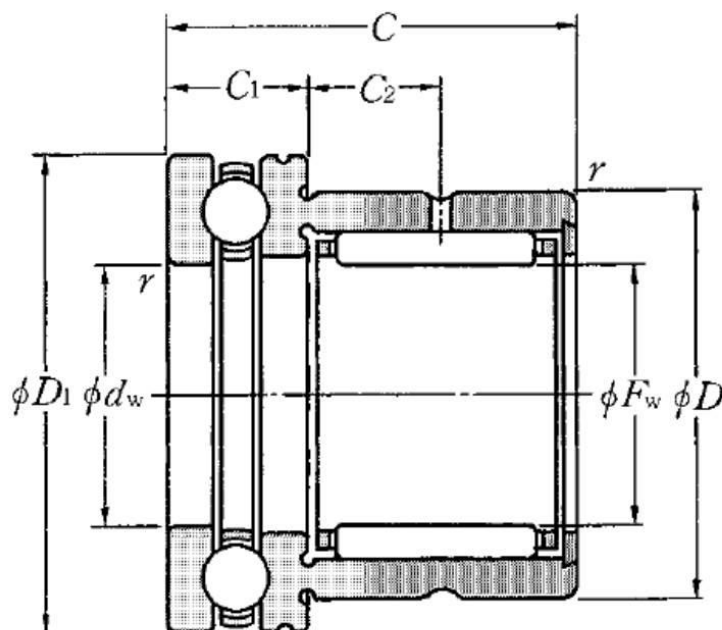

PRODUCT DEFINITION

Brand	NTN
Fw - Under rollers diameter	70 mm
dw - Shaft washer bore diameter	70 mm
D - External diameter	85 mm
D1 - Outer diameter of washer	95 mm
C - Width of bearing, drawn cup or outer ring	40 mm
C1 - Thrust bearing height	18 mm
C2 - Hole location	11 mm
rs - Min fillet radius	1 mm
Lubrication hole on outer ring	Oui/Yes
k - Hole diameter	3 mm
Precision class	P0
Mass	0,612 kg

PRODUCT PERFORMANCE

Cr - Dynamic load rating	36500000 mN
Ca - Dynamic axial load rating	43000000 mN
C0r - Static load rating	86000000 mN
C0a - Static axial load rating	127000000 mN
N lim - Grease lubrication limit speed	14400 °/s
N lim - Oil lubrication limit speed	20400 °/s
Tmin - Min operating temperature	253,15 °K
Tmax - Max operating temperature	393,15 °K



ABUTMENT	
da min - Min shoulder diameter IR	85 mm
ras max - Max shaft & housing fillet radius	1 mm

