


SAULT2 S3 SRC

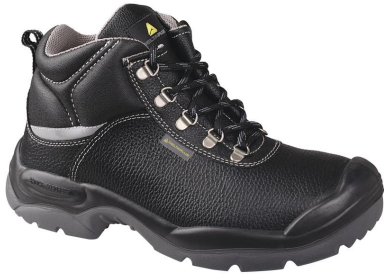

PIGMENTED SPLIT LEATHER BOOTS - S3 SRC

Ref. SAULT2S3



Product specifications

Upper: Pigmented split leather, S3 water resistant treatment. Lining: Polyamide. Insole: Removable preformed - Polyamide on EVA. Outsole: Injected - Dual-density PU with bump cap.

COLOUR

Black

SIZE

39, 40, 41, 42, 43, 44, 45, 46, 47, 48

Product Use - Risks



Antistatic



Shock



Cutting / Perforation



Slip



Construction / Civil engineering



Light industry



Second work / craftman



Heavy industry



Mining

Product's highlights & user's benefits



EXCELLENT SLIP RESISTANCE

- 1- Toe grip and heel grip
- 2- Lateral ladder grip



ANTIFATIGUE SOLE

Integrated flexing zone (PANOFLEX® system)



REINFORCED TOE PROTECTION

Toe with PU cover (BUMPER CAP SYSTEM)



GREAT COMFORT (wider fitting)

Last and toe size 11



SHOCK ABSORBER

Dual density PU outsole



Reflective strip

METAL

METAL

Certifications and Standards



PPE DIRECTIVE 89/686/EEC



EN ISO 20344:2011 Personal protective equipment - Test methods for footwear

EN ISO 20345:2011 Personal protective equipment - Safety footwear.

S3: Additional special requirements

SRC: Slip resistance

References

References	Bar code	COLOUR	SIZE		
SAUL2S3NO40	3295249209803	Black	40	5	-
SAUL2S3NO41	3295249209810	Black	41	5	-
SAUL2S3NO42	3295249209827	Black	42	5	-
SAUL2S3NO43	3295249209834	Black	43	5	-
SAUL2S3NO44	3295249209841	Black	44	5	-
SAUL2S3NO45	3295249209858	Black	45	5	-
SAUL2S3NO46	3295249209865	Black	46	5	-
SAUL2S3NO47	3295249209872	Black	47	5	-
SAUL2S3NO48	3295249209889	Black	48	5	-
SAUL2S3NO39	3295249209797	Black	39	5	-