

Cable duct - CD 25X80 BU - 3240304

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Wiring channel, blue, consisting of upper and lower part, width: 25 mm, height: 80 mm, length: 2000 mm

Why buy this product

- Thanks to its leverage and special cutting geometry, the PPS CD cable duct cutter enables easy, burr-free cutting with minimum effort
- Easy, burr-free cutting with minimum effort using the CUTFOX-CD cable duct cutter
- Predetermined breaking point enables tool-free, burr-free removal of bars
- The wide, diagonal heads of the cable duct bars make it easy to fit the cover and hold it securely in place
- Installed conductors are securely held in place by means of wire retaining clips that can be snapped onto bars on the side
- Plastic body-bound rivets enable easy fixing of cable ducts using the rivet setting tool



Key commercial data

Packing unit	10 pc
Minimum order quantity	10 pc
GTIN	 4 046356 507844
Weight per Piece (excluding packing)	800.0 g
Custom tariff number	39259020
Country of origin	Germany

Technical data

Dimensions

Length (b)	2000 mm
Height	80 mm
Width (a)	25 mm

Ambient conditions

Ambient temperature (operation)	-5 °C ... 60 °C
---------------------------------	-----------------

General

Color	blue
Components	Lead-free

Cable duct - CD 25X80 BU - 3240304

Technical data

General

Inflammability class according to UL 94	V0
Material	PVC

Classifications

eCl@ss

eCl@ss 4.0	27140602
eCl@ss 4.1	27140602
eCl@ss 5.0	27140602
eCl@ss 5.1	27140602
eCl@ss 6.0	27400703
eCl@ss 7.0	27400703
eCl@ss 8.0	27400703

ETIM

ETIM 2.0	EC000012
ETIM 3.0	EC000012
ETIM 4.0	EC000012
ETIM 5.0	EC000012

UNSPSC

UNSPSC 6.01	30101815
UNSPSC 7.0901	30101815
UNSPSC 11	30101815
UNSPSC 12.01	30101815
UNSPSC 13.2	30101815

Approvals

Approvals

Approvals

UL Recognized / VDE Zeichengenehmigung / CSA

Ex Approvals

Approvals submitted

Approval details

Cable duct - CD 25X80 BU - 3240304

Approvals

UL Recognized 

VDE Zeichengenehmigung 

CSA 

Accessories

Accessories

Cover

Cover profile - CD COVER 25 BU - 3240330



Cover for cable duct, blue, width: 25 mm, length: 2000 mm

Filler plug

Fastening clip - RVT-PA 4 - 3240498



Plastic body-bound rivet, for hole diameter of 4 mm and a material thickness of 1.5 ... 6 mm

Fastening clip - RVT-PA 6 - 3240499



Plastic body-bound rivet, for hole diameter of 6 mm and a material thickness of 1.5 ... 6 mm

Riveting tools

Cable duct - CD 25X80 BU - 3240304

Accessories

Tool - UNIFOX-RVT P 4 - 1212478



Rivet setting tool, for use with RVT-PA 4 plastic body-bound rivets


Tool - UNIFOX-RVT P 6 - 1212509



Rivet setting tool, for use with RVT-PA 6 plastic body-bound rivets

Drawings

Dimensioned drawing

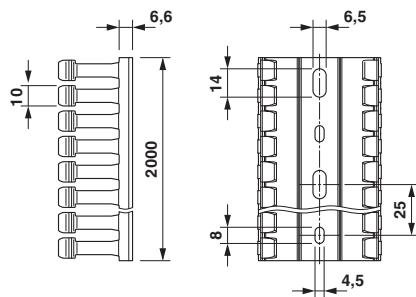

Base perforation according to DIN EN 50085