


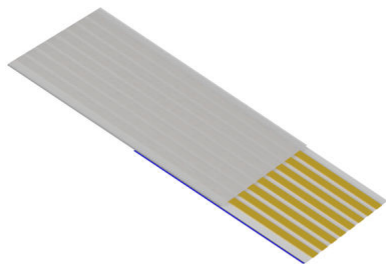

**Part Number :** [150200074](#)  
**Product Description :** 0.50mm Pitch Premo-Flex FFC  
Jumper, Opposite Side Contacts (Type D), 30.00mm  
Cable Length, Gold (Au) Plating, 8 Circuits  
**Series Number :** 15020  
**Status :** Active  
**Product Category :** Flat-Flexible Cable (FFC)



## Documents & Resources

### Drawings


- [150200074 sd.pdf](#)
- [STEP AP242](#)
- [SOLIDWORKS](#)
- [Creo](#)

### Specifications

- [PS-15020-001-001.pdf](#)

## Product Environment Compliance

### Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Reviewed per IEC 61249-2-21
REACH SVHC	Not Reviewed per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

### Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

### Industry Documents

- IPC 1752A Class C

- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

---

**Part Details**

**General**

Status	Active
Category	Flat-Flexible Cable (FFC)
Series	15020
Description	0.50mm Pitch Premo-Flex FFC Jumper, Opposite Side Contacts (Type D), 30.00mm Cable Length, Gold (Au) Plating, 8 Circuits
Comments	Contacts on opposite sides, Type D
Product Name	Premo-Flex FFC Jumper
UPC	884982175365

**Electrical**

Current - Maximum per Contact	0.5A
Voltage - Maximum	60V AC

**Physical**

Cable Length	30.00mm
Circuits (Loaded)	8
Contact Layout Type	D (opposite side)
Design Feature	Flexible
Material - Plating Mating	Gold
Net Weight	0.091/g
Packaging Type	Bag
Pitch - Mating Interface	0.50mm
Temperature Range - Operating	-40° to +105°C

Termination Style	FFC Connector
Wire/Cable Type	Flat Flex Cable
Wire Size (AWG)	N/A

---

## Mates With / Use With

### Mates with Part(s)

Description	Part Number
Easy-On FFC/FPC Connector, 0.50mm Pitch, V-Flip Series, Vertical, 4.05mm Height, 8 Circuits, Phosphor Bronze, Gold Plating	<a href="#"><u>5019510830</u></a>
Easy-On FFC/FPC Connector, 0.50mm Pitch, V-Flip Series, Vertical, 4.05mm Height, 8 Circuits, Copper Alloy, 125°C Operating Temperature, Gold Plating	<a href="#"><u>5019510850</u></a>
Easy-On FFC/FPC Connector, 0.50mm Pitch, FBH1 Series, Right-Angle, Dual Contact, 1.00mm Height, 8 Circuits, Gold over Nickel Plating	<a href="#"><u>5034800800</u></a>
Easy-On FFC/FPC Connector, 0.50mm Pitch, FD19 Series, Right-Angle, Bottom Contact, 1.90mm Height, 8 Circuits, Gold over Nickel Plating	<a href="#"><u>5051100892</u></a>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Vertical, 3.90mm Height, 8 Circuits, Gold Plating	<a href="#"><u>525590853</u></a>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Top Contact, 2.00mm Height, 8 Circuits, Gold Plating	<a href="#"><u>527450897</u></a>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Bottom Contact, 2.00mm Height, 8 Circuits, Gold Plating	<a href="#"><u>527460871</u></a>
0.50mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Right-	<a href="#"><u>512810898</u></a>

Angle, Non-ZIF, Dual Contact Style, 1.20mm Mated Height, 8 Circuits, Gold (Au) Plating	
0.50mm Pitch Easy-On FFC/FPC Connector, 1.20mm Height, Right- Angle, Surface Mount, ZIF, Bottom Contact Style, 8 Circuits, Gold (Au) Plating	<u>545480872</u>
0.50mm Pitch Easy-On FFC/FPC Connector, 1.20mm Height, Right- Angle, Surface Mount, ZIF, Top Contact Style, 8 Circuits, Gold (Au) Plating	<u>545500872</u>
0.50mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Vertical, Non-ZIF, Standard Footprint, Gold Plating, Black, 8 Circuits	<u>781190820</u>
0.50mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Vertical, Non-ZIF, Reverse Footprint, Gold Plating, Black, 8 Circuits	<u>781270820</u>
0.50mm Pitch Easy-On FFC/FPC Connector, 1.30mm Height, Right- Angle, Surface Mount, ZIF, Bottom Contact Style, 8 Circuits, Gold (Au) Contact Plating	<u>512960894</u>