


AR48 GY4 24V 20W 8D ALU 4000h 41930SP

Article number 20400040207

BAI AR48 GY4 24V 20W 8D Aluminum 4000h 48x36mm Low voltage halogen reflector lamp

Brilliant accent light with fitting for reduced glare. Excellent light distribution thanks to faceted reflector. UV filter. This lamp can be used in shops, restaurants, hotels, offices and public buildings.

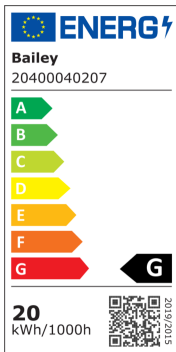

General ETIM properties

ETIM group	Lamps
ETIM class	Low voltage halogen reflector lamp
Name	20400040207
Brand	Bailey
Productseries	Halogen reflector
Product type	AR48

ETIM specifications

Lamp power [W]	20
Lamp voltage [V]	24 - 24
Socket	GY4
Beam angle [°]	8
Colour temperature [K]	2900
ANSI	Other
Infrared coating/-technique	No
Front glass	No
Diameter [mm]	48
Total length [mm]	36
Axial filament	No
Reflector type	Aluminium plated glass
Low-pressure technique	Yes
UV-protection	Yes
Luminous intensity [cd]	2400
Colour	White
Cool beam	No
Xenon	Yes
Neodym-lamp	No
Energy efficiency class	G
Weighted energy consumption in 1000 hours [kWh]	20
Average nominal lifespan [h]	4000
Lamp designation	AR48

Successor



146562

AR48 GY4 24V 20W
10D ALU Anti-Glare
2000h 41930SP