


Hex End Short L-Wrenches - ProGuard™

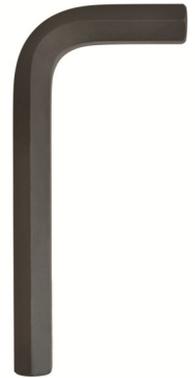

- Chamfered tool tips eliminate burrs and help tools seat in screw head
- Sharp corners transfer more torque to the screw and reduce stripping
- Precision machined for ease of use and superior fit



HighTorqueSteel

Up to 20% stronger, with more torque and twice the wear resistance of standard grades of steel



Corrosion-resistant finish: Environmentally safe, provides better tool grip, resists solvents and is 5 times more corrosion resistant than competitor finishes



SIZE INCH MM INCH MM PART#
SHORT Metric Singles

SIZE	INCH	MM	INCH	MM	PART#
0.71	1.2	31	0.22	6	12247
0.89	1.2	31	0.34	9	12248
1.27	1.6	42	0.53	13	12249
1.5	1.7	44	0.53	14	12250
2.0	1.9	49	0.61	16	12252
2.5	2.1	54	0.69	17	12254
3.0	2.4	61	0.75	19	12256
3.5	2.6	65	0.85	21	12258
4.0	2.7	68	0.87	22	12260
4.5	2.9	73	1.00	25	12262
5.0	3.1	78	1.06	27	12264
5.5	3.3	83	1.14	29	12266
6	3.5	88	1.22	31	12268
7	3.7	93	1.30	33	12270
8	3.9	98	1.38	35	12272
9	4.0	102	1.46	37	12274
10	4.3	109	1.54	39	12276
11	4.5	115	1.63	42	12278
12	4.8	122	1.73	44	12280
13	5.1	129	1.88	48	12282
14	5.4	136	2.15	55	12284
17	6.1	156	2.42	61	12286
19	6.9	175	2.72	69	12288
22	7.5	190	3.07	78	12291
24	8.4	213	3.47	88	12293
27	9.4	238	3.84	98	12295
32	11.8	300	4.80	122	12296
36	13.3	338	5.37	137	12298



SIZE INCH MM INCH MM PART#
SHORT Inch Singles

SIZE	INCH	MM	INCH	MM	PART#
.028	1.2	31	0.22	6	12200
.035	1.2	31	0.34	9	12201
.050	1.6	42	0.53	13	12202
1/16	1.8	45	0.56	14	12203
5/64	1.9	48	0.61	15	12204
3/32	2.0	51	0.65	16	12205
7/64	2.1	54	0.70	18	12206
1/8	2.3	58	0.75	19	12207
9/64	2.4	61	0.80	20	12208
5/32	2.5	64	0.84	21	12209
3/16	2.8	70	0.94	24	12210
7/32	3.0	77	1.03	26	12211
1/4	3.3	83	1.13	29	12212
5/16	3.8	96	1.25	32	12213
3/8	4.3	108	1.38	35	12214
7/16	4.8	121	1.50	38	12215
1/2	5.3	133	1.63	41	12216
9/16	5.8	146	1.75	44	12217
5/8	6.3	159	1.88	48	12218
3/4	7.3	184	2.13	54	12219
7/8	8.2	207	2.37	60	12220
1	9.2	232	2.62	67	12221
1 1/4	11.0	279	3.00	76	12225
1 1/2	13.0	330	3.50	89	12229
1 3/4	13.3	337	4.00	102	12231
2	15.0	381	4.50	114	12233

Bondhus Corporation

1400 E Broadway • PO Box 660 • Monticello, MN 55362

Tel: 763-295-2162 • Toll Free: 800-328-8310 • Fax: 763-295-4440

Bondhus, ProTanium, ProGuard, BriteGuard, GoldGuard and BallStar are trademarks of Bondhus Corporation.

TORX® and TORX PLUS® are registered trademarks of Acument Intellectual Properties, LLC.