


Deburring Blades

N80 M42 Blade

RS Stock No. [244-6739](#)

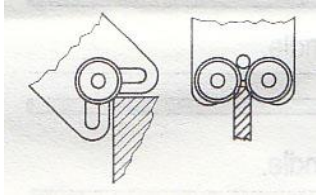

Unique round cutting blades can be rotated and reversed to provide long blade life
Suitable for use on stainless steel
Can be set to deburr sheet widths from 0-12mm
Blade material: HSS M42
Blade hardness: 65-67 HRC
Attached to Double Burr

Packed Weight and Dimensions:

Weight g	W mm	H mm	L mm
34	62	8	130