


SIVACON, Roof, Closed, IP55, W: 1200 mm, T: 800 mm, zinc-plated

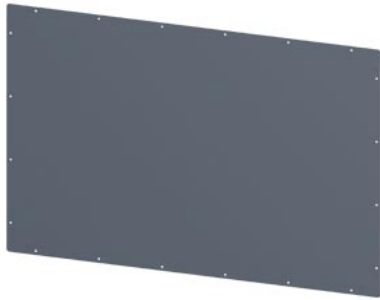

Model		
product brand name	SIVACON	
product designation	top plate	
design of the product	Closed	
design of the surface	zinc plated	
design of the product EMC version	No	
Protection class		
protection class IP	IP55	
Suitability		
suitability for use for outside use	No	
Product details		
product component		
• cable entry	No	
• ventilation	No	
Mechanical Design		
width	1 200 mm	
depth	800 mm	
net weight	11.65 kg	
material	steel	
Approvals Certificates		
General Product Approval		Test Certificates
		other



[Special Test Certificate](#)

[Confirmation](#)

[Miscellaneous](#)

other

Environment

[Miscellaneous](#)



[Environmental Confirmations](#)

Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1028-2UD11-0A>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8MF1028-2UD11-0A>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1028-2UD11-0A

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

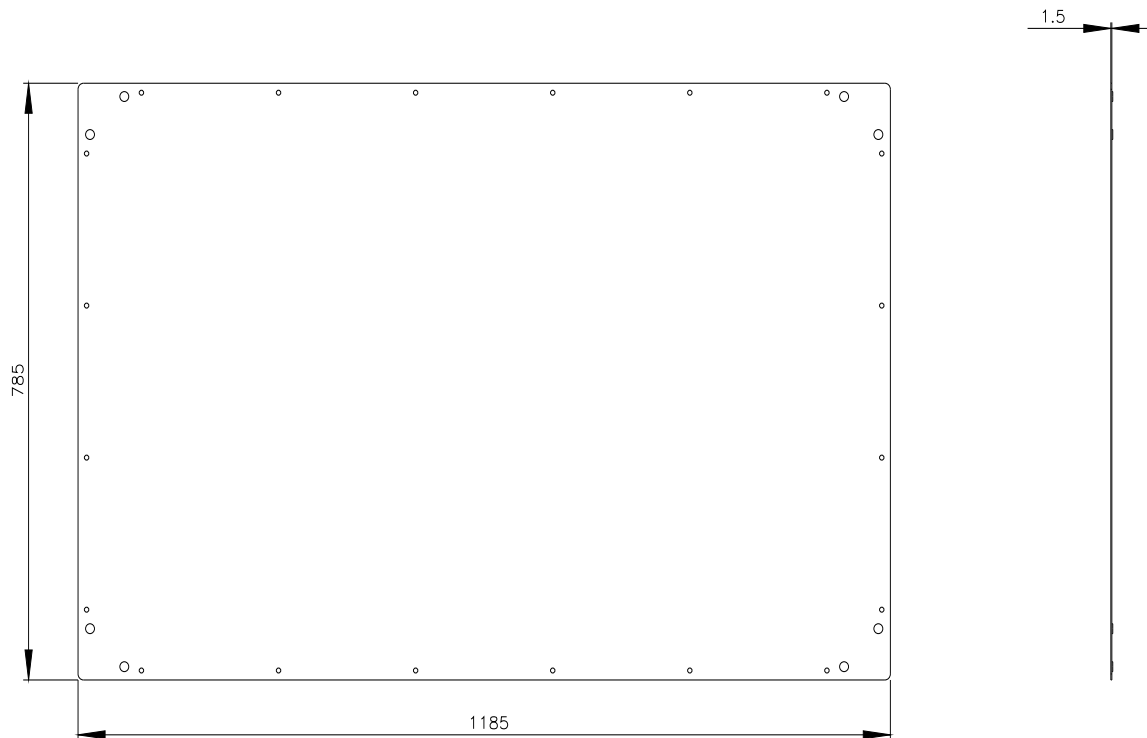

last modified:

7/24/2023 

