

Best of **Accessories**

October – December 2013

**Concrete
and Stone
programme**



Page 14 – 22

Promotions



Page 23 – 28

NEW! Bosch Safety Accessories –
safety at the work place



BOSCH

Invented for life

Table of contents



Safety Accessories	03
▶ Protective glasses	04
▶ Protective masks	07
▶ Ear protectors	09
▶ Hand protectors	11

Concrete and Stone programme	14
▶ Drilling	15
▶ Chiselling	21

Promotions	23
▶ 2-Step Solution grinding discs	24
▶ Screwdriver bit sets	26

New Bosch safety at work range – protection and wearer comfort



The work environment is not always free of dangers. Injuries in the eyes and ears as well as hearing loss or inhalation of harmful substances are the most common types of accidents at the workplace.

Safety products are needed! However, wearing safety products over a long period of time can be inconvenient and comfort plays a very important role in this.

Bosch safety products meet the strictest international standards and have been developed to provide exceptional wearer comfort.

Sales support

We prepared for you as sales support:

- ▶ Catalogue



Bosch protective glasses – the right protection for the human eye



Adjustable temple
▶ 100 % protection
▶ Perfect fit for comfort

In accordance with DIN EN 166
▶ Distortion-free view
▶ Exceptional longevity

Lens with nano-coating
▶ Scratch-resistant outside
▶ Anti-fog inside
▶ Easy to clean

Spectacles

<i>Tested to</i>	<i>Lens</i>	<i>Part number</i>	<i>Pack quantity</i>	<i>Minimum order quantity</i>	<i>Barcode</i> 3 165 140 ...
Product properties		Ordering information			

Spectacles GO 1C

- ▶ Ergonomically shaped lens, perfect side protection, wide field of vision
- ▶ Coating is scratch-resistant on both sides
- ▶ For use in assembly work and light duty tradesman work

EN 166	Polycarbonate colourless 100 % UV protection	2 607 990 071	1	1	711 883
EN 166	Polycarbonate colourless 100 % UV protection	2 607 990 072	1	5	711 890



Spectacles

Product properties		Ordering information			
Tested to	Lens	Part number	Pack quantity	Minimum order quantity	Barcode 3 165 140 ...

Spectacles GO 2C

- ▶ Large, distortion-free field of view, excellent ventilation
- ▶ Coating is scratch-resistant on the outside, non-fogging on the inside
- ▶ For use in light duty dust activities, sanding work, drilling and routing work

EN 166	Polycarbonate colourless 100% UV protection	2 607 990 073	1	1	711906
EN 166	Polycarbonate colourless 100% UV protection	2 607 990 074	1	5	711913



Spectacles GO 2G

- ▶ Large, distortion-free field of view, excellent ventilation
- ▶ Coating is scratch-resistant on the outside, non-fogging on the inside
- ▶ For use in light duty dust activities, sanding work, drilling and routing work
- ▶ Grey sun protection lens for perfect use outdoors

EN 166	Polycarbonate grey 100% UV protection Sun glare protection	2 607 990 075	1	1	711920
EN 166	Polycarbonate grey 100% UV protection Sun glare protection	2 607 990 076	1	5	711937



Spectacles GO 3C

- ▶ Metal-free protective glasses adapt perfectly to the face
- ▶ Ergonomic Softflex bridge pieces, Softflex nose loops and Softflex ear pieces also offer non-slip comfort
- ▶ Coating is scratch-resistant on the outside, non-fogging on the inside, easy to clean due to nanotechnology
- ▶ For use in all mechanical work, turning and routing work, and assembly work

EN 166	Polycarbonate colourless 100% UV protection	2 607 990 079	1	1	711968
EN 166	Polycarbonate colourless 100% UV protection	2 607 990 080	1	5	711975



Spectacles GO 3G

- ▶ Metal-free protective glasses adapt perfectly to the face
- ▶ Ergonomic Softflex bridge pieces, Softflex nose loops and Softflex ear pieces also offer non-slip comfort
- ▶ Coating is scratch-resistant on the outside, non-fogging on the inside, easy to clean due to nanotechnology
- ▶ Grey sun protection lens for perfect use outdoors

EN 166	Polycarbonate grey 100% UV protection Sun glare protection	2 607 990 081	1	1	711982
--------	--	---------------	---	---	--------



Spectacles

Product properties		Ordering information			
Tested to	Lens	Part number	Pack quantity	Minimum order quantity	Barcode 3 165 140 ...

Spectacles GO 3G

- ▶ Metal-free protective glasses adapt perfectly to the face
- ▶ Ergonomic Softflex bridge pieces, Softflex nose loops and Softflex ear pieces also offer non-slip comfort
- ▶ Coating is scratch-resistant on the outside, non-fogging on the inside, easy to clean due to nano-technology
- ▶ Grey sun protection lens for perfect use outdoors



EN 166	Polycarbonate grey 100 % UV protection Sun glare protection	2 607 990 082	1	5	711 999
--------	---	---------------	---	---	---------

Overspecs

Overspecs GO OG

- ▶ Lightweight overspecs with hinged side arms and unrestricted lateral vision
- ▶ Very comfortable and secure fit due to soft and “non-slip” ear piece
- ▶ Coating is extremely scratch-resistant on both sides, easy to clean due to nanotechnology
- ▶ For use by spectacle wearers in all mechanical work



EN 166	Polycarbonate colourless 100 % UV protection	2 607 990 083	1	1	712 002
EN 166	Polycarbonate colourless 100 % UV protection	2 607 990 084	1	5	712 019

Full vision goggles

Full vision goggles GO FV2

- ▶ Comfortable full vision goggles with hard/soft components for a pressure-free fit
- ▶ Suitable for spectacle wearers, low weight, optimum ventilation, panorama field of vision, synthetic headband
- ▶ For use in work subject to dust exposure and high mechanical strain such as cut-off grinding work, construction and renovation work, and work with chemicals



EN 166	Polycarbonate colourless 100 % UV protection	2 607 990 087	1	1	712 040
EN 166	Polycarbonate colourless 100 % UV protection	2 607 990 088	1	4	712 057

Bosch protective masks – effective protection that is comfortable to wear



Fine dust masks

Product properties		Ordering information			
Tested to	Protection class	Part number	Pack quantity	Minimum order quantity	Barcode 3165 140 ...

Fine dust mask MA C1

- ▶ Soft material edges and adjustable nose clip for a comfortable fit
- ▶ Additional sealing lip in nose area
- ▶ Seamless headband



EN 149	FFP1	2 607 990 089	3	1	712 064
EN 149	FFP1	2 607 990 090	20	1	712 071

Fine dust mask MA C2

- ▶ Soft material edges and adjustable nose clip for a comfortable fit
- ▶ Additional sealing lip in nose area
- ▶ Seamless headband
- ▶ Valve with 360-degree opening for minimal breathing resistance



EN 149	FFP2	2 607 990 091	2	1	712 088
EN 149	FFP2	2 607 990 092	15	1	712 095

Fine dust masks

Product properties		Ordering information				
Tested to	Protection class	Part number	Pack quantity	Minimum order quantity	Barcode 3 165 140 ...	



Fine dust mask MA F2

- ▶ Space-saving folding mask made of soft filter material
- ▶ Soft material edges and adjustable nose clip for a comfortable fit
- ▶ Additional sealing lip in nose area
- ▶ Seamless headband
- ▶ Valve with 360-degree opening for minimal breathing resistance

EN 149	FFP2	2 607 990 094	15	1	712 118
--------	------	---------------	----	---	---------



Fine dust mask MA C3

- ▶ Soft material edges and adjustable nose clip ensure maximum comfort
- ▶ All-round, wide sealing lip in nose area
- ▶ 4-point headband attachment for a secure fit
- ▶ Valve with 360-degree opening for minimal breathing resistance

EN 149	FFP3	2 607 990 095	1	1	712 125
EN 149	FFP3	2 607 990 096	10	1	712 132



Fine dust mask MA C33

- ▶ 3D breathing protection mask offers maximum safety
- ▶ Soft sealing lip ensures a perfect fit
- ▶ 3 large 360-degree valves ensure easy breathing – even when worn for extended periods
- ▶ Seamless headband

EN 149	FFP3	2 607 990 097	1	1	712 149
EN 149	FFP3	2 607 990 098	3	1	712 156

Bosch ear protectors – effective protection that is comfortable to wear



Ear plugs

Product properties	Tested to	Part number	Pack quantity	Minimum order quantity	Barcode 3 165 140 ...

Disposable ear plugs EP PL37

- ▶ Ergonomically pre-shaped disposable ear plugs with excellent voice recognition
- ▶ Ideal for use in extremely loud environments
- ▶ X-emboss for easy insertion and removal
- ▶ Very comfortable to wear, even for extended periods
- ▶ SNR 37 dB, H = 36 dB, M = 34 dB, L = 34 dB
- ▶ Available in pairs



EN 352	2 607 990 099	5	16	712 163
EN 352	2 607 990 100	50	1	712 170

Ear plugs

Product properties	Ordering information
	Tested to Part number Pack quantity Minimum order quantity Barcode 3 165 140 ...



Reusable ear plugs EP PLC27

- ▶ Reusable ear plugs with cord for use in areas with medium noise exposure
- ▶ Smooth, dirt-repellent surface for easy cleaning and repeated use
- ▶ Pocket box for hygienic storage of the ear plugs
- ▶ SNR 27 dB, H = 27 dB, M = 24 dB, L = 22 dB

EN 352	2 607 990 101	1	16	712 187
--------	---------------	---	----	---------

Earmuffs



Earmuffs EM 21

- ▶ Small, lightweight ear pieces
- ▶ Continuously variable head bar adjustment
- ▶ Head bar can be worn over head, on neck and under chin
- ▶ SNR 21 dB, H = 25 dB, M = 18 dB, L = 12 dB

EN 352	2 607 990 102	1	1	712 194
--------	---------------	---	---	---------



Earmuffs EM 27

- ▶ Foldable ear piece with high-quality steel head bar and dual suspension system
- ▶ Optimum protection and comfort, especially over extended periods
- ▶ Small ear pieces, especially lightweight
- ▶ SNR 27 dB, H = 31 dB, M = 24 dB, L = 16 dB

EN 352	2 607 990 103	1	1	712 200
--------	---------------	---	---	---------

Bosch hand protectors – protective gloves for optimum safety



Knitted glove with innovative coating

- ▶ For dry and wet applications
- ▶ Excellent sensitiveness
- ▶ Very good grip
- ▶ Breathable

Manufactured without harmful substances

- ▶ Allergy-free

Leather protective gloves

- ▶ High-quality leather protective gloves made of split leather or full-grain leather, rubberised fabric cuff for pulse protection
- ▶ **Properties:** high leather quality, supple leather, good workmanship on seams, tested for harmful substances
- ▶ **Application range:** all-round, transportation, assembly, heavy workpieces



Product properties		Ordering information			
Tested to	Size	Part number	Pack quantity	Minimum order quantity	Barcode 3 165 140...
Split cowhide leather protective gloves GL SL 10					
EN 388	10	2 607 990 104	1	1	712 217
EN 388	10	2 607 990 105	1	10	712 224
Split cowhide leather protective gloves GL SL 11					
EN 388	11	2 607 990 106	1	1	712 231
EN 388	11	2 607 990 107	1	10	712 248

Leather protective gloves



Product properties		Ordering information				
Tested to	Size	Part number	Pack quantity	Minimum order quantity	Barcode 3 165 140 ...	
Cowhide leather protective gloves GL FL 10						
EN 388	10	2 607 990 108	1	1	712 255	
EN 388	10	2 607 990 109	1	10	712 262	
Cowhide leather protective gloves GL FL 11						
EN 388	11	2 607 990 110	1	1	712 279	
EN 388	11	2 607 990 111	1	10	712 286	

Leather protective gloves

- ▶ Knitted gloves with innovative coating for dry and slightly damp areas, very good fit, sits on hand “like a second skin”
- ▶ **Properties:** excellent dexterity, little sweating, good slip resistance, dermatologically tested
- ▶ **Application range:** precision work, fine assembly work, loosening screws, setting tools



Precision gloves GL Ergo 8						
EN 388	8	2 607 990 112	1	1	712 293	
EN 388	8	2 607 990 113	1	10	712 309	
Precision gloves GL Ergo 9						
EN 388	9	2 607 990 114	1	1	712 316	
EN 388	9	2 607 990 115	1	10	712 323	
Precision gloves GL Ergo 10						
EN 388	10	2 607 990 116	1	1	712 330	
EN 388	10	2 607 990 117	1	10	712 347	

Cut protection gloves

- ▶ Knitted gloves with moisture-repellent coating
- ▶ **Properties:** very good dexterity, comfortable to wear due to bamboo fibre, little sweating, very high cut protection
- ▶ **Application range:** cut protection, working with metal (sheets), working with glass, assembly work with risk of cutting



Product properties		Ordering information			
Tested to	Size	Part number	Pack quantity	Minimum order quantity	Barcode 3 165 140 ...
Cut protection gloves GL Protect 8					
EN 388	8	2 607 990 118	1	1	712 354
EN 388	8	2 607 990 119	1	5	712 361
Cut protection gloves GL Protect 9					
EN 388	9	2 607 990 120	1	1	712 378
EN 388	9	2 607 990 121	1	5	712 385
Cut protection gloves GL Protect 10					
EN 388	10	2 607 990 122	1	1	712 392
EN 388	10	2 607 990 123	1	5	712 422

Set



Product properties	Ordering information			
	Part number	Pack quantity	Minimum order quantity	Barcode 3 165 140 ...
Set				
Consisting of:				
▶ Spectacles GO 1C				
▶ Reusable ear plugs EP PLC27				
▶ Fine dust mask MA F2				
▶ Precision gloves GL Ergo 9				
-	2607017183	1	1	712415

Concrete
and Stone
programme



Page 14 – 42



**The Concrete and Stone
programme**
for all applications

SDS plus-7 – better performance with the 5-cutter full tungsten carbide head

The 5-cutter full tungsten carbide head of the SDS plus-7 offers 3× lifetime (against 2-cutter drill bits) and reliability without jamming when drilling in concrete with rebar. Thanks to the 5 cutters, the SDS plus-7 has highest demolition power and with the optimised flute high drilling speed is reached.



Benefits

- ▶ With the SDS plus-7 I get a drill bit with a very long lifetime while delivering a constantly high performance even in rebar

activeteq
Active centring tip
for active cutting in
concrete

Fine grade high durable carbide
Long lifetime/
best wear resistance

Wear mark

The visibility of the wear mark indicates if the diameter of the hole is still in tolerance for metal anchor setting

5-cutter full head carbide, diffusion bonding technology

Shaped cutters for highest demolition force, exceptional lifetime and best wear resistance. No jamming in rebar

2+2 flute design

Vibration-optimised flute design for the best power transfer and speed

Special Offer

SDS plus-7

Up to - 10 %

SDS plus-7 hammer drill bits

plus-7

- ▶ Suitable for masonry, concrete and reinforced concrete
- ▶ Appropriate for all rotary hammers with SDS plus holder

long
LIFE **× 3** **fast**
DRILL



Diameter [mm]	Working length [mm]	Total length [mm]	Part number	Pack quantity	Minimum order quantity	Barcode 3 165 140 ...
Product properties			Ordering information			
5.0	50	110	2 608 585 023	1	1	439 909
5.0	100	160	2 608 585 024	1	1	439 916
5.0	150	210	2 608 585 025	1	1	439 923
5.5	50	110	2 608 585 026	1	1	439 930
5.5	100	160	2 608 585 027	1	1	439 947
6.0	50	115	2 608 585 028	1	1	439 954
6.0	100	165	2 608 585 029	1	1	439 961
6.0	150	215	2 608 585 030	1	1	439 978
6.0	200	265	2 608 585 031	1	1	439 985
6.5	50	115	2 608 585 032	1	1	439 992
6.5	100	165	2 608 585 033	1	1	440 004
6.5	200	265	2 608 585 035	1	1	440 028
6.5	250	315	2 608 587 171	1	1	604 895
7.0	50	115	2 608 585 036	1	1	440 035
7.0	100	165	2 608 585 037	1	1	440 042
7.0	150	215	2 608 585 943	1	1	522 175
8.0	50	115	2 608 585 038	1	1	440 059
8.0	100	165	2 608 585 039	1	1	440 066
8.0	150	215	2 608 585 040	1	1	440 073
8.0	200	265	2 608 585 041	1	1	440 080
8.0	250	315	2 608 587 172	1	1	604 901
8.0	300	365	2 608 585 042	1	1	440 097
8.0	400	465	2 608 585 043	1	1	440 103
10.0	50	115	2 608 585 044	1	1	440 110
10.0	100	165	2 608 585 045	1	1	440 127
10.0	150	215	2 608 585 046	1	1	440 134
10.0	200	265	2 608 585 047	1	1	440 141
10.0	250	315	2 608 587 173	1	1	604 918
10.0	300	365	2 608 585 048	1	1	440 158
10.0	400	465	2 608 585 049	1	1	440 165

SDS plus-7 hammer drill bits

plus-7



Diameter [mm]	Working length [mm]	Total length [mm]	Part number	Pack quantity	Minimum order quantity	Barcode 3165140 ...
Product properties			Ordering information			
12.0	100	165	2 608 585 050	1	1	440 172
12.0	150	215	2 608 585 051	1	1	440 189
12.0	200	265	2 608 585 052	1	1	440 196
12.0	300	365	2 608 585 053	1	1	440 202
12.0	400	465	2 608 585 054	1	1	440 219
14.0	100	165	2 608 585 944	1	1	522 182
14.0	150	215	2 608 585 945	1	1	522 199
14.0	200	265	2 608 585 946	1	1	522 205
14.0	300	365	2 608 585 947	1	1	522 212
14.0	400	465	2 608 585 948	1	1	522 229
15.0	100	165	2 608 587 178	1	1	605 601
15.0	200	265	2 608 587 179	1	1	605 618
16.0	150	215	2 608 587 180	1	1	605 625
16.0	200	265	2 608 587 181	1	1	605 632
16.0	400	465	2 608 587 182	1	1	605 649
18.0	200	250	2 608 586 719	1	1	564 434
18.0	400	450	2 608 586 720	1	1	564 441
20.0	200	250	2 608 586 721	1	1	564 458
20.0	400	450	2 608 586 722	1	1	564 465
22.0	200	250	2 608 586 723	1	1	564 472
22.0	400	450	2 608 586 724	1	1	564 489
24.0	400	450	2 608 586 725	1	1	564 496
25.0	400	450	2 608 586 726	1	1	564 502
28.0	400	450	2 608 586 727	1	1	564 519
30.0	400	450	2 608 586 728	1	1	564 526

Get up to - 10 % volume discount
for the listed SDS plus-7 drill bits

Order quantity	Volume discount
----------------	-----------------

Max. discount of -10% defined by PA,
other steps to be defined by CSO

CYL-9 Multi Construction – drilling in all kinds of materials

- ▶ **Suitable for** practically all materials in interior fitting work, e.g. concrete, masonry, brick, eternit, light building materials, multi-layer materials, ceramics and tiles, wood, plastic, sheet metals, aluminium
- ▶ Perfect results when drilling with or without impact
- ▶ Drill bit colour: blue, polished



Benefits

- ▶ With the CYL-9 Multi Construction, I can drill in all kinds of materials without changing the drill bit, even in very thick walls with insulation material



Special Offer

CYL-9 Multi Construction

Up to - 10 %

With the additional lengths of the CYL-9 Multi Construction, façade installations – even through insulated walls – can be done easily with one drill bit.

NEW! CYL-9 Multi Construction multi-purpose drill bits

- CYL-9 MultiConstruction** ▶ **Focus products**
 ▶ Insulation range – additional lengths



Diameter [mm]	Working length [mm]	Total length [mm]	Part number	Pack quantity	Minimum order quantity	Barcode 3 165 140 ...
Product properties			Ordering information			
3.0	80	130	2 608 588 196	1	5	693 158
3.5	40	70	2 608 588 197	1	5	693 165
3.5	80	130	2 608 588 198	1	5	693 172
4.0	80	130	2 608 588 199	1	5	693 189
5.0	90	150	2 608 588 200	1	5	693 196
5.0	200	250	2 608 588 241	1	1	773 010
5.5	100	150	2 608 588 201	1	5	693 202
6.0	350	400	2 608 588 202	1	1	693 219
10.0	350	400	2 608 588 203	1	1	693 226
12.0	350	400	2 608 588 204	1	1	693 233
14.0	150	200	2 608 588 205	1	1	693 240
14.0	350	400	2 608 588 206	1	1	693 257
16.0	150	200	2 608 588 207	1	1	693 264
16.0	350	400	2 608 588 208	1	1	693 271
18.0	150	200	2 608 588 209	1	1	693 288
18.0	350	400	2 608 588 210	1	1	693 295
20.0	150	200	2 608 588 211	1	1	693 301
20.0	350	400	2 608 588 212	1	1	693 318

CYL-9 Multi Construction multi-purpose drill bits

CYL-9 MultiConstruction



Diameter [mm]	Working length [mm]	Total length [mm]	Part number	Pack quantity	Minimum order quantity	Barcode 3 165 140 ...
Product properties			Ordering information			
3.0	40	70	2 608 595 359	1	5	328 753
4.0	40	75	2 608 596 050	1	5	044 790
5.0	50	85	2 608 596 051	1	5	044 806
5.5	50	85	2 608 596 052	1	5	044 813
6.0	60	100	2 608 596 053	1	5	044 820
6.0	90	150	2 608 596 060	1	5	044 899
6.0	200	250	2 608 595 506	1	1	366 465
6.5	60	100	2 608 596 059	1	5	044 837
6.5	90	150	2 608 596 061	1	5	044 905
6.5	200	250	2 608 595 507	1	1	366 472
7.0	60	100	2 608 596 054	1	5	044 844
7.0	90	150	2 608 596 076	1	5	046 978
7.0	200	250	2 608 595 508	1	1	366 489
8.0	80	120	2 608 596 055	1	5	044 851
8.0	90	150	2 608 585 223	1	5	462 242
8.0	200	250	2 608 596 062	1	1	044 912
8.0	350	400	2 608 595 361	1	1	328 777
9.0	80	120	2 608 596 056	1	5	044 868
10.0	80	120	2 608 596 057	1	5	044 875
10.0	90	150	2 608 585 224	1	5	462 259
10.0	200	250	2 608 596 063	1	1	044 929
11.0	90	150	2 608 595 360	1	5	328 760
12.0	90	150	2 608 596 058	1	5	044 882
12.0	200	250	2 608 596 064	1	1	044 936
14.0	200	250	2 608 596 065	1	1	044 943

Get up to - 10 % volume discount
for the listed CYL-9
Multi Construction drill bits

Order quantity	Volume discount
5	2%
20	10%

Max. discount of -10% defined by PA, other steps to be defined by CSO


The long life chisel programme – always the right chisel for each application



Benefits


- ▶ The long life chisels allow me to work more efficiently thanks to an up to 30% higher removal rate and 100% longer life time

Increased power output

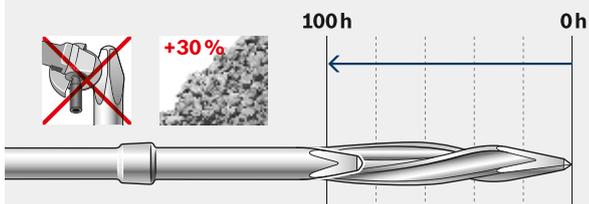

- ▶ No jamming
- ▶ Lifetime of 100 hours
- ▶ 30% higher material removal rate than standard pointed chisels

Double material removal rate

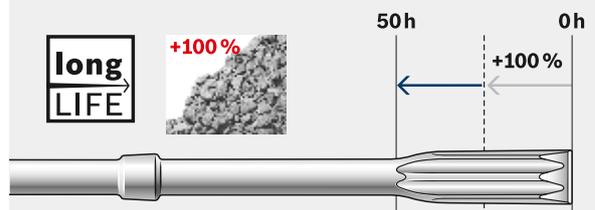


- ▶ 100% longer lifetime due to the new self-sharpening cutting edge. Therefore removes twice as much material



Special Offer

Up to - 10 %

 NEW! Chisels with SDS-max shank



► **Focus products:** chisels SDS-max shank



Total length [mm]	Chisel cutting edge [mm]	Part number	Pack quantity	Minimum order quantity	Barcode 3165 140 ...
Product properties		Ordering information			
40	80	2 608 690 198	1	1	670 135
40	115	2 608 690 199	1	1	670 142

NEW! Chisels with 22 mm hex shank



► **Focus products:** chisels hex shank
 ► **Appropriate for** TE-S system



Self-sharpening pointed chisel					
400	-	2 608 690 188	1	1	670 036



Self-sharpening flat chisel					
400	25	2 608 690 190	1	1	670 050



Self-sharpening spade chisel					
400	50	2 608 690 192	1	1	670 074
400	80	2 608 690 193	1	1	670 081
400	115	2 608 690 194	1	1	670 098



Excavation chisel					
400	125	2 608 690 195	1	1	670 104



Earth rod driver					
400	25	2 608 690 196	1	1	670 111



Toolholder for tamping plate					
400	-	2 608 690 197	1	1	670 128

Get up to - 10 % volume discount
 on the focus products
 and the whole chisel range

Order quantity	Volume discount
5	2%
20	10%

Max. discount of -10% defined by PA, other steps to be defined by CSO



Promotions



Page 23 – 28

2-Step Solution –
high-quality weld treatment

2-Step Solution – high-quality surface treatment

The Bosch 2-Step grinding system for angle grinders enables the user to efficiently grind weld seams and then produce an even surface in only two steps.

1st Step: Fibre disc



- ▶ **Removing** the weld seam as fast as with flap discs or bonded grinding wheels



2nd Step: SCM Fleece disc



- ▶ **Refining** the surface, even deep scratches without grinding off too much of the material
- ▶ **Benefit:** only two steps to an even and high-quality surface

SCM = Surface Conditioning Material



2-Step Solution

promotion offer

Up to - 10 %

Stainless steel (Inox)




Disc diameter [mm]	Bore diameter [mm]	Grit / Version	Max. speed [rpm]	Part number	Pack quantity	Minimum order quantity	Barcode 3165140...
Product properties				Ordering information			
Fibre sanding discs, Best for Inox – EN 13743							
125	22.23	80	12,250	2 608 608 313	1	50	607 032
SCM fleece disc, Best for Inox, 50 m/s							
125	22.23	Coarse	7,650	2 608 607 636	2	5	528 764

Carbon steel



Fibre sanding discs, Best for Metal – EN 13743							
125	22.23	36	12,250	2 608 607 255	1	50	247 924
SCM fleece disc, Best for Inox, 50 m/s							
125	22.23	Extra coarse	7,650	2 608 607 635	2	5	528 757

Aluminium

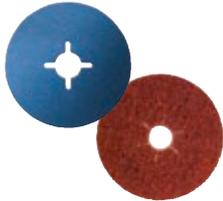

Fibre sanding discs, Best for Metal – EN 13743							
125	22.23	60	12,250	2 608 606 733	1	50	179 980
SCM fleece disc, Best for Inox, 50 m/s							
125	22.23	Medium	7,650	2 608 607 637	2	5	528 771

Get up to 10 % discount

on the combined order of Fibre disc and SCM Fleece disc


Fibre disc order quantity	SCM Fleece disc order quantity	Total discount
50 pcs 1 × 50 pcs pack	10 pcs 5 × 2 pcs pack	5 %
100 pcs 2 × 50 pcs pack	20 pcs 10 × 2 pcs pack	10 %

NEW! Save 10 %

on the new 37-piece screwdriver bit set

- 10 %

- ▶ This one set replaces 36 individual hand screwdrivers
- ▶ Huge versatility: fits all available types of screws in the market
- ▶ Compact set case with ergonomically designed hand screwdriver
- ▶ Competitive pricing: more value for money for the customer

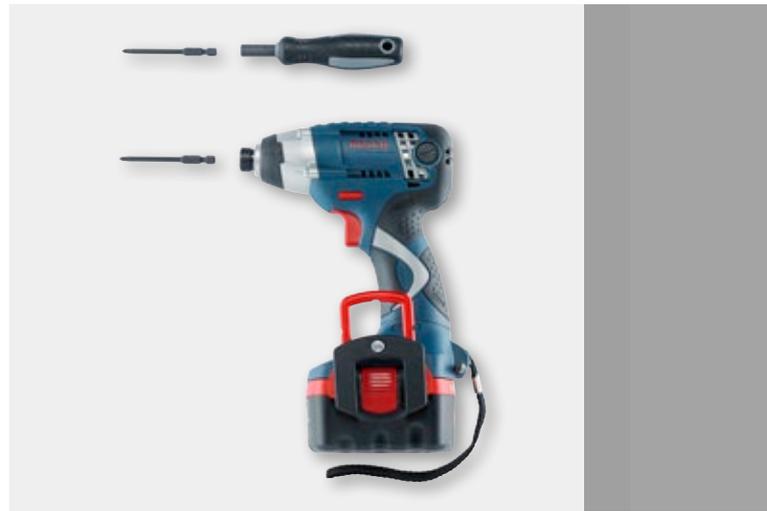

Ideal for the use with handle and power tool

Product description	Set contents	Length [mm]	Part number	Pack quantity	Minimum order quantity	Barcode 3 165 140 ...	Standard price without VAT	Special price without VAT
Product properties								
37-piece screwdriver bit set	+ PH1, PH2, PH3 + PZ1, PZ2, PZ3 * T8, T10, T15, T20, T25, T27, T30, T40 ● S0.6×5, S1×6 ○ HEX2, HEX2.5, HEX3, HEX4, HEX5, HEX6 + TS6, TS8, TS10 ● TW1, TW2, TW3, TW4 ● SP4, SP6, SP8, SP10 □ R1, R2, R3	75	2607 017 320	37	1	761987	XX.XX	XX.XX
	Hand screwdriver							

Now on stock!

43-piece screwdriver bit set

- ▶ Compact size
- ▶ Covers the most screwdriving applications
- ▶ Attractive colour coding
- ▶ Competitive pricing



Product description	Set contents	Length [mm]	Part number	Pack quantity	Minimum order quantity	Barcode 3 165 140 ...	Price without VAT
Product properties			Ordering information				
43-piece screwdriver bit set with quick-change universal holder and magnetic universal holder	<ul style="list-style-type: none">  PH1, PH2 (2×), PH3  PZ1, PZ2 (2×), PZ3  S3, S4, S5, S6  HEX3, HEX4, HEX5, HEX6  T10, T15, T20 (2×), T25, T27, T30, T40  TH10, TH15, TH20 (2×), TH25, TH27, TH30, TH40  PH2  PZ2  S6  T15, T20, T25 Nutsetter with permanent magnet for 6 mm, 8 mm, 10 mm hex screws 	<ul style="list-style-type: none"> 25 25 25 25 25 25 75 75 75 75 48–50 	2607 017 164	43	6	669 702	XX.XX


Now on stock!


11+1-piece screwdriver bit set in different configurations


- ▶ Pocket size
- ▶ Available as Max Grip and Extra Hard
- ▶ Priced below DeWalt, Metabo, Wera and Wiha



Product description	Set contents	Length [mm]	Part number	Pack quantity	Minimum order quantity	Barcode 3165 140 ...	Price without VAT
Product properties		Ordering information					
11+1-piece screwdriver bit sets							
Max Grip version with quick-change universal holder	 PH1, PH2, PH3  PZ1, PZ2, PZ3	25	2 608 522 126	12	10	704 250	XX.XX
Extra Hard version with quick-change universal holder	 T10, T15, T20, T25, T30		2 608 522 129	12	10	704 281	XX.XX
Max Grip version with magnetic universal holder			2 608 522 132	12	10	704 311	XX.XX
Max Grip version with quick-change universal holder	 PH1, PH2, PH3  PZ1, PZ2, PZ3	25	2 608 522 127	12	10	704 267	XX.XX
Extra Hard version with quick-change universal holder	 S0.6×4.5, S0.8×5.5  T15, T20, T25		2 608 522 130	12	10	704 298	XX.XX
Max Grip version with magnetic universal holder			2 608 522 133	12	10	704 328	XX.XX
Max Grip version with quick-change universal holder	 PH2  PZ2	25	2 608 522 128	12	10	704 274	XX.XX
Extra Hard version with quick-change universal holder	 S0.6×4.5, S0.8×5.5  HEX3, HEX4, HEX5		2 608 522 131	12	10	704 304	XX.XX
Max Grip version with magnetic universal holder	 T10, T15, T20, T25		2 608 522 134	12	10	704 335	XX.XX

 

 

 



Bosch Customer Service **01895 838791**

This number connects you to the Bosch Customer Service Team. It is there to answer your questions about technical matters and for customer service – quick and user-friendly. Outside office hours an answerphone will take your message.

Imprint

Publisher

Y. XXXXXXXX

Editor

Y. XXXXXXXX

Address

Robert Bosch GmbH
XXXXXX XXXXXXXX
YYYY YYYYYYYYYYYY
www.bosch.com

Edition

1

**Content
to be adapted
locally**

Dealer contact details



BOSCH

Invented for life