

HC-STA-RJ45PC-HT-M20-PLRBK - Connector set



1249556

<https://www.phoenixcontact.com/in/products/1249556>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Connector set, material: PA, cable outlet: straight, with slotted seal, with adapter for patch cables

Your advantages

- Lower costs than metal version
- Labeling option using 9 x 20 mm marking label
- Low weight
- Lower risk of condensation

Commercial data

Item number	1249556
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	*****
Product key	AF7AFX
GTIN	4063151353667
Weight per piece (including packing)	31.2 g
Weight per piece (excluding packing)	31 g
Customs tariff number	85366990
Country of origin	CN

HC-STA-RJ45PC-HT-M20-PLRBK - Connector set



1249556

<https://www.phoenixcontact.com/in/products/1249556>

Set consists of

HC-Q-I-RJ45-AD-PC-M - Contact insert

1077120

<https://www.phoenixcontact.com/in/products/1077120>



Contact insert, number of positions: RJ45, size: D7, type : RJ45, Pin, 50 V, 1 A, application: Data, Adapter for patch cables

HC-STA-D07-HHFS-1TGM20-PL-BK - Housing

1419255

<https://www.phoenixcontact.com/in/products/1419255>



Sleeve housing D7, for single locking latch, material: PA, cable outlets: 1, straight, 1x M20, height: 77.6 mm, cable gland: with, Standard

Technical data

Notes

General	Connectors may be operated only when there is no load/voltage.
---------	--

Product properties

Product type	Connector set
Series	HC-D
Type	D7
Type of the screw connection	1x M20
Cable outlet	straight

Insulation characteristics

Degree of pollution	3
---------------------	---

Material specifications

Flammability rating according to UL 94	V0
Seal material	NBR
Housing material	PA
Contact carrier material	PC

Cable/line

External cable diameter	4 mm ... 7 mm
-------------------------	---------------

Mechanical properties

Mechanical data

Type of the screw connection	1x M20
------------------------------	--------

Environmental and real-life conditions

Ambient conditions

Degree of protection	IP66
Impact strength	IK06
Ambient temperature (operation)	-25 °C ... 60 °C

Mounting

Mounting type	Latching with lower housing part
---------------	----------------------------------

HC-STA-RJ45PC-HT-M20-PLRBK - Connector set


1249556

<https://www.phoenixcontact.com/in/products/1249556>



Drawings

Dimensional drawing

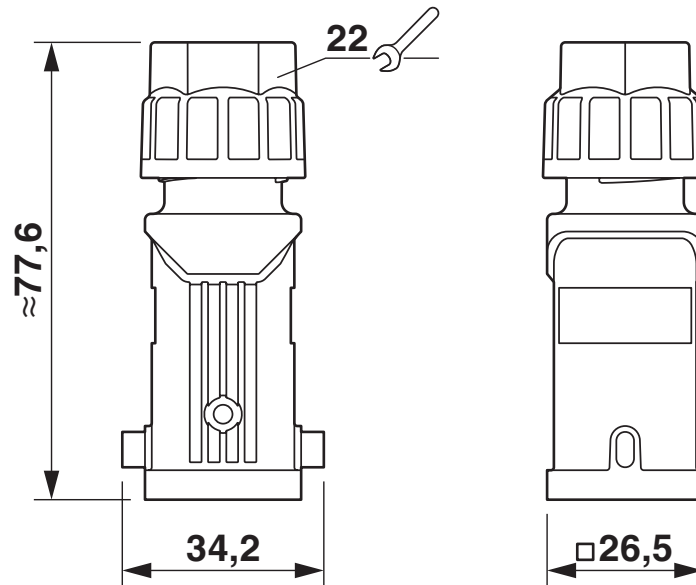

Dimensional drawing

HC-STA-RJ45PC-HT-M20-PLRBK - Connector set



1249556

<https://www.phoenixcontact.com/in/products/1249556>

Classifications

ECLASS

ECLASS-11.0	27440101
ECLASS-12.0	27440113
ECLASS-13.0	27440113

ETIM

ETIM 9.0	EC002636
----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

HC-STA-RJ45PC-HT-M20-PLRBK - Connector set



1249556

<https://www.phoenixcontact.com/in/products/1249556>

Accessories

HC-STA-RJ45GC-BWSC-PLRBK - Connector set

1249559

<https://www.phoenixcontact.com/in/products/1249559>

Connector set, number of positions: 8, CAT6, material: PA, Gender changer



HC-STA-RJ45GC-BWSC-ELAL - Connector set

1249560

<https://www.phoenixcontact.com/in/products/1249560>

Connector set, number of positions: 8, CAT6, material: Die-cast aluminum, salt water resistant, Gender changer



HC-STA-RJ45PC-HT-M20-PLRBK - Connector set

1249556

<https://www.phoenixcontact.com/in/products/1249556>



FL CAT5 PATCH 0,3 - Patch cable

2832250

<https://www.phoenixcontact.com/in/products/2832250>

Patch cable, CAT5, assembled, 0.3 m



FL CAT5 PATCH 0,5 - Patch cable

2832263

<https://www.phoenixcontact.com/in/products/2832263>

Patch cable, CAT5, assembled, 0.5 m



HC-STA-RJ45PC-HT-M20-PLRBK - Connector set

1249556

<https://www.phoenixcontact.com/in/products/1249556>



FL CAT5 PATCH 1,0 - Patch cable

2832276

<https://www.phoenixcontact.com/in/products/2832276>

Patch cable, CAT5, assembled, 1 m



FL CAT5 PATCH 1,5 - Patch cable

2832221

<https://www.phoenixcontact.com/in/products/2832221>

Patch cable, CAT5, assembled, 1.5 m



HC-STA-RJ45PC-HT-M20-PLRBK - Connector set

1249556

<https://www.phoenixcontact.com/in/products/1249556>



FL CAT5 PATCH 2,0 - Patch cable

2832289

<https://www.phoenixcontact.com/in/products/2832289>

Patch cable, CAT5, assembled, 2 m



FL CAT5 PATCH 3,0 - Patch cable

2832292

<https://www.phoenixcontact.com/in/products/2832292>

Patch cable, CAT5, assembled, 3 m



HC-STA-RJ45PC-HT-M20-PLRBK - Connector set

1249556

<https://www.phoenixcontact.com/in/products/1249556>



FL CAT5 PATCH 5,0 - Patch cable

2832580

<https://www.phoenixcontact.com/in/products/2832580>

Patch cable, CAT5, assembled, 5 m



FL CAT5 PATCH 7,5 - Patch cable

2832616

<https://www.phoenixcontact.com/in/products/2832616>

Patch cable, CAT5, assembled, 7.5 m



HC-STA-RJ45PC-HT-M20-PLRBK - Connector set

1249556

<https://www.phoenixcontact.com/in/products/1249556>



FL CAT5 PATCH 10,0 - Patch cable

2832629

<https://www.phoenixcontact.com/in/products/2832629>

Patch cable, CAT5, assembled, 10 m



FL CAT6 PATCH 0,3 - Patch cable

2891181

<https://www.phoenixcontact.com/in/products/2891181>

Patch cable, degree of protection: IP20, cable length: 0.3 m, number of positions: 8, 1 Gbps, CAT6, Ethernet



HC-STA-RJ45PC-HT-M20-PLRBK - Connector set



1249556

<https://www.phoenixcontact.com/in/products/1249556>

FL CAT6 PATCH 0,5 - Patch cable

2891288

<https://www.phoenixcontact.com/in/products/2891288>



Patch cable, degree of protection: IP20, cable length: 0.5 m, number of positions: 8, 1 Gbps, CAT6, Ethernet

FL CAT6 PATCH 1,0 - Patch cable

2891385

<https://www.phoenixcontact.com/in/products/2891385>



Patch cable, degree of protection: IP20, cable length: 1 m, number of positions: 8, 1 Gbps, CAT6, Ethernet

HC-STA-RJ45PC-HT-M20-PLRBK - Connector set



1249556

<https://www.phoenixcontact.com/in/products/1249556>

FL CAT6 PATCH 1,5 - Patch cable

2891482

<https://www.phoenixcontact.com/in/products/2891482>



Patch cable, degree of protection: IP20, cable length: 1.5 m, number of positions: 8, 1 Gbps, CAT6, Ethernet

FL CAT6 PATCH 2,0 - Patch cable

2891589

<https://www.phoenixcontact.com/in/products/2891589>



Patch cable, degree of protection: IP20, cable length: 2 m, number of positions: 8, 1 Gbps, CAT6, Ethernet

HC-STA-RJ45PC-HT-M20-PLRBK - Connector set



1249556

<https://www.phoenixcontact.com/in/products/1249556>

FL CAT6 PATCH 3,0 - Patch cable

2891686

<https://www.phoenixcontact.com/in/products/2891686>



Patch cable, degree of protection: IP20, cable length: 3 m, number of positions: 8, 1 Gbps, CAT6, Ethernet

FL CAT6 PATCH 5,0 - Patch cable

2891783

<https://www.phoenixcontact.com/in/products/2891783>



Patch cable, degree of protection: IP20, cable length: 5 m, number of positions: 8, 1 Gbps, CAT6, Ethernet

HC-STA-RJ45PC-HT-M20-PLRBK - Connector set



1249556

<https://www.phoenixcontact.com/in/products/1249556>

FL CAT6 PATCH 7,5 - Patch cable

2891880

<https://www.phoenixcontact.com/in/products/2891880>



Patch cable, degree of protection: IP20, cable length: 7.5 m, number of positions: 8, 1 Gbps, CAT6, Ethernet

FL CAT6 PATCH 10 - Patch cable

2891877

<https://www.phoenixcontact.com/in/products/2891877>



Patch cable, degree of protection: IP20, cable length: 10 m, number of positions: 8, 1 Gbps, CAT6, Ethernet

HC-STA-RJ45PC-HT-M20-PLRBK - Connector set



1249556

<https://www.phoenixcontact.com/in/products/1249556>

FL CAT6 PATCH 12,5 - Patch cable

2891369

<https://www.phoenixcontact.com/in/products/2891369>



Patch cable, degree of protection: IP20, cable length: 12.5 m, number of positions: 8, 1 Gbps, CAT6, Ethernet

FL CAT6 PATCH 15,0 - Patch cable

2891372

<https://www.phoenixcontact.com/in/products/2891372>



Patch cable, degree of protection: IP20, cable length: 15 m, number of positions: 8, 1 Gbps, CAT6, Ethernet

HC-STA-RJ45PC-HT-M20-PLRBK - Connector set



1249556

<https://www.phoenixcontact.com/in/products/1249556>

FL CAT6 PATCH 20,0 - Patch cable

2891576

<https://www.phoenixcontact.com/in/products/2891576>




Patch cable, degree of protection: IP20, cable length: 20 m, number of positions: 8, 1 Gbps, CAT6, Ethernet

NBC-R4AC1/0,3-94G/R4AC1-BU - Patch cable

1413158

<https://www.phoenixcontact.com/in/products/1413158>

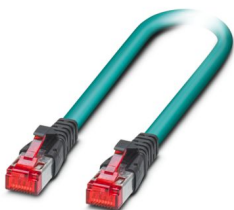

Patch cable, degree of protection: IP20, cable length: 0.3 m, number of positions: 8, 10 Gbps, CAT6_A, connection method: Pierce connection, Ethernet

HC-STA-RJ45PC-HT-M20-PLRBK - Connector set




1249556

<https://www.phoenixcontact.com/in/products/1249556>

NBC-R4AC1/0,5-94G/R4AC1-BU - Patch cable

1413159

<https://www.phoenixcontact.com/in/products/1413159>

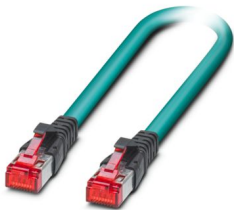


Patch cable, degree of protection: IP20, cable length: 0.5 m, number of positions: 8, 10 Gbps, CAT6_A, connection method: Pierce connection, Ethernet

NBC-R4AC1/1,0-94G/R4AC1-BU - Patch cable

1413160

<https://www.phoenixcontact.com/in/products/1413160>

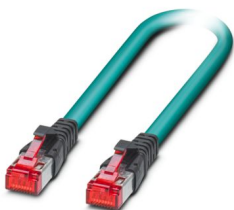

Patch cable, degree of protection: IP20, cable length: 1 m, number of positions: 8, 10 Gbps, CAT6_A, connection method: Pierce connection, Ethernet

HC-STA-RJ45PC-HT-M20-PLRBK - Connector set




1249556

<https://www.phoenixcontact.com/in/products/1249556>

NBC-R4AC1/2,0-94G/R4AC1-BU - Patch cable

1413161

<https://www.phoenixcontact.com/in/products/1413161>

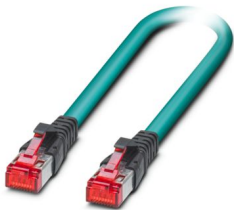


Patch cable, degree of protection: IP20, cable length: 2 m, number of positions: 8, 10 Gbps, CAT6_A, connection method: Pierce connection, Ethernet

NBC-R4AC1/3,0-94G/R4AC1-BU - Patch cable

1413162

<https://www.phoenixcontact.com/in/products/1413162>

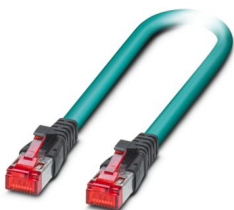

Patch cable, degree of protection: IP20, cable length: 3 m, number of positions: 8, 10 Gbps, CAT6_A, connection method: Pierce connection, Ethernet

HC-STA-RJ45PC-HT-M20-PLRBK - Connector set




1249556

<https://www.phoenixcontact.com/in/products/1249556>

NBC-R4AC1/5,0-94G/R4AC1-BU - Patch cable

1413163

<https://www.phoenixcontact.com/in/products/1413163>

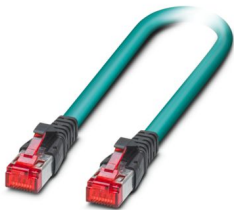


Patch cable, degree of protection: IP20, cable length: 5 m, number of positions: 8, 10 Gbps, CAT6_A, connection method: Pierce connection, Ethernet

NBC-R4AC1/10,0-94G/R4AC1-BU - Patch cable

1413164

<https://www.phoenixcontact.com/in/products/1413164>

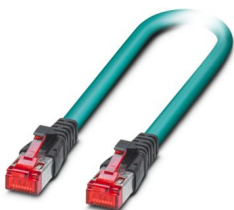

Patch cable, degree of protection: IP20, cable length: 10 m, number of positions: 8, 10 Gbps, CAT6_A, connection method: Pierce connection, Ethernet

HC-STA-RJ45PC-HT-M20-PLRBK - Connector set




1249556

<https://www.phoenixcontact.com/in/products/1249556>

NBC-R4AC1/15,0-94G/R4AC1-BU - Patch cable

1413165

<https://www.phoenixcontact.com/in/products/1413165>

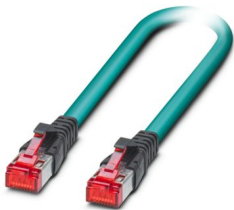


Patch cable, degree of protection: IP20, cable length: 15 m, number of positions: 8, 10 Gbps, CAT6_A, connection method: Pierce connection, Ethernet

NBC-R4AC1/20,0-94G/R4AC1-BU - Patch cable

1413166

<https://www.phoenixcontact.com/in/products/1413166>

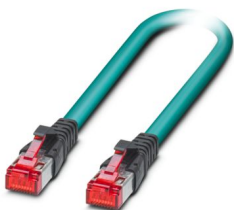

Patch cable, degree of protection: IP20, cable length: 20 m, number of positions: 8, 10 Gbps, CAT6_A, connection method: Pierce connection, Ethernet

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.

A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420

info@phoenixcontact.co.in