


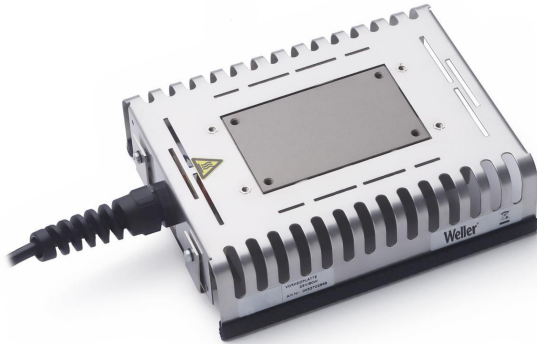

WHP80

Item No: T0052702899N

Preheating plate 80 W, 24 V, 80 x 50 mm

KEY FEATURES

- + 80 W, 24 V
- + Heating surface 80 x 50 mm
- + Temperature range 50 °C - 200 °C
- + For all Weller stations with min. 80 W
- + Size housing 150 x 120 x 65 mm
- + Electrostatic safety certification

TECHNICAL DATA

Height	45mm
Length	175mm
Dimensions L x W x H	175.0 x 125.0 x 45.0mm
ESD Safe	Yes
Heating Plate Dimensions	80.0 x 50.0mm
Power	80 W
Supply Unit	PU81 PUD81 PUD81i PUWAD101 PUD121 PUWAD101IG PUD151 WD1 WD1M WR2 WR3M WR3ME
Temperature Range (Depends on Tool)	65 - 204°C
Temperature Range °C	65 - 204 °C
Temperature Range °F	150 - 400 °F
Tip Type	WT
UPC	037103303011
Works With	PU81 PUD81 PUD81i PUWAD101 PUD121 PUWAD101IG PUD151 WD1 WD1M WR2 WR3M WR3ME WT1H WT2M
Product Family	Pre-Heating Plates