


Series AS1

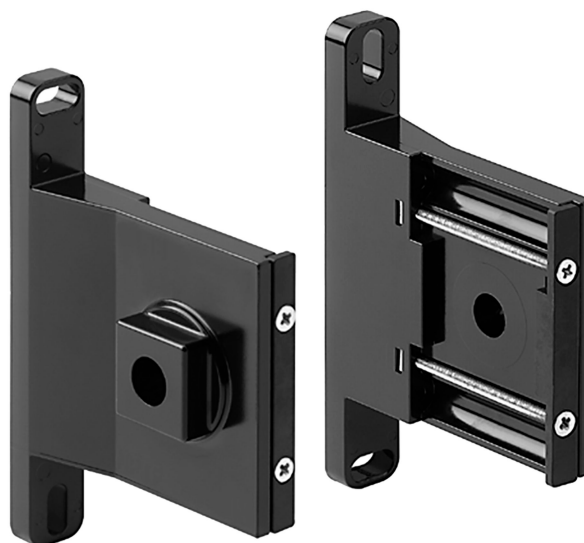

Technical data

Industry

Industrial

Port

G 1/8

Min. ambient temperature

-10 °C

Max. ambient temperature

50 °C

Weight

0.403 kg

Housing material

Die cast zinc

Surface housing

black painted


Seal material

Acrylonitrile butadiene rubber

R412014753

Dimensions in mm

Fig. 2

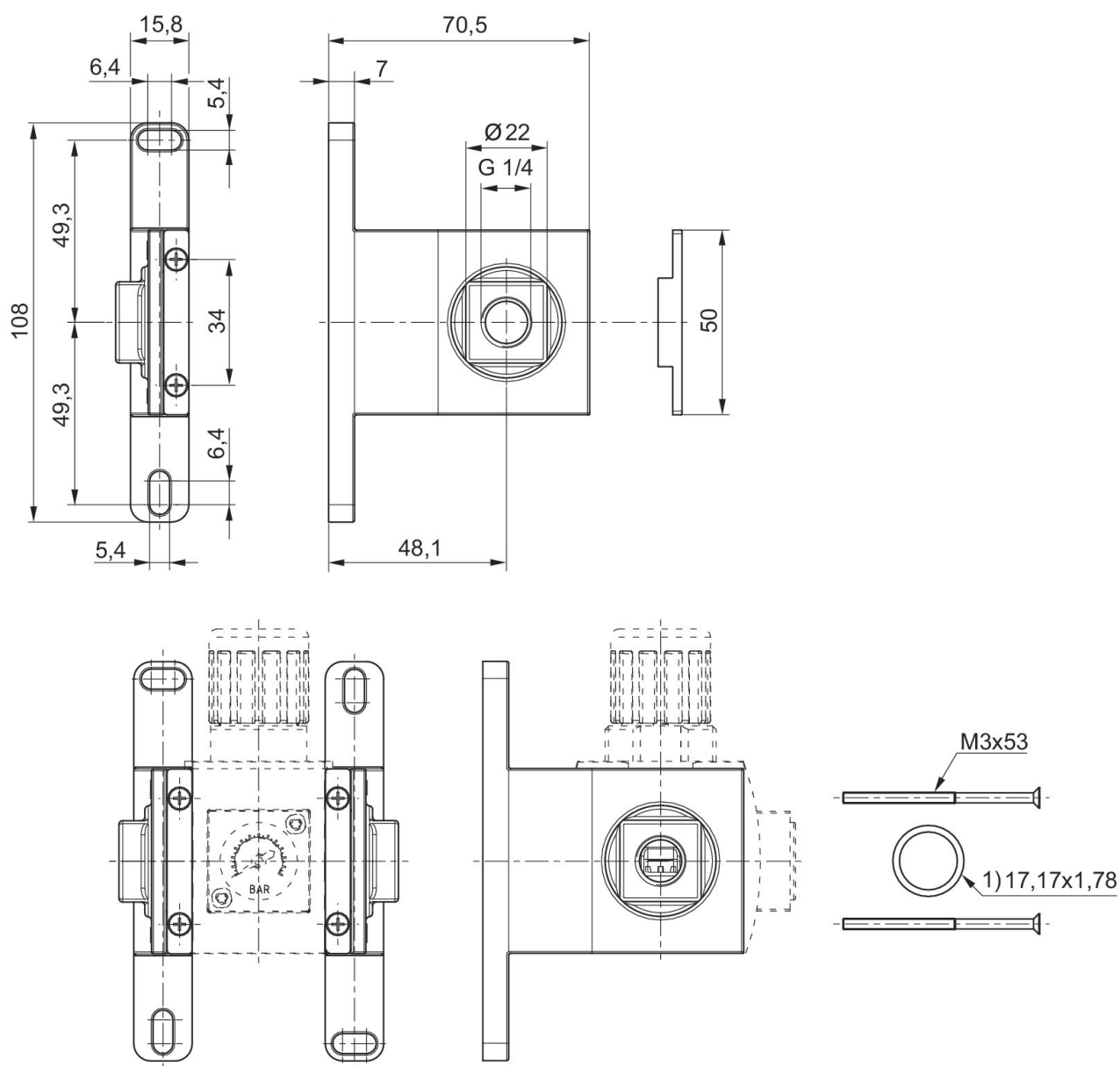


1) Scope of delivery incl. 4 mounting screws M3x53-4.8-A2R according to EN ISO 7046-1 (countersunk screw with type H X-slot), 2x O-ring

Dimensions in mm

R412014753

Fig. 1

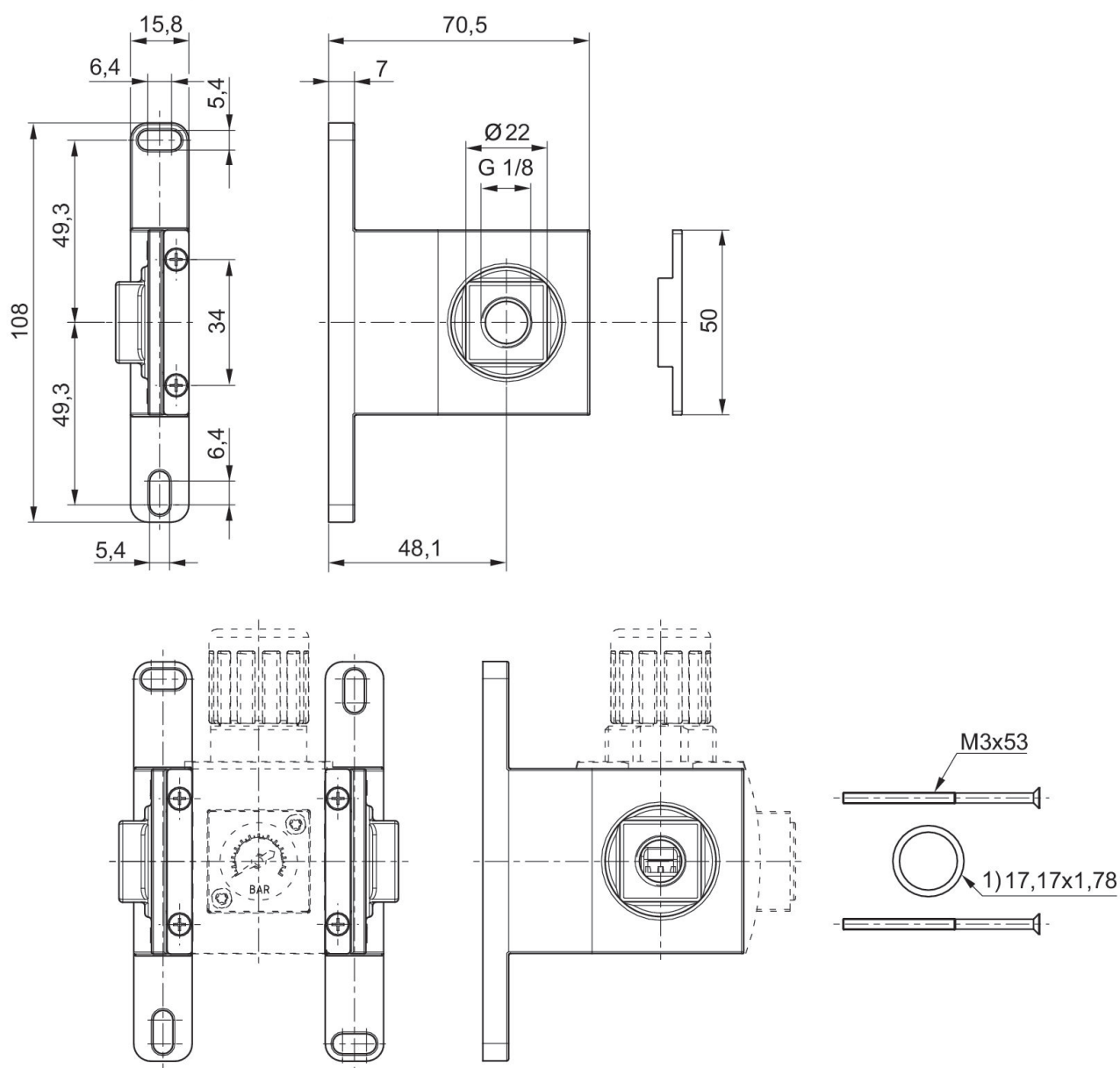

1) Scope of delivery incl. 4 mounting screws M3x53-4.8-A2R according to EN ISO 7046-1 (countersunk screw with type H X-slot), 2x O-ring