

T8 Luxline® Plus

F18W/865

0001502



Range features



PRODUCT OVERVIEW

Light colour	860 Daylight
Technology	Fluorescent
Ordering number	0001502
Energy class	A
Lamp shape	Linear
Lamp finish	Frosted
Dimmable	Yes
Cap/Base	G13
Type	T8 Luxline Plus
EAN code	5410288015026
CRI (Ra)	85
Colour temperature (K)	6000
Luminous flux (Rated) (lm)	1300
Efficacy (Rated) 100h (lm/W)	72
Watt (Nominal) (W)	18
Voltage (V)	57

T8 Luxline® Plus

F18W/865

0001502

DATA TABLE

General data

Technology	Fluorescent
Ordering number	0001502
Average life (Nominal) (h)	20000
Energy class	A
Lamp shape	Linear
Lamp finish	Frosted
Dimmable	Yes
Cap/Base	G13
Type	T8 Luxline Plus
EAN code	5410288015026
E-number FI	4940170
E-number SE	8356588
Product name	F18W/865
Lamp mercury content (mg)	2.8
Control gear required	Yes
Fixture rating	Open
IEC Reference	IEC 60081
IEC Reference 2	IEC 61195
Intended purpose	General lighting
Special purpose lamp	No
Transformer required	No
Sales pack quantity	25
Rated survival factor at 2000 h 50Hz	0.99
Rated survival factor at 4000 h 50Hz	0.98
Rated survival factor at 6000 h 50Hz	0.96
Rated survival factor at 8000 h 50Hz	0.94
Rated survival factor at 12000 h 50Hz	0.92
Rated survival factor at 16000 h 50Hz	0.8
Rated survival factor at 20000 h 50Hz	0.5

T8 Luxline® Plus

F18W/865

0001502

Optical data

Light colour	860 Daylight
CRI (Ra)	85
Colour temperature (K)	6000
Luminous flux (Rated) (lm)	1300
Luminous flux (Nominal) (lm)	1300
Ambient temperature for maximum luminous flux (°C)	25
Rated lumen maint. factor at 2000 h 50Hz	0.96
Rated lumen maint. factor at 4000 h 50Hz	0.94
Rated lumen maint. factor at 6000 h 50Hz	0.92
Rated lumen maint. factor at 8000 h 50Hz	0.91
Rated lumen maint. factor at 12000 h 50Hz	0.9
Rated lumen maint. factor at 16000 h 50Hz	0.89
Rated lumen maint. factor at 20000 h 50Hz	0.87

Electrical data

kWh per 1000 hours burning time	23
Efficacy (Rated) 100h (lm/W)	72
Watt (Rated) (W)	18
Watt (Rated) - High frequency (W)	16
Watt (Nominal) (W)	18
Voltage (V)	57
Ignition voltage (V)	0
Current (A)	0.37

Physical data


Weight (kg)	0.08
Length base to base (mm) - A	589.8
Length base to pin Min-Max - B	594.5-596.9
Max overall length (mm) - C	604
Max. Lamp Diameter (mm) - D	26
Single packaging type	Box/Sleeve
Single package dimensions (L x W x H) (cm)	61.00 x 2.90 x 2.80
Outer package dimensions (L x W x H) (cm)	63.00 x 15.50 x 15.00

T8 Luxline® Plus



F18W/865

0001502

PHOTOMETRY

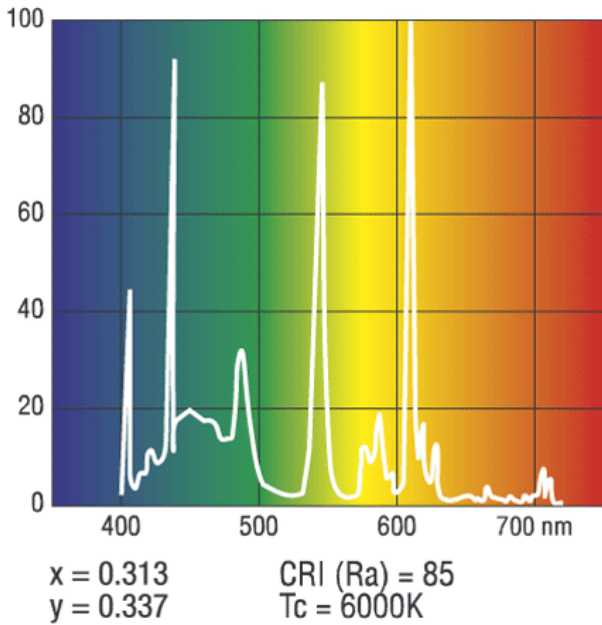

TECHNICAL DRAWINGS

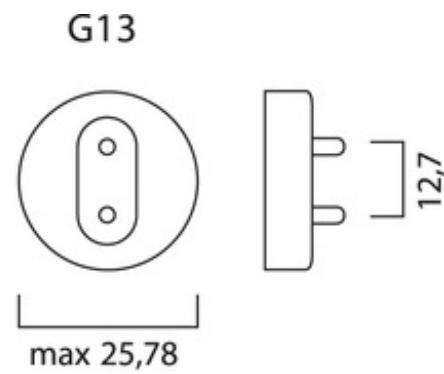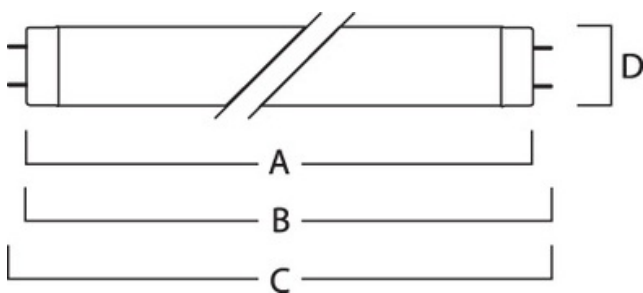

ENERGY LABEL

