




Technical data

51305

One direction thrust ball bearings

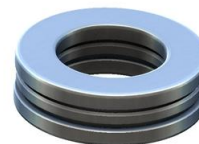

VISUAL (S)

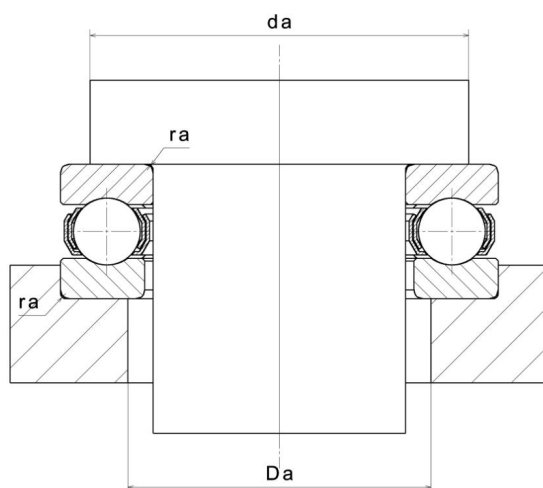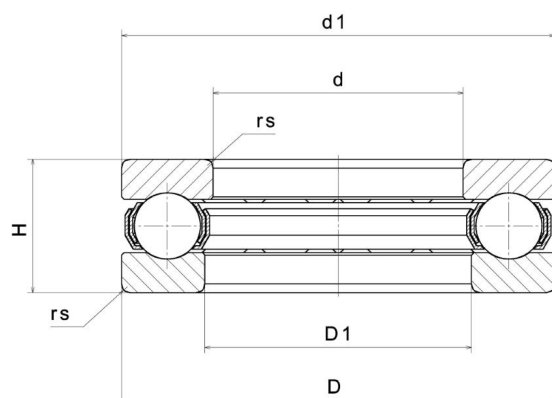

PRODUCT DEFINITION

Brand	NTN
d - Internal diameter	25 mm
D - External diameter	52 mm
T - Thrust bearing height	18 mm
rs - Min fillet radius	1 mm
Mass	0,176 kg

PRODUCT PERFORMANCE

Ca - Dynamic axial load rating	35500000 mN
C0a - Static axial load rating	61500000 mN
Cua - Limit axial load rating	2770000 mN
N lim - Oil lubrication limit speed	27600 °/s
N lim - Grease lubrication limit speed	19200 °/s
Tmin - Min operating temperature	233,15 °K
Tmax - Max operating temperature	393,15 °K

ABUTMENT

Da max - Max shoulder diameter OR	36 mm
da min - Min shoulder diameter IR	41 mm

