
 


Cast resin joint, Branch Y, 3 x 1.5mm² to 5 x 10mm², L=205mm, 490 ml, Polyurethane resin (PUR) green

Art.-No. 435-12064 | Y-1 / SF-PUR-GN | 

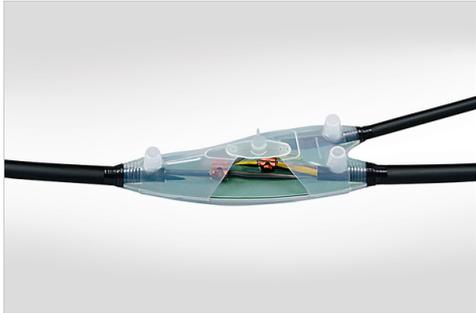

- Colour changes from blue to green whilst mixing
- Two-part, impact-proof, transparent moulding shells
- Compact, optimized dimensions
- Standard cable diameters indicated on the shells
- SF-system
- Immediately ready for use
-
-




More products in this product group:

[Branch cable joints >](#)



Application	RELICON branch joints are made for installations in low-voltage electrical networks. They are suitable for jointing on polymeric cables and wires made of PVC, XLPE, PE, EPR and utility cables. Application: Connections in industrial buildings, power supply in the ground, outdoors and underwater.
Colour	Green (GN)
Content	Cast resin PUR 33 Two-chamber pouch, transparent Moulding shells, transparent SF-system and nozzle Protective gloves, emery cloth, installation instructions HelaTape vinyl electrical tape
Material	Polyurethane resin (PUR)
No. of Wires	5
PART DESCRIPTION	Y-1 / SF-PUR-GN
Pack Content	1 Set
Package Content packed in	set
Product Family	RELICON Y-Line SF with PUR 33
Product Group	Branch cable joints
Type	Y-1 / SF
Variant	Cast resin

Product Dimensions

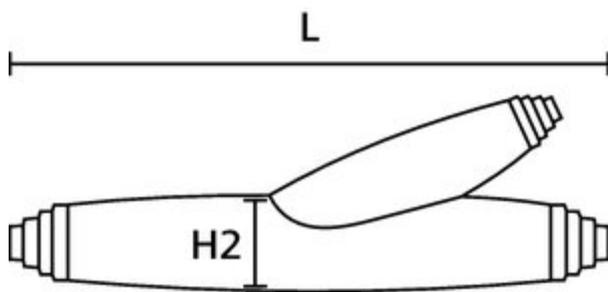

Angle	30
Branch Cable min	3 x 1.5 mm ²
Branch Cable max	5 x 6 mm ²
Height (H2)	70 mm
Length (L)	205 mm
Main Cable max	5 x 10 mm ²
Main Cable min	3 x 1.5 mm ²

ELV Compliant (Article 4 - 2)	YES
Halogen-free	No
Hazardous Goods	No
Operating Temperature	-25 °C to +120 °C
ROHS compliant	Yes
Shelf Life	48 months
Specifications	

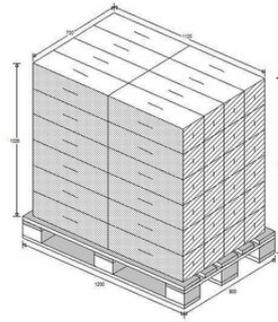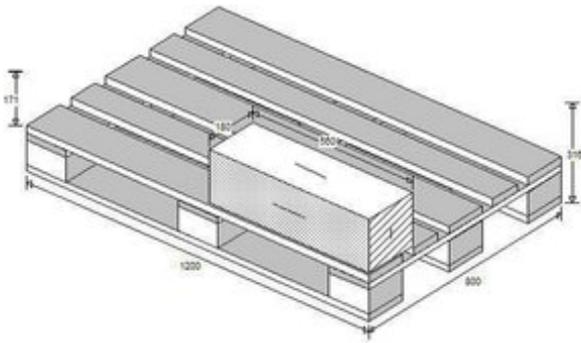

GTIN-13 / EAN	4031026626819
Packaging 1 - Height (m)	0.068 m
Packaging 1 - Length (m)	0.377 m
Packaging 1 - Qty	1
Packaging 1 - Type	carton
Packaging 1 - Volume (m ³)	0.00525538 m ³
Packaging 1 - Weight (kg)	1.276 kg
Packaging 1 - Width (m)	0.205 m
Packaging 3 - Height (m)	0.171 m
Packaging 3 - Length (m)	0.56 m
Packaging 3 - Qty	1
Packaging 3 - Type	box
Packaging 3 - Volume (m ³)	0.0172 m ³
Packaging 3 - Weight (kg)	2.005 kg
Packaging 3 - Width (m)	0.18 m
Packaging 4 - Height (m)	1.055 m
Packaging 4 - Length (m)	1.2 m
Packaging 4 - Qty	110
Packaging 4 - Type	pallet
Packaging 4 - Volume (m ³)	1.013 m ³
Packaging 4 - Weight (kg)	281.65 kg
Packaging 4 - Width (m)	0.8 m
Storage Temperature	+4 °C to +40 °C

More Information

