

Features

- 5kvar shunt reactor drive capacity
- Separate Thermal inputs
- Driveability from %0 to %100
- Intervention without delay
- System with the test button
- Thermal and status led
- Separate drive notification Led for T1,T2,T3
- Infinity contac life

RS PRO Power Factor Correction Capacitors

RS Stock No.: 0434503



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

- *The inductive load drives can be used with the new generation SVC enabled RS PRO power factor relays. It designed to drive 3 single-phase shunt reactors.*
- *Prevent capacitive penalty*
- *Compensate capacitive loads powers*
- *It protect the client electrical system.*
- *It prevents electrical network fatigue.*

General Specifications

Product type	Inductive load driver, thyristor module
Operating temperature	-20 , +55
Storage temperature	-30 , +80
Syrge protection	YES
Mounting type	Mounting on the vertical or terminal rail in the cabinet
Connection type	Terminal

Mechanical Specifications

Width	130mm
Length	104 mm
Height	1404 mm
Weight	1050 gr

Electrical Specifications

Operating voltage	85-260V AC
Safety Category voltage	CATII
Cable diameter	2,5mm


Protection Category

IP Rating	00
-----------	----

Approvals

Compliance/Certifications	CE-UKCA
Hazardous Area Certification	ROHS-3

Wiring Diagram

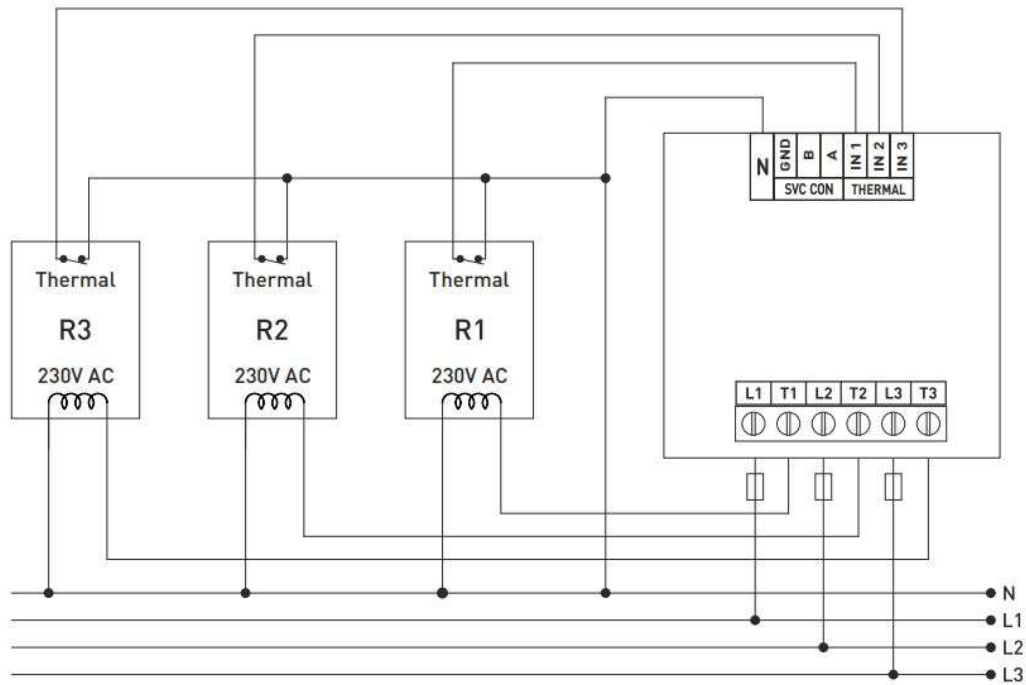

Similar Products

Stock No.	Product Name	Attribute 1	Attribute 2	Attribute 3
0434514	Power factor correction capacitor	10 KVAR shunt reactor capacity driver	Driveability from %0 to %100	Intervention without delay