

FX20V Downflow Fan Heater



Product Description

Compact wall mounted downflow fan heater, ideal for heating bathrooms, ensuites and kitchens.

Key Features


- 2kW maximum output
- Pull cord operation
- Neon indicator
- Energy saving thermostat switches output down to 1kW once the room is warm (functions on 2kW setting only)
- 1kW output selectable on installation

Technical Details

Thermostat	Non-adjustable - switches output down to 1kW once room is warm. Only functions on 2kW output.
Construction	Double insulated plastic case. Moulded in flame retardant self extinguishing grade nylon.
Thermal Cut out	Manually resettable thermal overload cut out and thermal fuselink
Element	2kW stitched type with thermal fuse protection
Colour/ Finish	White
IP Rating	IPX2. Product should be mounted at a minimum height of 600mm if installed in zone 3 of a location containing a bath or shower.
Installation	Two upper keyhole slots are provided together with a third fixing hole to secure the heater to the wall. Supplied without cable.
Electrical Connections	All installations must be in accordance with IEE wiring regulations
Approvals	CE and BEAB
Warranty	1 year
Country of Origin	Ireland
Manufacturer	Dimplex UK

Dimensions

MAIN DIMENSIONS - FX20V, FX20VE & FX20VL

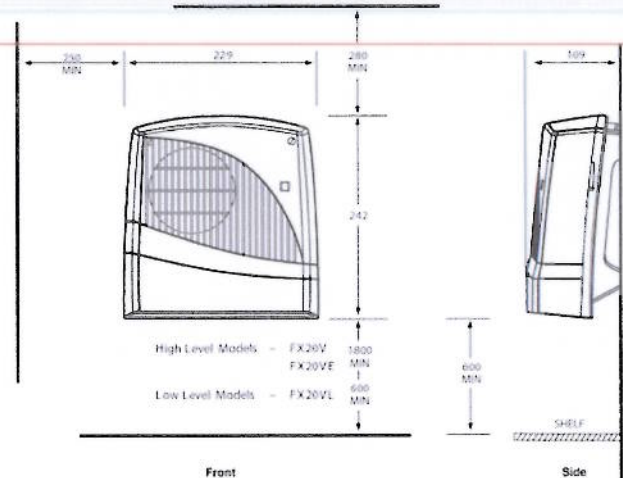

Model No.	Loading kW	Height mm	Width mm (A)	Depth mm	Weight kg
FX20V	2	242	229	109	1.1
FX20VE	2	242	229	109	1.1
FX20VL	2	242	229	109	1.1

Packaging Details

Model No.	Length	Height	Depth	Barcode
FX20V	243	260	120	5011139 016263
FX20VE	243	260	120	5011139 016270
FX20VL	243	260	120	5011139 016287

Additional Information

Model No.	Ti	Hi	Pallet Quantity (2.4m high)
FX20V	40	8	320
FX20VE	40	8	320
FX20VL	40	8	320