

Range datasheet

RS Pro Cylindrical Female - Female Anti-Vibration Mounts



Product Details -

FEMALE - FEMALE Cylindrical mounts, a simple and cost effective mount. For use in compression and shear. A very large range of available size and studs.


H = Height

D = Diameter

G = Tread Size

B = Thread Depth

Line Drawing -

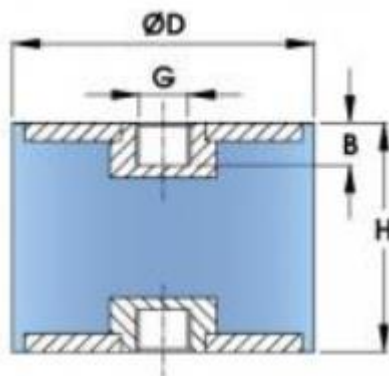



Range Table:

RS Stock number	Description	D	H	G x L/B	45 Shore Hardness (Max KG)		60 Shore Hardness (Max KG)	
					Load	Sheer	Load 2	Sheer 2
1263922	Cyl. Mount (F/F) 15x12mm M4 45 ShA Stainless Steel (316 grade)	15	12	M4	9.43	2.97	16.7	5.72
1263923	Cyl. Mount (F/F) 20x20mm M6 60 ShA Stainless Steel (304 grade)	20	20	M6	12.65	4.62	27	10.12
1263924	Cyl. Mount (F/F) 30x40mm M6 45 ShA Stainless Steel (316 grade)	30	40	M6	26.8	10.45	58.4	22.88
1263925	Cyl. Mount (F/F) 50x40mm M10 45 ShA Stainless Steel (304 grade)	50	40	M10	83.95	29.15	176.3	63.47
1263926	Cyl. Mount (F/F) 50x45mm M10 55 ShA Stainless Steel (304 grade)	50	45	M10	80.62	29.15	171.4	63.47
1264335	Stud Mount Cyl. Mount (F/F) 15x15mm M4 60 ShA	15	15	M4	6.9	2.2	15.3	5.72
1264336	Stud Mount Cyl. Mount (F/F) 15x15mm M5 60 ShA	15	15	M5	6.9	2.2	15.3	5.72
1264337	Stud Mount Cyl. Mount (F/F) 16x15mm M4 50 ShA	16	15	M4	6.9	2.2	15.3	5.72
1264338	Stud Mount Cyl. Mount (F/F) 16x18mm M5 60 ShA	16	18	M5	6.9	2.2	15.3	5.72
1264339	Stud Mount Cyl. Mount (F/F) 20x15mm M5 50 ShA	20	15	M5	14.15	4.62	29.3	10.12
1264340	Stud Mount Cyl. Mount (F/F) 20x15mm M6 65 ShA Chloroprene (Neoprene) Stainless Steel (304 grade)	20	15	M6	12.65	4.62	27	10.12
1264341	Stud Mount Cyl. Mount (F/F) 20x20mm M6 55 ShA	20	20	M6	12.65	4.62	27	10.12
1264342	Stud Mount Cyl. Mount (F/F) 20x20mm M6 60 ShA	20	20	M6	12.65	4.62	27	10.12
1264898	Stud Mount Cyl. Mount (F/F) 20x25mm M6 55 ShA	20	25	M6	12.08	4.62	26.1	10.12
1264899	Stud Mount Cyl. Mount (F/F) 25x15mm M6 60 ShA	25	15	M6	24.73	7.26	49.7	15.84
1264900	Stud Mount Cyl. Mount (F/F) 25x20mm M6 60 ShA	25	20	M6	21.16	7.26	44.3	15.84
1264901	Stud Mount Cyl. Mount (F/F) 25x22mm M8 60 ShA	25	22	M8	20.47	7.26	43	15.84
1264903	Stud Mount Cyl. Mount (F/F) 25x25mm M6 60 ShA	25	25	M6	19.67	7.26	42.1	15.84
1264904	Stud Mount Cyl. Mount (F/F) 25x25mm M8 60 ShA	25	25	M8	19.67	7.26	42.1	15.84
1264905	Stud Mount Cyl. Mount (F/F) 25x30mm M8 60 ShA	25	30	M8	18.86	7.26	40.9	15.84
1264906	Stud Mount Cyl. Mount (F/F) 30x20mm M8 60 ShA	30	20	M8	33.93	10.45	69	22.88
1264907	Stud Mount Cyl. Mount (F/F) 30x22mm M8 60 ShA	30	22	M8	31.05	10.45	65.6	22.88
1264908	Stud Mount Cyl. Mount (F/F) 30x30mm M8 60 ShA	30	30	M8	28.52	10.45	60.8	22.88
1264909	Stud Mount Cyl. Mount (F/F) 30x50mm M8 55 ShA	30	50	M8	50	17	100	40
1264910	Stud Mount Cyl. Mount (F/F) 40x28mm M10 60 ShA	40	28	M10	56.58	18.7	119.6	40.59
1264911	Stud Mount Cyl. Mount (F/F) 40x40mm M8 60 ShA	40	40	M8	50.26	18.7	107.5	40.59
1264912	Stud Mount Cyl. Mount (F/F) 50x30mm M10 60 ShA	50	30	M10	97.29	29.15	196.2	63.47



Range Table:

RS Stock number	Description	D	H	G x L/B	45 Shore Hardness (Max KG)		60 Shore Hardness (Max KG)	
					Load	Sheer	Load 2	Sheer 2
1264913	Stud Mount Cyl. Mount (F/F) 50x35mm M10 60 ShA	50	35	M10	89.01	29.15	183.8	63.47
1264914	Stud Mount Cyl. Mount (F/F) 50x45mm M10 60 ShA	50	45	M10	80.62	29.15	171.4	63.47
1264915	Stud Mount Cyl. Mount (F/F) 50x50mm M12 60 ShA	50	50	M12	78.32	29.15	167.9	63.47
1264916	Stud Mount Cyl. Mount (F/F) 60x35mm M10 60 ShA	60	35	M10	142.26	33	264.3	74.8
1264917	Stud Mount Cyl. Mount (F/F) 60x45mm M10 60 ShA	60	45	M10	115.12	33	214.8	74.8
1264919	Stud Mount Cyl. Mount (F/F) 70x50mm M10 60 ShA	70	50	M10	163.65	44	336.6	88
1264920	Stud Mount Cyl. Mount (F/F) 80x30mm M12 60 ShA	80	30	M12	78.32	29.15	167.9	63.47
1264921	Stud Mount Waisted Mount (F/F) 30x20 M8 60 ShA NR	30	20	M8	33.93	10.45	69	22.88
1264922	Stud Mount Waisted Mount (F/F) 40x28 M10 60 ShA NR	40	28	M10	56.58	18.7	119.6	40.59

