



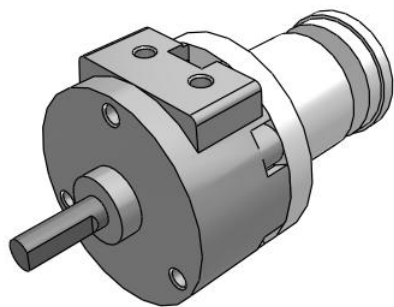

C(D)RB2*W10~40-Z, Rotary Actuator, New Vane Style CDRB2BW10-90SZ

- Standard type.
- Piping ports are located on the flat surface.
- Many variations of shaft-end shape (6 types).

Magnet	D (Built-in)
Mounting	B (Basic)
Standard Shaft Type	W (Double Shaft with Single Flat)
Angle Adjusting Unit	None
Size	10 mm
Rotation Angle - Vane	90S (Angle: 90 Single Vane)
Port	Side
Auto Switch	No Switch
Lead Wire or Prewired Connector	0.5m (Or None in the Case of No Switch)
Number	2 pcs. (Or None in the Case of No Switch)
-	Air (Non-lube)

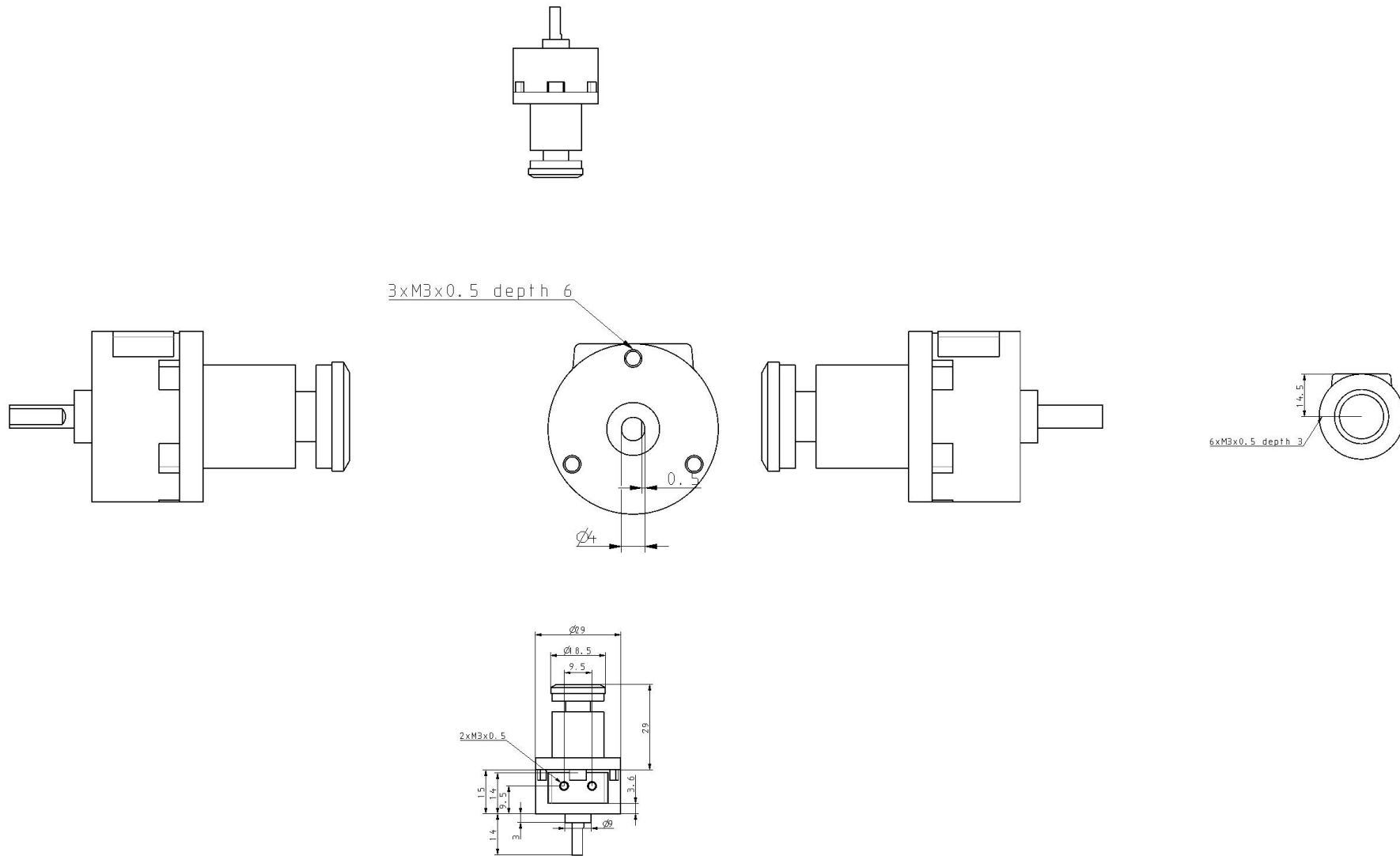

-

-

[CRB2-C_EU.pdf](#)

-

[OM_CRB2_OM00001EN-B.pdf](#)