


suction cup ESS-30-ES

Part number: 189344

FESTO

easily interchangeable,

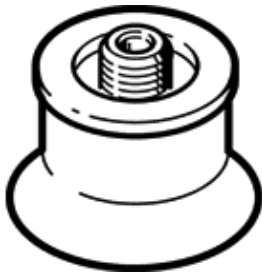

Data sheet

Feature	Value
Min. workpiece radius	50 mm
Nominal size	3 mm
suction cup diameter	30 mm
suction cup volume	2.12 cm ³
Position of connection	on top
Assembly position	Any
Correlation to suction-cup holder	Size 4
Suction cup shape	Round, extra deep
Operating pressure	0 ... 0.95 bar
Nominal operating pressure	-0.7 bar
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7::-]
Corrosion resistance classification CRC	1 - Low corrosion stress
Food-safe	See Supplementary material information
Ambient temperature	-30 ... 180 °C
Retention force at nominal operating pressure	37.2 N
Lateral force at nominal operating pressure	21.5 N
Product weight	9.2 g
Mounting type	Via vacuum port
Vacuum connection	M6
Colour	transparent
Shore hardness	50 +/- 5
Material of threaded plug	Nickel-plated brass Galvanised and chrome-plated steel
Materials note	Free of copper and PTFE Contains PWIS substances Conforms to RoHS
Material suction cup	VMQ (silicon)