


KEMET Part Number: MMK5223J100J01L15.0CBULK
(F601JF223J100ALF0C, MMK5223J100J01L15,0CBULK)

MMK/F601, Film, Metallized Polyester, General Purpose, 0.022 uF, 5%, 100 VDC, 85°C, Lead Spacing = 5mm

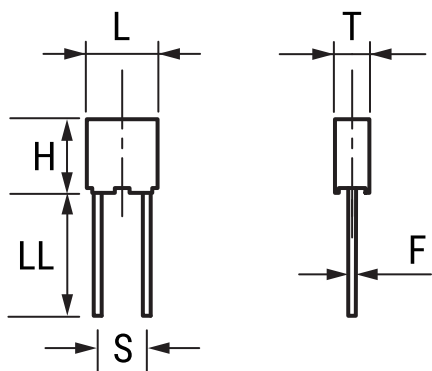

General Information

| | |
|--------------------|---|
| Supplier: | KEMET |
| Series: | MMK/F601 |
| Dielectric: | Metallized Polyester |
| Style: | Radial |
| Features: | DC Multipurpose Applications |
| RoHS: | Yes |
| Lead: | Wire Leads |
| Notes: | Not For New Design, Please Check Possible Alternative Parts (AltPart) |

Dimensions

| | |
|-----------|--------------|
| L | 7.2mm MAX |
| H | 6.5mm MAX |
| T | 2.5mm MAX |
| S | 5mm +/-0.4mm |
| LL | 15mm NOM |
| F | 0.5mm NOM |

Specifications

| | |
|-------------------------------|--------------------------|
| Capacitance: | 0.022 uF |
| Capacitance Tolerance: | 5% |
| Voltage AC: | 63 VAC |
| Voltage DC: | 100 VDC, 77.5 VDC (100C) |
| Temperature Range: | -55/+100C |
| Rated Temperature: | 85°C |
| Insulation Resistance: | 15 GOhms |
| Max dV/dt: | 30 V/us |

Packaging Specifications

| | |
|-------------------|-----------|
| Packaging: | Bulk, Bag |
|-------------------|-----------|