

### Right Angle Shapes, VG style/MIL style

- Helashrink 1100 Series, with rib, low profile



1123-1-G supplied / fully recovered.

Combinations "On request"					
Adhesive	Material				
	B7	G	J	H	L
WM250	√	√	√	√	-
W8	√	√	√	√	-
W24	√	√	√	√	√
V9500	√	√	√	√	-
HMT200A	√	√	√	√	-
W21	-	-	-	√	-
Without Adhesive	√	√	√	√	√

For Material / Adhesive selection and other information please refer to page 10.

Standard combinations	
Article-No.	Type
411-21180	1121-1-G
411-22180	1122-1-G
411-23180	1123-1-G
411-24180	1124-1-G
411-25180	1125-1-G
411-26180	1126-1-G
411-27180	1127-1-G
411-28180	1128-1-G
411-29180	1129-1-G
411-41180	1141-1-G
411-21007	1121-4-G
411-22015	1122-4-G
411-23013	1123-4-G
411-24009	1124-4-G
411-25008	1125-4-G
411-25027	1125-2-G
411-26008	1126-4-G
411-27008	1127-4-G
411-27005	1127-3-B7
411-28002	1128-4-G
411-29001	1129-4-J


**Right Angle Shapes, VG style/MIL style**

- Helashrink 1100 Series, with rib, low profile


This style is typically used on airborne harnesses to achieve light weight, low profile, compact strain relief and mechanical protection.



1123-1-G supplied / fully recovered.

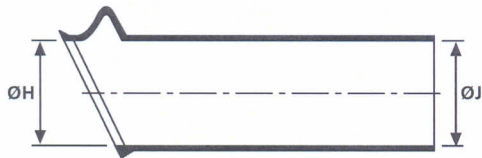

a: Expanded form (supplied)

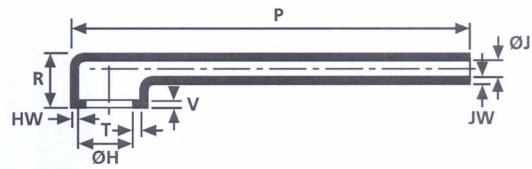

b: Fully recovered form (after heating)

Sizes and Type Table

Type	Designation as per VG-Norm	ØH		ØJ		P		R	HW	JW	T	V
		min. a	max. b	min. a	max. b	± 10%	± 10%					
1121-1	VG95343T06F001A	22.0	12.0	22.0	6.5	70.0	19.0	1.5	1.1	1.0	3.0	
1122-1	VG95343T06F002A	25.5	15.0	25.0	7.5	79.0	20.0	1.5	1.1	1.0	3.0	
1123-1	VG95343T06F003A	29.0	19.0	29.0	8.5	89.0	21.0	1.8	1.1	1.0	3.0	
1124-1	VG95343T06F004A	34.0	23.0	34.0	10.0	102.0	22.0	1.8	1.1	1.0	3.0	
1125-1	VG95343T06F005A	37.0	30.0	37.0	11.0	108.0	24.0	2.0	1.1	1.7	3.0	
1126-1	VG95343T06F006A	43.5	34.0	43.5	12.0	121.0	27.0	2.0	1.1	1.7	3.0	
1127-1	VG95343T06F007A	50.0	41.5	50.0	14.5	132.0	30.0	2.3	1.4	1.7	3.0	
1128-1	VG95343T06F008A	62.5	47.0	62.5	18.0	133.0	33.0	2.5	1.4	2.0	3.0	
1129-1	VG95343T06F009A	69.0	60.0	69.0	20.0	137.0	35.0	2.5	1.4	2.0	3.0	
1141-1	VG95343T06F010A	82.0	67.0	82.0	23.0	140.0	45.0	2.5	1.4	2.0	3.0	
1121-4	-	22.3	11.4	22.3	6.4	105.2	18.5	1.5	1.1	1.0	3.3	
1122-4	-	25.6	15.0	25.6	7.5	124.0	19.8	1.5	1.1	1.0	3.3	
1123-4	-	29.4	19.0	29.4	8.5	146.3	20.8	1.8	1.1	1.0	3.3	
1124-4	-	34.0	22.9	34.0	10.0	172.2	21.8	1.8	1.1	1.0	3.3	
1125-4	-	29.5	37.3	37.3	11.0	185.2	24.4	2.0	1.1	1.7	3.3	
1125-2	-	41.2	29.5	41.2	11.0	82.0	24.4	2.0	1.1	1.7	3.3	
1126-4	-	43.7	34.0	43.7	12.0	213.6	27.0	2.0	1.1	1.7	3.3	
1127-4	-	50.0	41.1	2.3	14.5	224.5	9.5	2.3	1.4	1.7	3.3	
1127-3	-	50.0	41.1	2.3	14.5	65.0	29.5	2.3	1.4	1.7	3.3	
1128-4	-	62.7	47.0	62.7	18.0	227.3	33.3	2.5	1.4	2.0	3.3	
1129-4	-	69.3	59.7	69.3	20.0	233.4	35.1	2.5	1.4	2.0	3.3	

All dimensions in mm. Subject to technical changes.