



ENGLISH

Datasheet

Stock No: 1243898

RS Pro



50/60Hz Current Transformers

Application

- Power Monitoring
- Current Measurement
- Instrumentation


Features

- High Output Voltage in small package
- Good Linearity over current range
- High Saturation current
- Fully ROHS & REACH Compliance
- All Materials UL94-V0
- Operating temperature range -40 deg C to +120 deg C

Electrical Specifications @ 20°C ambient

Primary Current	5A
Turns Ratio	500:1 nominal
Winding Resistance	32Ω
Dielectric Withstanding Voltage (Hi-pot)	2.5KVrms

Mechanical Dimensions

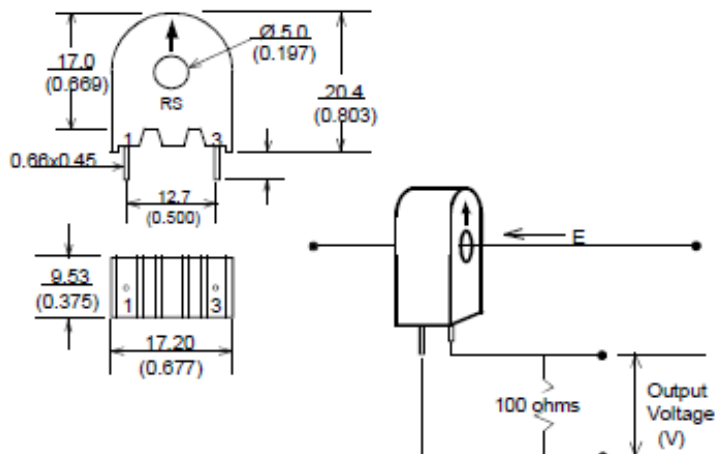

Dimensions in mm. General Tolerance $\pm 0.25\text{mm}$ unless specified. Pin pitch tolerance $\pm 0.1\text{mm}$.

