



ENGLISH

Datasheet

RS Pro Plain Nylon Flat Head Machine Screws, M3 x 16mm

RS Stock No: **291-379**



Product Details

RS Pro machine screw measuring M3 x 16 mm, is moulded from ivory coloured nylon 6.6. This flat head machine screw features high mechanical strength. The machine screw is ideal for use where good insulation and corrosion resistance is required. This screw is suitable for use in high voltage assemblies. The slotted drive machine screw meets BS4183 standards.


Features and Benefits

- High mechanical strength
- Ideal for use where good insulation and corrosion resistance is required
- Suitable for use in high voltage assemblies
- Moulded from ivory coloured Nylon 6.6

Specifications:

Drive Type	Slot
Finish	Plain
Head Shape	Countersunk
Material	Nylon 66
Length	16 mm
Thread Pitch	0.5
Thread Size (Metric)	M3
Specification	BS 4183

BS 4183 Metric Slotted Countersunk Head Machine Screws

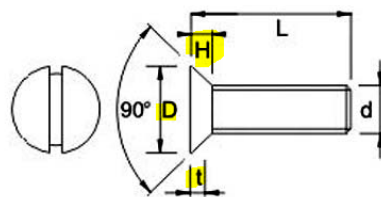

Dimensions of Metric Slotted Countersunk Head Machine Screws

Thread (d)	H max (BS / DIN)	H max (ISO)	D nom (DIN)	D nom (BS)	D nom (ISO)	w (slot width) nom	t (slot depth) min
M2	1.2	1.2	3.8	4.4	3.8	0.6	0.8
M2.5	1.5	1.6	4.7	5.5	4.7	0.7	1
M3	1.65	1.65	5.6	6.3	5.6	0.9	1.2