

00 21 37

Tool Case "Robust45" Electric 63 parts with integrated rollers and telescopic handle




- Fit to fly case, made from impact-resistant polypropylene
- Dustproof and watertight
- Air pressure compensation valve
- Temperatures ranging from - 30°C to + 80° C
- Padlock eyelets
- Document compartment; tool boards with 54 tool pockets and 94 straps
- Lockable base tray can be individually divided using aluminium separator system
- Ergonomic dual-component handle
- With two smooth castors
- With telescopic handle
- Volume: 45 l
- 35 kg maximum load

Article No.	00 21 37
EAN	4003773082606
Dimension exterior (interior) width mm	609 (540)
Dimension exterior (interior) height mm	263 (229)
Dimension exterior (interior) depth mm	428 (364)
Net weight g	15000



With pressure valve for venting and name plate

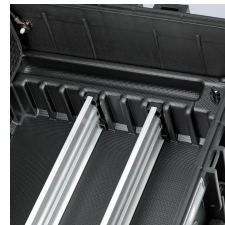

Aluminium separators for individually dividing up the base tray




With document compartment

technical change and errors excepted

Content 00 21 37 (21)

Article No.			Quantity	Nominal size	
00 11 01	Knipex	KNIPEX TwinKey®, for all standard cabinets and shut-off systems	1		
08 26 145	Knipex	Needle-Nose Combination Pliers	1		⚡ 1000 V ⚡ ⚡ ⚡
12 42 195	Knipex	KNIPEX MultiStrip 10, Automatic Insulation Stripper	1		⚡ ⚡ ⚡
13 86 200	Knipex	Pliers for Electrical Installation	1		⚡ 1000 V ⚡ ⚡ ⚡ ⚡ ⚡ ⚡ ⚡
16 95 01 SB	Knipex	KNIPEX ErgoStrip®, Universal Stripping Tool	1		⚡ ⚡ ⚡
26 26 200	Knipex	Snipe Nose Side Cutting Pliers, (Stork Beak Pliers)	1	200 mm	⚡ 1000 V ⚡ ⚡ ⚡ 40°
70 06 160	Knipex	Diagonal Cutter	1	160 mm	⚡ 1000 V ⚡ ⚡ ⚡
74 06 200	Knipex	High Leverage Diagonal Cutter	1	200 mm	⚡ 1000 V ⚡ ⚡ ⚡
86 03 180	Knipex	Pliers Wrench, pliers and a wrench in a single tool	1	180 mm	⚡ ⚡
87 01 180	Knipex	KNIPEX Cobra®, Hightech Water Pump Pliers	1	180 mm	⚡ ⚡ ⚡
97 53 04	Knipex	Self-Adjusting Crimping Pliers for End Sleeves (ferrules), with lateral access	1		⚡ ⚡ ⚡
98 52	Knipex	Cable Knife	1	185 mm	⚡ 1000 V ⚡ ⚡
98 25 01 SL	Knipex	Screwdriver (Slim) for cross-recessed screws, Pozidriv®	1	PZ1	⚡ 1000 V ⚡ ⚡ ⚡

98 20 35 SL	Knipex	Screwdriver (Slim) for slotted screws	1	3,5 x 100 mm	
3003010119	Picard	Locksmith's hammer	1	300 g	
004018	Wera	8100 SA 8 Zyklus set of metal ratchets, 28 parts	1	1/4"	
003760	Wera	Joker open-end wrench	1	10 x 13 mm	
18115	Stabila	Pocket Electric mini spirit level	1	68 mm	
003484	Wera	Kraftform Kompact VDE 16 Slim	1		
16135	Stabila	Model 70 Electric spirit level	1	430 mm	
361 252 1	Rennsteig	Electrician's Chisel	1	250 x 10 mm	