


## CE 25/CE 30 SQUARE SPLICE WASHER

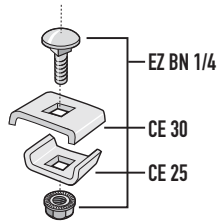


- Use CE 25 and CE 30 with EZ BN 1/4 to splice any two sections of Cablofil tray.
- Consult chart below for correct number of Nut/Bolt/Clamp sets needed for each width of tray.
- Also use for fabricating bends, turns and tees.
- UL Classified Splice.



	PKG. QTY.	WEIGHT		EZ	GC	DC	316L	BL	PE
		LBS	KG	Ⓜ					
CE 25	50	1.0	0.45	558 011	942 459	558 013	558 014	941 274	934 022
CE 30	50	1.7	0.75	558 041	942 460	558 043	558 044	941 275	934 028
EZ BN 1/4	50	1.0	0.45	941 084	943 178	943 458	941 059	942 308	942 380

CF30 – CF54 – CF105 – CF150	2" (50 mm)	4" → 8" (100 → 200 mm)	12" → 24" (300 → 600 mm)
 CE 25-CE30 attachment sets needed for side wires	2x CE 25, CE 30, EZ BN 1/4	2x CE 25, CE 30, EZ BN 1/4	2x CE 25, CE 30, EZ BN 1/4
 CE 25-CE30 attachment sets needed for bottom wires	–	1x CE 25, CE 30, EZ BN 1/4	2x CE 25, CE 30, EZ BN 1/4

## CE 35 CLAMPING WASHER

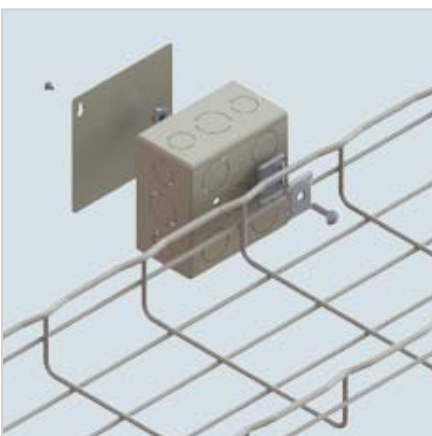

- Useful for clamping cable dropouts or other accessories to the top two side wires of Cablofil tray.
- Use with EZ BN 1/4 Bolt/Nut sold separately.

	PKG. QTY.	LENGTH		WEIGHT		316L
		INCHES	MM	LBS	KG	
CE 35	50	1.4	35	1.1	0.5	943 249

