


PREVOST FILTRATION - KOMBINATIONEN VON EINHEITEN

Dreifachblock - Filter, Regler und Öler

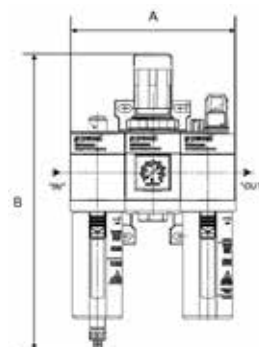

Max. Betriebsdruck

10 bar

Filterung (µm)

25.00

Art. Nr	IG	Durchfluß bei 6 bar (l/min) (ΔP= 1.00 bar)		Nettogewicht (Kg)	Abm. A (mm)	Abm. B (mm)
ATU T2510100	G1/8	500	0.5 / 10	0.977	97	302
ATU T2510101	G1/4	800	0.5 / 10	0,977	97	302
ATU T2510102	G3/8	2200	0.5 / 10	2,446	97	302
ATU T2510103	G1/2	3500	0.5 / 10	2.446	97	302