

Laserliner

VideoControl-Snake 15m Set




15 m
DOF 2...6 cm



Video inspection system with practical camera unit for mobile use

Rev18W02

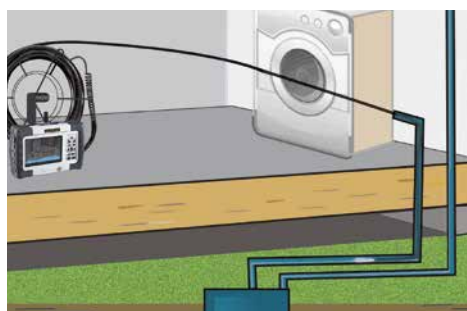

VideoControl-Master

- Large, high resolution 5.0" colour display
- Integrated still image and video recording function with snapshot option for image documentation during video recording.
- Adjustable, digital zoom function with large and high resolution zoom range.
- Image rotation in 90° increments
- Image comparison function: Compares the current image with a reference image
- Data storage on SD card, max. 16 GB
- USB 2.0 port
- External monitors operated via TV Out connection
- Multilingual On-Screen-Display
- Interchangeable camera unit
- Li-ion battery for up to 4 hours of continuous operation

VideoControlSnake-Camera

- 20 mm stainless steel camera head
- No pull-back thanks to flexible coil spring
- Powerful object lighting
- Sturdy, hand-held reel with 15 m cable
- Stable, reinforced feed cable (ø 5.8 mm)
- Suitable for 40 mm tubes with 90° bend

TECHNICAL DATA

VIDEOCONTROL-MASTER
SCREEN TYPE 5.0" TFT colour display
DISPLAY RESOLUTION 640 x 480 pixels
CONNECTIONS
Industrial connector for camera TV-Out, USB 2.0, SD card slot, 5V DC power pack
FORMAT PICTURE / IMAGE RESOLUTION
JPEG format, 640 x 480 pixels
VIDEO FORMAT / IMAGE REFRESH RATE
NTSC / 30 frames / sec
LED 10 luminosity degrees
ZOOM 2 x digital zoom in 10% steps
MEMORY SD card, max. 16 GB
AUTO SHUT OFF 5 min / 10 min / 15 min / 30 min (adjustable)
POWER SUPPLY
Li-ion rechargeable battery / power pack
OPERATING TIME 4h
OPERATING TEMPERATURE -10 ... 60°C
SNAKE-CAMERA
TYPE OF CAMERA CMOS image sensor
CAMERA HEAD / CABLE
ø 25 mm, IP 67
CAMERA RESOLUTION 640 x 480 pixels
FIELD OF VISION 127°
FOCAL DEPTH 2 ... 6 cm
CABLE LENGTH 15 m
REEL DIAMETER 31 cm
MINIMUM BENDING RADIUS 70 mm
OPERATING TEMPERATURE -10 ... 60°C



5.0" TFT colour display

Camera head with 10 high-performance LEDs

ARTICLE	ARTICLE NO.	EAN CODE	PU
VideoControl-Snake Set	089.815L	4 021563 702886	1

VIDEOCONTROL-MASTER

640 x 480 pixel



ZOOM 2x



CAMERA

640 x 480 pixel



VideoControl-Snake set

- + VideoControl-Master
- + VideoControlSnake-Camera
- + power supply/battery charger incl. Sortimo® L-BOXX® 238
- + 4 GB SD-card
- + USB-cabel
- + AV-cabel
- + carrying strap
- + software

Packing dimension (W x H x D)
442 x 253 x 357 mm