

# S1705P Press to call with LED & buzzer




A wall mounted Call button in white ABS complete with a single gang mounting box. This is a non-latching unit with a N/O contacts. The LEDs (available in RED, BLUE, GREEN or YELLOW) and buzzer have separate terminals for acknowledge purposes.

The LED current limit resistor is provided for 12 vdc operation and button the contacts are rated at 50mA @ 24vdc. N/O press to close.

**They should NOT be used for switch feeds to door strikes or mag locks etc.**

- Back box supplied for surface mount
- Flush mount onto 18mm standard galvanised box (Not supplied)
- Mark resistant decal
- Tactile button
- Two high brightness LEDs
- Integral buzzer

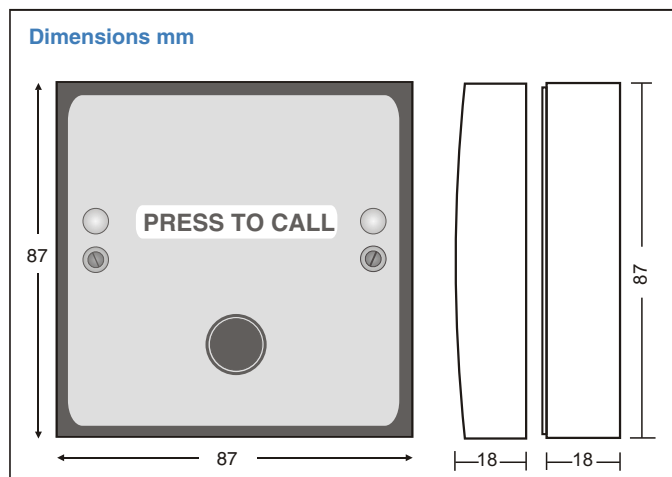

Specification	S1705S
Led Current	40mA @ 12vdc
Sounder Current	20mA @ 12vdc
Switch Contacts	50mA @ 24vdc
Visual Indication	2 x LED's
Integral Sounder Level	85db @ 10cm
Tamper	N/A
Material	White ABS
Dimensions	87 x 87 x 36mm
Weight	0.12kg
IP Rating	IP44 - To maintain the IP rating a suitable sealant or gasket for the rear of the plate is required
Approvals	CE and RoHs compliant

Available as:	
S1705PR	Call button with re-assurance Red LED's and buzzer
S1705PB	Call button with re-assurance Blue LED's and buzzer
S1705PG	Call button with re-assurance Green LED's and buzzer
S1705PY	Call button with re-assurance Yellow LED's and buzzer



## Related Products



**Hoyles Electronic Developments Ltd**

T. 01744 886600

F. 01744 886607

E. sales@hoyles.com

W. www.hoyles.com

