

**SPECIFICATION SHEET**

**Talento 111 mini & 211 mini**



**PRODUCT/ORDER CODE**

Talento 111mini	single channel	16 Amps
Talento 211mini	single channel	16 Amps


Talento 111mini                    24 hour synchronous timeswitch.  
 Talento 211mini                   24 hour quartz with reserve timeswitch  
 This product is suitable for din-rail mounting.

The 24 hour dial has 48 captive tappets. Each tappet switches the output for 30 minutes

**Technical specification:**

Dimensions	45 x 18 x 60 (single module width)
Weight	100g
AC switching capacity:	
- resistive load	16A 250v AC
- inductive load cos $\phi$ 0.6	4A 250v AC
- incandescent lamp load	1000W
Contact type	volt-free changeover
Ambient temperature	-25 <sup>0</sup> C to +55 <sup>0</sup> C
Quartz model (211 mini)	-20 <sup>0</sup> C to +55 <sup>0</sup> C
Accuracy	mains synchronised
Running reserve (quartz only)	50 hours
Recharge time	100hours
Minimum switching time	30 minutes
Manual override	Automatic / Fix on

talento 111 mini, talento 211 mini

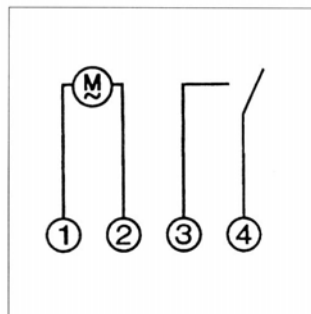

talento 111 mini, talento 211 mini

