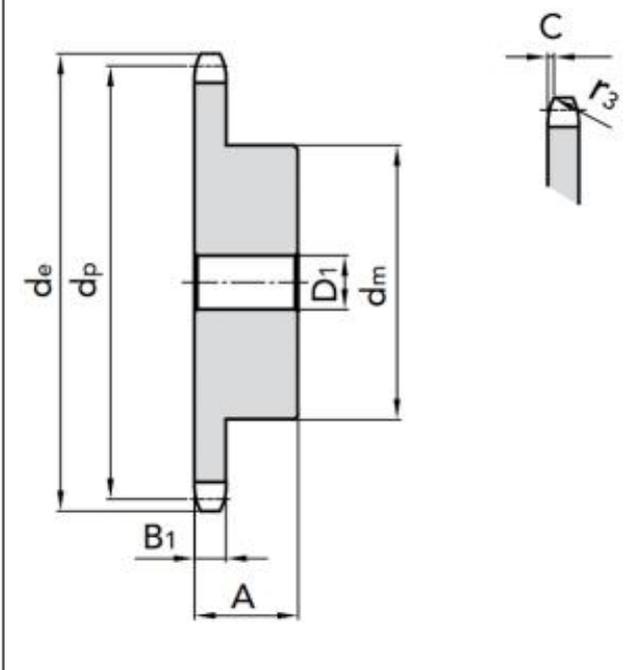


**10112016**

1/2in x 5/16in - Chain sprockets ISO

**2D Technical Drawing**

**Dynamic 3D View**

**Technical Specifications**

Number of teeth (T)	16
de (DE) mm	69.59
dp (DP) mm	65.10
Part number (CODE)	10112016
dm (DM) mm	50
D1 (D1) mm	12
A (A) mm	28
Tooth radius r3 (R3) mm	13
Radius width C (C) mm	1.3
Sprockets tooth width B1 (B1) mm	7.2
Weight (WEIGHT) kg	0.46
Material (MAT)	STEEL C 45