



STYLE 1 Part No.	STYLE 2 Part No.	"A" mm
MDLSP-1-02M-01	MDLSP-2-02M-01	2.0
	MDLSP-2-03M-01	3.0
MDLSP-1-04M-01	MDLSP-2-04M-01	4.0
MDLSP-1-05M-01	MDLSP-2-05M-01	5.0
MDLSP-1-06M-01	MDLSP-2-06M-01	6.0
	MDLSP-2-07M-01	7.0
MDLSP-1-08M-01	MDLSP-2-08M-01	8.0
MDLSP-1-10M-01	MDLSP-2-10M-01	10.0
MDLSP-1-12M-01	MDLSP-2-12M-01	12.0
MDLSP-1-14M-01	MDLSP-2-14M-01	14.0
MDLSP-1-16M-01	MDLSP-2-16M-01	16.0
MDLSP-1-18M-01	MDLSP-2-18M-01	18.0
MDLSP-1-20M-01	MDLSP-2-20M-01	20.0
MDLSP-1-22M-01	MDLSP-2-22M-01	22.0
	MDLSP-2-23M-01	23.0
	MDLSP-2-41M-01	41.0


STYLE 1

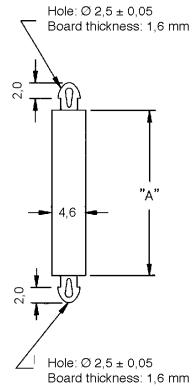

STYLE 2

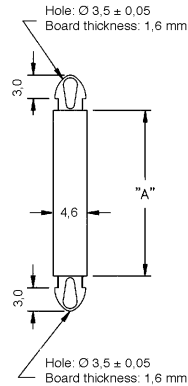

Material: Nylon 6/6 - natural; UL 94 V-2, RMS-01
or
Nylon 6/6 - natural; UL 94 V-0, RMS-19
Std. Pk.: 1.000 pcs.

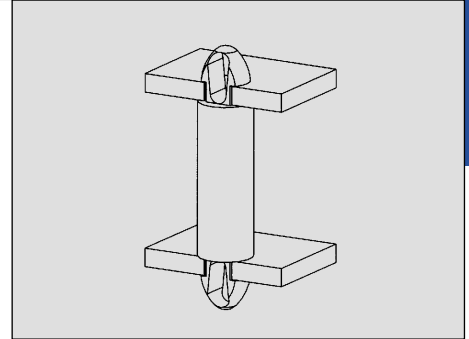

MDLSP-1/MDLSP-2

MINIATURE DUAL LOCKING SUPPORT POST

Note:

