



## U.306N - Inside pullers



### Description:

- Versatile: takes 2 or 3 legs. Converts into outside puller with the legs U.306G1 + screw U.306-4 or legs U.306G10 + screw U.306-2 or legs U.306G15 + screw U.306-3 (supplied fitted with its extension).
- Comfort: self-gripping legs by return spring. The puller stays in rolling position even when not in tension.
- Safety: legs locked in position on the bearing using a knob. No risk for the puller to escape from the bearing.
- Shear pin: the pin shears if torque limit is exceeded. Supplied with 2 spare pins.
- Set of 3 spare pins. Refer to spares table according to puller power.
- Adaptable puller accessories: slide hammer U.306M (direct attachment) and beam U.40 (attached using ring and nut U.306A1 to be ordered separately).

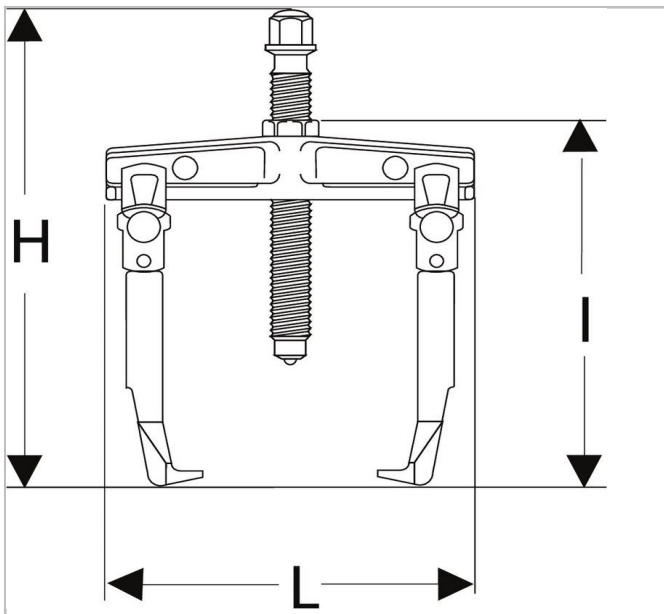

	Dep th Max i [mm]	Leng th L [mm]	Heig ht H [mm]	C Min i - Ma xi [mm]	Leng th [mm]	He x Siz e [mm]	Scre w Size ["]	t ["]	Weig ht [Kg]	Legs_M ulti ["]	Scre w Size Mult i ["]	Tonn es ["]
<b>U.306- 170N</b>	190. 0	135.0	320. 0	50 - 170	285.0	18. 0	U.30 6-2	40. 0	1.8	U.306G2 0	18.0	4.0
<b>U.306A13 ON</b>	140. 0	130.0	250. 0	23 - 130	225.0	18. 0	U.30 6-4	30. 0	1.3	U.306G2	18.0	3.0