



Brand of NTN corporation

## Technical data

### UCSP.210

Bearing units




Grey cast housing, radial insert ball bearing with socket set screws, seal with slinger

### KIT CONTENT

UC210G2, SP208-210/90

### VISUAL (S)

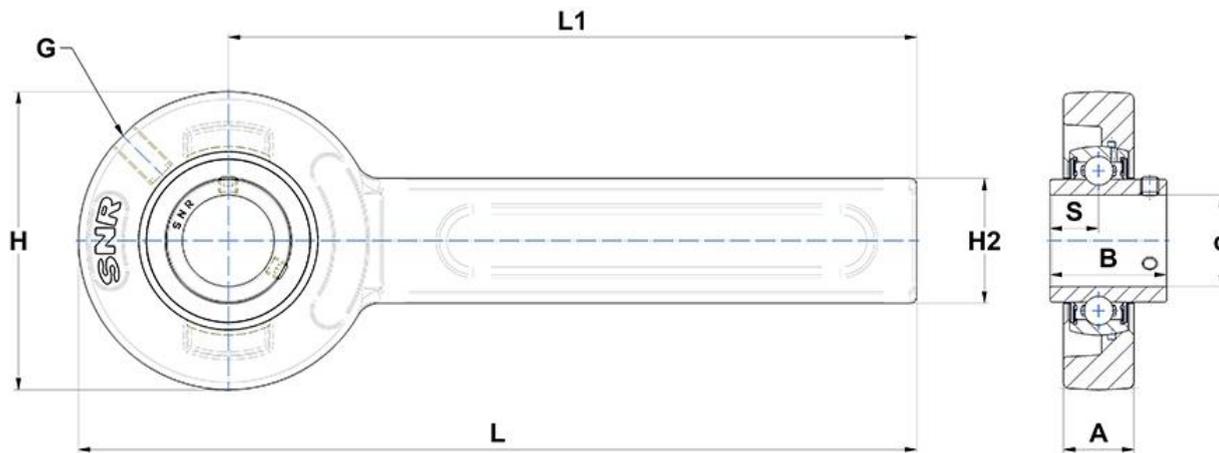

### PRODUCT DEFINITION

<b>Brand</b>	SNR
<b>A - Housing width</b>	31 mm
<b>B - Width of Inner Ring</b>	51,6 mm
<b>d - Shaft diameter</b>	50 mm
<b>G - Grease fitting</b>	R1/8"
<b>H - Housing length, width or diameter</b>	120 mm



**NTN Europe**

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00  
 S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072  
 SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

### PRODUCT DEFINITION

<b>H2 - Housing height / width</b>	61 mm
<b>L - Housing length</b>	320 mm
<b>L1 - Distance attachment end face to bearing centerline</b>	260 mm
<b>S - Distance front side/bearing centre</b>	19 mm

### PRODUCT PERFORMANCE

<b>C - Dynamic load rating</b>	35100000 mN
<b>C0 - Static load rating</b>	23200000 mN
<b>Operating temperature min.</b>	253,15 °K
<b>Operating temperature max.</b>	373,15 °K

### OTHER FEATURES

<b>Stretcher frame 2</b>	SPR21
<b>Stretcher frame 3</b>	SPR22
<b>Stretcher frame 4</b>	SPR24
<b>Mass</b>	3,93 kg
<b>Recommended tightening torque for set screw</b>	22 N-m

