


SLIM 40B WRENCHES - SINGLES

Singles SKUs



- **Slim design:** For ultimate access in tight spaces
- **12 POINTS OGV® PROFILE:** Maximizes the contact surface with the nut for a longer lifetime
- **Ring-end angled at 15°:** Prevents fingers from coming into contact with nearby surfaces, offering a safe and comfortable use
- **Open-end angled at 15°:** Reduced recovery angle for increased accessibility
- **Matte finish:** High corrosion resistance
- **ISO 691 - ISO 1711-1 - ISO 3318 - ISO 7738 - DIN 3113**

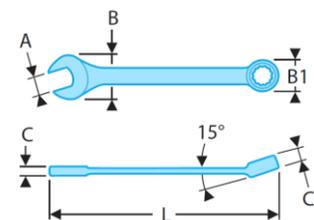

SKU	SKU Desc	A(mm)	B(mm)	B1(mm)	C(mm)	C1(mm)	L(mm)	EAN Code
40B.6	SLIM COMBINATION WRENCH 6mm	6	16,2	10,4	3,7	4,5	100	3662424112447
40B.7	SLIM COMBINATION WRENCH 7mm	7	18,2	11,7	3,7	5	110	3662424112454
40B.8	SLIM COMBINATION WRENCH 8mm	8	20,2	13,2	4	5	120	3662424112461
40B.9	SLIM COMBINATION WRENCH 9mm	9	22,2	14,6	4	6	130	3662424112478
40B.10	SLIM COMBINATION WRENCH 10mm	10	23,7	16	4	6,5	140	3662424112485
40B.11	SLIM COMBINATION WRENCH 11mm	11	25,7	17	4,7	6,5	150	3662424112492
40B.12	SLIM COMBINATION WRENCH 12mm	12	27,5	19	4,8	7	160	3662424112508
40B.13	SLIM COMBINATION WRENCH 13mm	13	28,7	20,6	5,5	7,5	170	3662424112515
40B.14	SLIM COMBINATION WRENCH 14mm	14	31,7	22	5,6	8	180	3662424112522
40B.15	SLIM COMBINATION WRENCH 15mm	15	34	23,4	5,7	8,5	190	3662424112539
40B.16	SLIM COMBINATION WRENCH 16 m	16	36	24,8	5,8	9	200	3662424112546
40B.17	SLIM COMBINATION WRENCH 17m	17	38,5	26,2	6,3	9,5	210	3662424112553
40B.18	SLIM COMBINATION WRENCH 18mm	18	39	27,6	6,8	10	220	3662424112560
40B.19	SLIM COMBINATION WRENCH 19mm	19	42,2	29	7,1	10,4	230	3662424112577
40B.22	SLIM COMBINATION WRENCH 22mm	20	42,7	30,2	7,2	10,9	240	3662424112584
40B.24	SLIM COMBINATION WRENCH 24mm	21	45,5	31,7	7,5	11,4	250	3662424112591

RRP
€xx.xx
€xx.xx