




S/SC/SOV 103 Multiple Plugs

All dimensions see note 1)

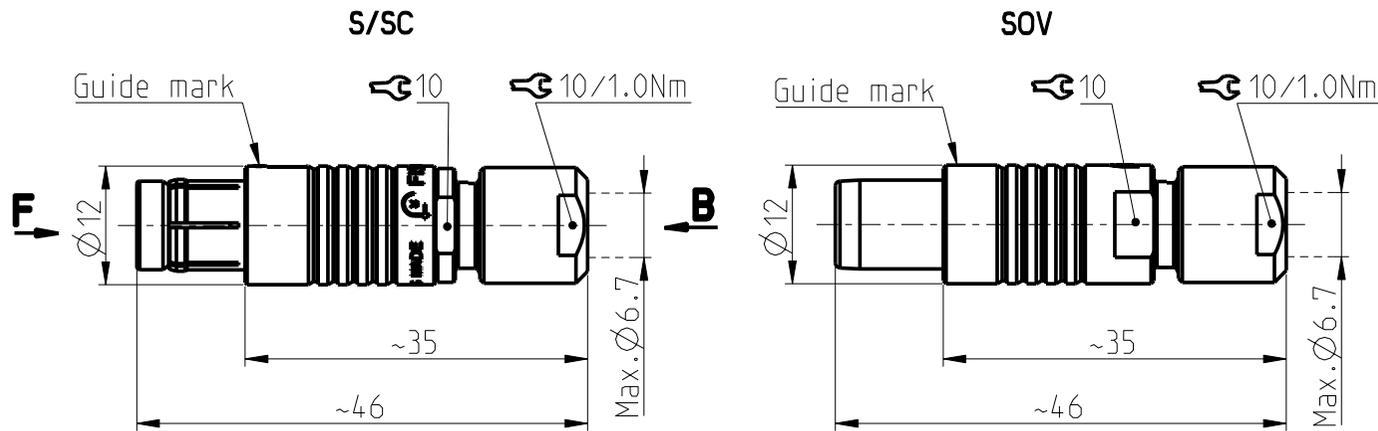


Contact polarity A


Contact polarity Z

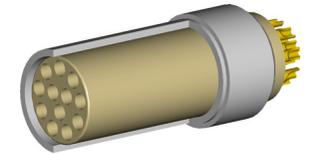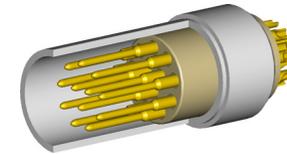


CONTACT CONFIGURATION	Contacts	Solder cup \varnothing		Crimp ⁽²⁾ cup \varnothing
103 A Z 051	2	1.18		1.18
103 A Z 052	3	1.18		-
103 A Z 053	4	0.79		-
103 A Z 054	5	0.79		0.80

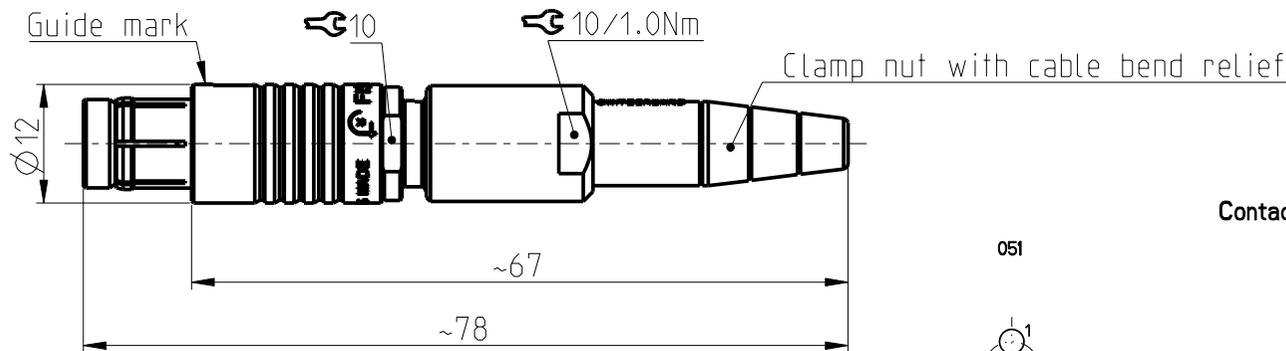

Keying codes (View from F)

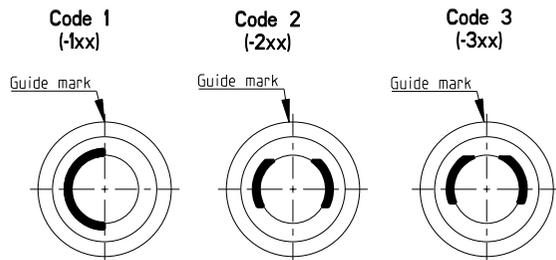

Contact configuration for polarity A (View from B)

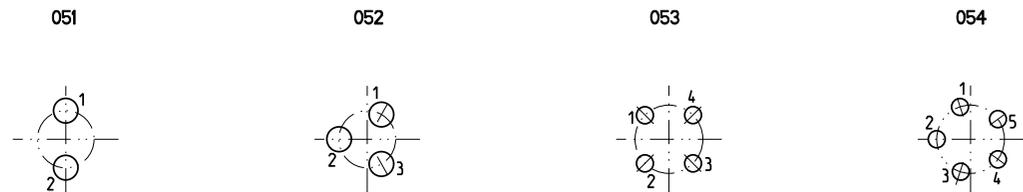

Contact configuration for polarity Z (View from B)



All dimensions in mm

Rev. Pages

Notes:
 1) All tolerances resulting from connector assembly are typically $\pm 0.3\text{mm}$
 2) For optimum crimping refer to available crimping manual.
 Part number example : S 103 A062-130

600023

1


1/2



www.fischerconnectors.com


S/SC/SOV 103 Multiplole Plugs

All dimensions see note 1)

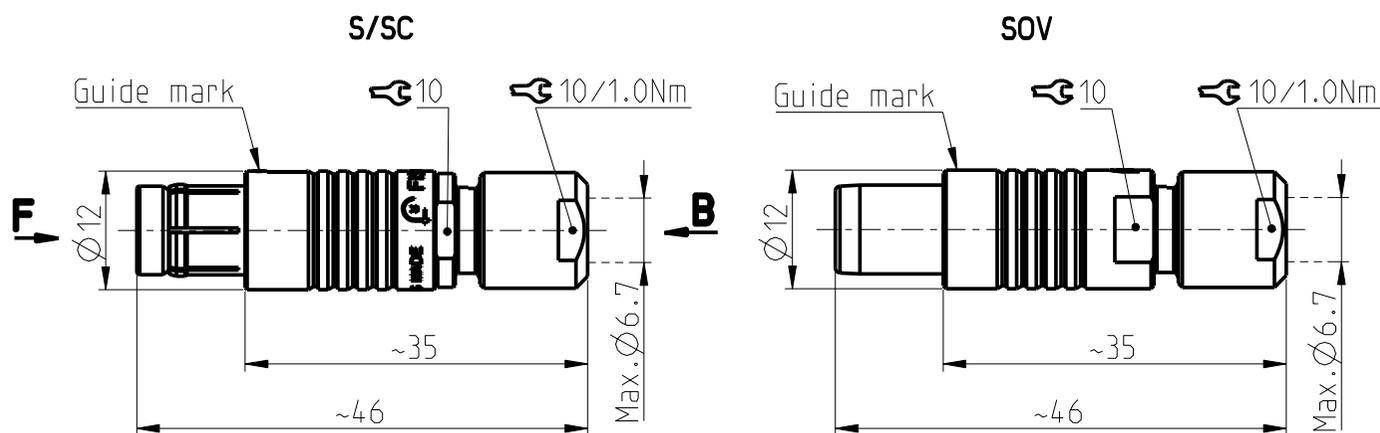


Contact polarity A


Contact polarity Z

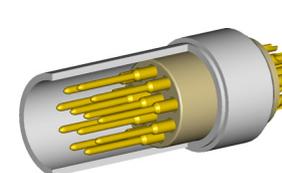


CONTACT CONFIGURATION	Contacts	Solder cup \varnothing		Crimp ⁽²⁾ cup \varnothing
103 A Z 056	6	0.79		0.60
103 A Z 057	7	0.79		0.60
103 A Z 058	8	0.79		0.60
103 A Z 062	12	0.43		-

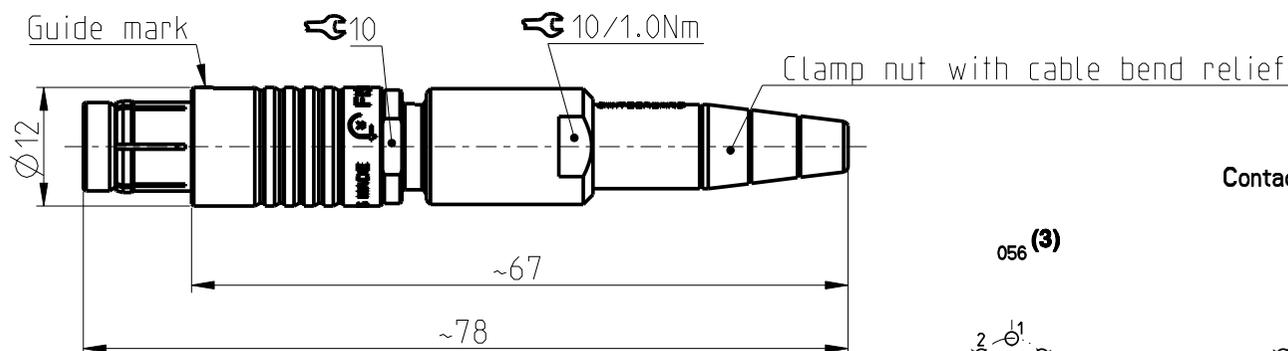

Contact configuration for polarity A (View from B)

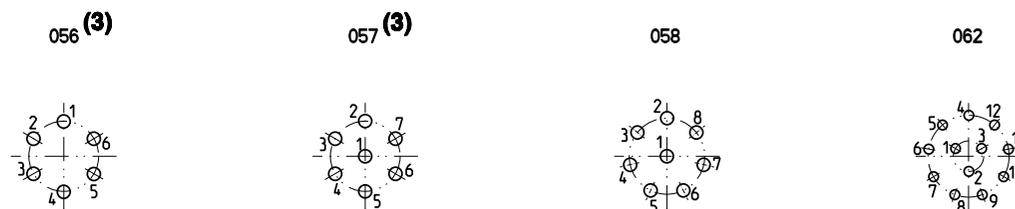

Keying codes (View from F)

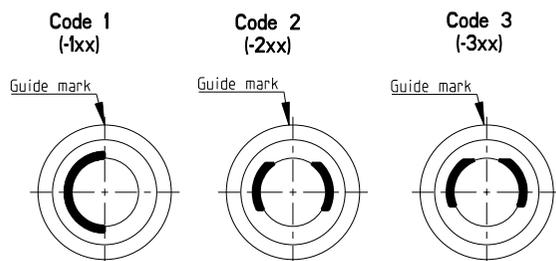

Contact configuration for polarity Z (View from B)



All dimensions in mm

Rev. Pages

Notes:

600023

1

2/2

- 1) All tolerances resulting from connector assembly are typically $\pm 0.3\text{mm}$
 - 2) For optimum crimping refer to available crimping manual.
 - 3) Only valid for Code 1. For other codes please contact us.
- Part number example : S 103 A062-130



www.fischerconnectors.com