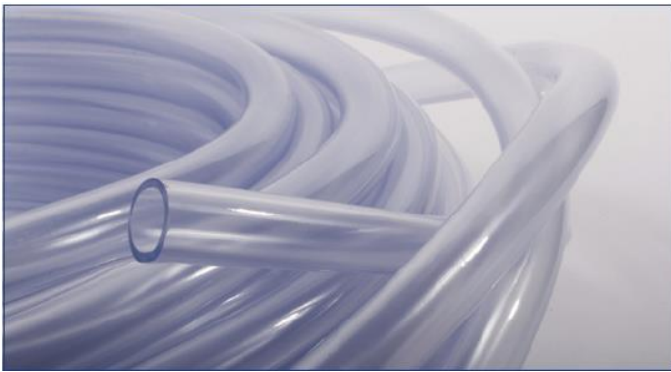


Datasheet

**Stock No: 9145512****RS Pro Clear Unreinforced PVC Hose**

Nominal Size	32 x 42mm
Internal Diameter	32.0 ± 0.50mm
External Diameter	42.0 ± 0.50mm
Length Tolerance	BS EN ISO 1307 (± 1%)
Maximum Working Pressure	N/A
Minimum Burst Pressure	N/A
Bend Radius	378mm
Working Temperature	-15°C to +60°C
Material	Flexible PVC
Material Softness	BSS45 FDA Approved
Flammability	Self-Extinguishing
Weight Per Meter	0.640Kg
Coil Weight	19.20Kg