


FEATURES

- Durable and lightweight
- Corrosion resistant
- Resistant to greases and oils
- Good electrical and thermal insulating properties
- Resistant to a wide range of temperatures

RS PRO, M5 Cheese Head, 25mm Nylon Slot Plain

RS Stock No.: 527-763

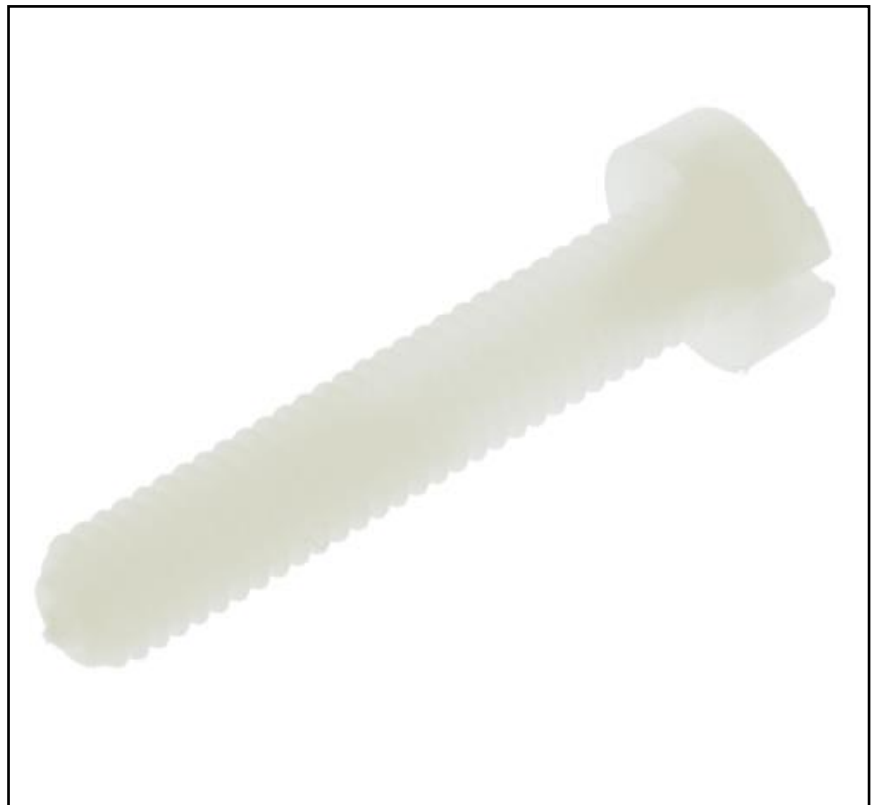

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

From RS PRO a high-quality machine screw with a slotted Cheese type head for easy tightening with a flat blade screwdriver. This machine screw has a metric thread and is made from high-quality nylon making it strong, lightweight and resistant to corrosion. Nylon also has excellent electrical insulation properties making this machine screw ideal for use in electronics applications.

General Specifications

Head Shape	Cheese
Drive Type	Slot
Applications	Washing machines, Household appliances, Handheld devices, Electronics and circuit boards, Commercial machinery, Automotive parts

Mechanical Specifications

Thread Size (Metric)	M5
Length Metric	25mm
Material	Nylon
Finish	Plain
Thread Pitch	0.8mm



RS Stock No.	Thread Size	Length (L) (mm)
527-656	M3 x 0.50	20
527-684	M4 x 0.70	12
527-690	M4 x 0.70	16
527-707	M4 x 0.70	20
527-735	M5 x 0.80	12
527-779	M6 x 1.00	12
527-785	M6 x 1.00	16
527-791	M6 x 1.00	20
527-808	M6 x 1.00	25
527-814	M6 x 1.00	30
527-971	M3 x 0.50	6
527-987	M3 x 0.50	12
527-993	M3 x 0.50	16

