
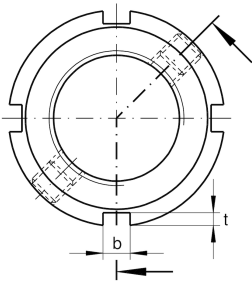


ZM12

Precision locknut

Precision locknut ZM, accessory ZM..

Technical information

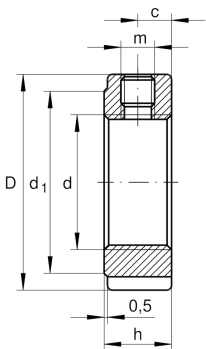

Main Dimensions & Performance Data

d	M12X1	Thread
D	22 mm	Outside diameter
h	8 mm	Height
M _A	1 Nm	Mounting torque set screw
F _{aB}	38,000 N	Breaking load, axial
M _L	30 Nm	Breakawag
M _{AL}	8 Nm	Mounting torque reference
M _M	0.013 kg*cm2	Mass moment of inertia

≈m 14.49 g Weight

Dimensions

d ₁	18 mm	Plant diameter outside
t	2 mm	Hight retaining slot
b	3 mm	Width retaining slot
c	4 mm	Distance bore
m	M4	Threaded - threaded pin