

Clearly identify items with a durable P-touch label

Around the home, office, school, shop and other places of work, there are many uses for long lasting, durable P-touch labels. Common examples include:

- Cables and plugs •CD's and DVD's •Office equipment •File folders •Filing cabinets •Staff and visitor name badges •Signage •Mail rooms •Notice boards •Shelving •Telephone extension numbers



Technical Specifications

Items included

Items included	- PT-H105 labelling machine - 12mm black on white laminated label cassette (4m) - User guide
----------------	--

Hardware

Housing dimensions (mm)	110(w) x 207(h) x 59(d)
Housing weight	390g
Tape size	TZe tape: 3.5, 6, 9, 12mm
Print resolution	180 dpi
Max. print height	9.0 mm
Max. print speed	20mm / sec
Cutter type	Cutter blade
Keyboard type	ABC
Number of keys	54 keys
LCD display	12 chrs x 1 line
LCD size	58 mm x 22 mm
Text buffer	Max 80 chrs
Label memory	720 chrs (9 areas x 80 chrs)
Power	6 x AAA (LR03) alkaline batteries (not supplied) AD-24ES AC adapter (not supplied)

Built-in software

Built-in fonts	1 font
Built-in symbols	178
Character sizes	3 sizes
Character widths	3 widths: (extended, medium, condensed)
Font styles	9
Frames	7 frames
Underline	Yes
Max. number of lines	2 lines
Horizontal alignment	Automatic length labels: left aligned Pre-set length labels: centre aligned
Pre-set format (auto format)	None
Tape length setting	Yes (30-300 mm)
Tape margin settings	None, narrow, half, full, chain print
Tab function	No
Number of deco mode designs	12 designs
Number of auto designs	9 + random
Cable labelling function	Yes
Automatic numbering	No
Mirror printing	No
Vertical printing	Yes
Copy (repeat) printing	Yes (1-9)
Print preview	Yes (preview text and shows label length)
Auto power off	Yes
Unit change	Yes (inch/mm)
Language change	20 languages: (English, German, French, Spanish, Portuguese, Italian, Dutch, Danish, Norwegian, Swedish, Finnish, Hungarian, Czech, Polish, Romanian, Slovenian, Slovakian, Croatian, Turkish, Brazilian Portuguese)

Contact:



Brother UK Ltd
Audenshaw, Manchester, M34 5JD
Telephone: 08444 999444
Fax: 0870 8304031
Website: www.brother.co.uk
ZLFTPTH105U1



Labelling Machine

Easily organise your office files, CD cases, shelves and other items with the handheld P-touch H105.

- Easy-to-use label Auto Design function
- 9 font styles | 178 symbols | 7 frames
- Includes 12mm black on white label cassette
- Prints 3.5, 6, 9 & 12mm labels



Identify your important information with
the P-touch H105 labelling machine.



P-touch
H105

Organise your office with the P-touch H105

Increase your efficiency by ensuring items such as file folders, CD cases, shelving, filing cabinets and personal possessions are clearly identified with a Brother P-touch label. The compact handheld P-touch H105 is ideal for using around the office. With a wide variety of tape cassettes in various widths and colours you will find the P-touch H105 indispensable.



Easy-to-read display
With text preview before printing feature




9 font styles
Emphasise your text with a font style



Soft-touch keys
Type quicker and more accurately



Over 170 symbols
Emphasise your message

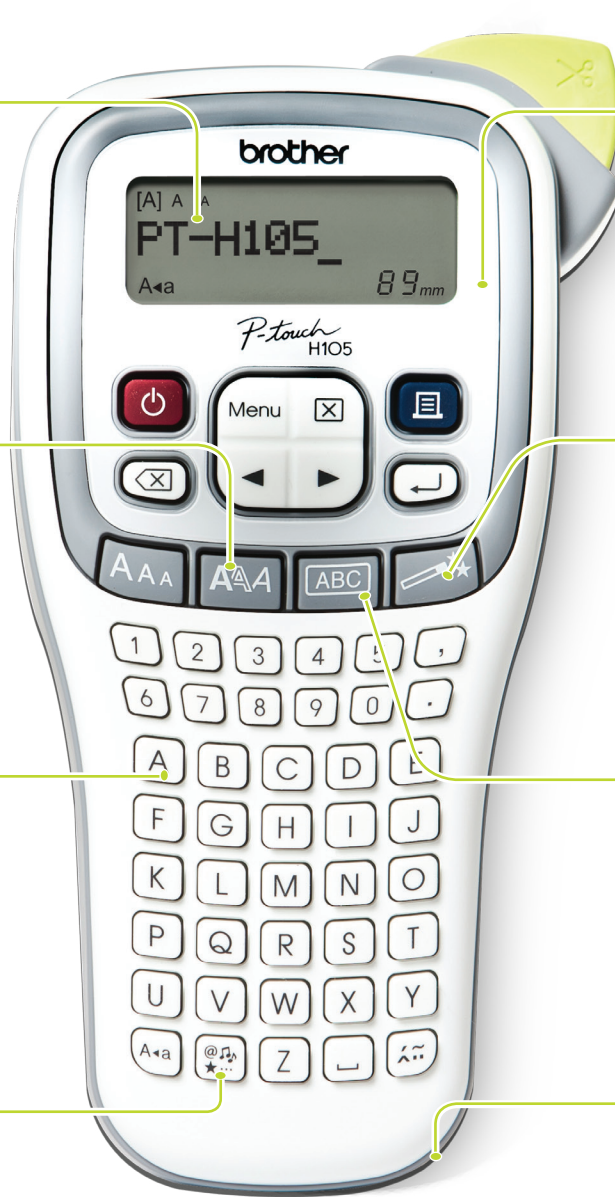

Lightweight, compact design
Ergonomic design that's easy to hold and use



Design creative labels
Using Auto Design or Deco Mode functions



7 frames
Personalise your labels by adding a frame



AC adapter slot
Uses batteries or AD-24ES AC adapter*

P-touch laminated labels – designed to last

Brother P-touch laminated TZe tapes consist of six layers of materials, resulting in a thin yet extremely strong label. The thermal transfer ink is sandwiched between two protective layers of PET (polyester film), which protects the text against the effects of liquids, abrasion, temperature, chemicals and sunlight. As the labels have been tested to the extreme, you can be confident of a professional quality label that has been designed to last.



Laminated



Temperature Resistant



Water Resistant



Fade Resistant



Abrasion Resistant



Chemical Resistant



Easy Peel



Strong Adhesion

* Optional accessory