



3315RZ1

Ultra compact, lithium ion rechargeable and safety certified make the Peli™ 3315RZ1 one of the most versatile work torches available today. Its compact design fits comfortably in your hand and requires little space for storage or transport. The 3315RZ1 produces up to 176 lumens and provides up to 48 hours of continuous run time. 3 modes are provided, High / Low / Flashing. There is a full time battery level indicator built into the power switch so you'll always know when it's time to recharge. Additionally, there is a right angle adapter accessory (sold separately) that provides hands free lighting. The right angle adapter also allows the light head to articulate, directing the light exactly where you need it.

- Full Time Battery Level Indication
- 3 modes High / Strobe / Low
- Lithium Ion Rechargeable Battery
- Lanyard (included)
- Articulating right angle adapter with clip (sold separately)
- Safety Certified Atex Zone 1
- Up to 176 Lumens
- Up to 48 hours run time
- IP67 waterproof and dustproof



DIMENSIONS

Length	6.11" (15.5 cm)
---------------	-----------------

MATERIALS

Body	Anti-static Impact Modified PC/PBT
O-Ring	EPDM
Lens	Polycarbonate (PC)
Shroud	Anti-static Impact Modified PC/PBT

COLOURS

	High Visibility Yellow
---	------------------------

LIGHT SPECS

Lamp Type	LED
------------------	-----

POWER

Battery Size	18650
Battery Type	Lithium-Ion
Battery Quantity	1
Batteries Included	yes
Rechargeable	yes
Charge Time	5 hrs
Battery Level Indicator	RGB LED
Volts	3.7v

WEIGHT

Weight With Batteries	6.2 oz (176 gr)
Weight Without Batteries	3.7 oz (105 gr)

SWITCH

Switch Type	Push Button
Light Modes	High / Low / Flashing

CERTIFICATIONS

ATEX Zone 1
IECEx ib

Peli

c/ Provença, 388, Planta 7 • Barcelona, Spain 08025 • Phone: +34 934 674 999

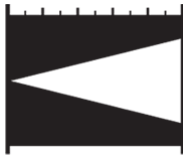
info@peli.com • www.peli.com

OTHER

Minimum Pack
Package Code

1
C

Document created on 02-19-19

FL1 STANDARD	HIGH	LOW
	176 LUMENS	22 LUMENS
	5h 30mins	48h 0mins
	127m	44m
	4022cd	492cd
	IP67	

ACCESSORIES